

[All Products](#) / [Optomechanics](#) / [Manual Translation Stages and Slides](#) / [Manual Stages and Slides](#)

Metric Lab Jacks



- Rugged, Black Anodized Aluminum Construction
- Fine Lead Screw for Precision Movement
- Large Adjustment Knob for Maximum Control
- Locking Knob to Secure Vertical Positioning

Common Specifications

Physical & Mechanical Properties


Type of Movement:	Linear (Z)	Guide System:	Pantograph
Construction:	Aluminum, Brass, & Stainless	Leadscrew Pitch (mm):	1
Parallelism (mm):	0.1 (typical)		

Hardware & Interface Connectivity

Type of Drive:	Lead Screw
----------------	------------


Technical Information

#54-687

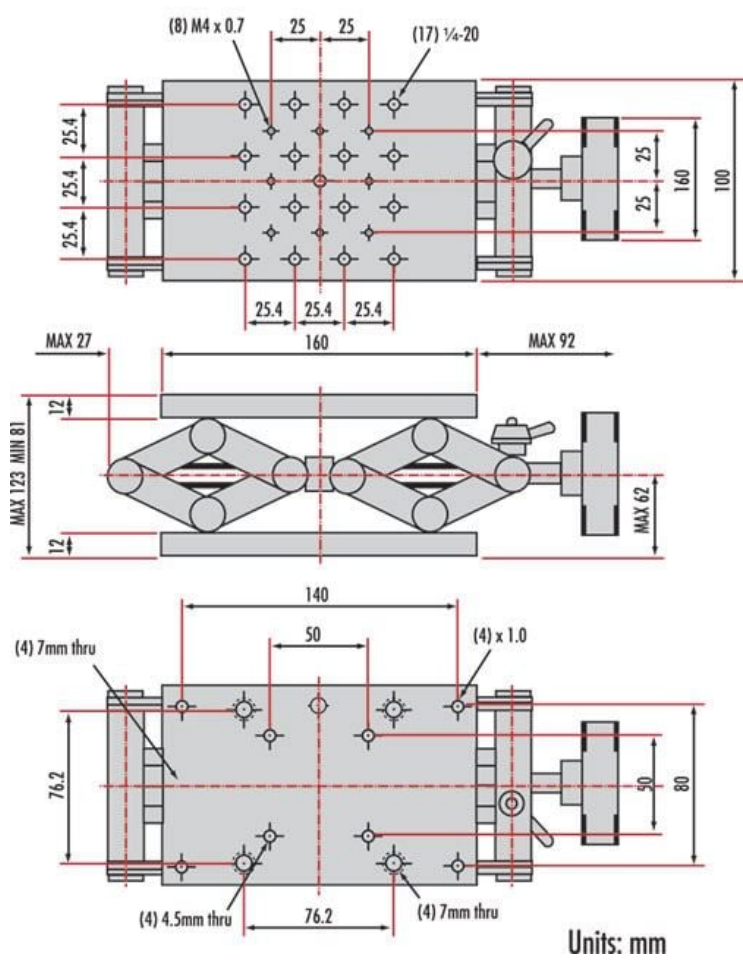

[illegible]

#56-336 132mm x 80mm Lab Jack

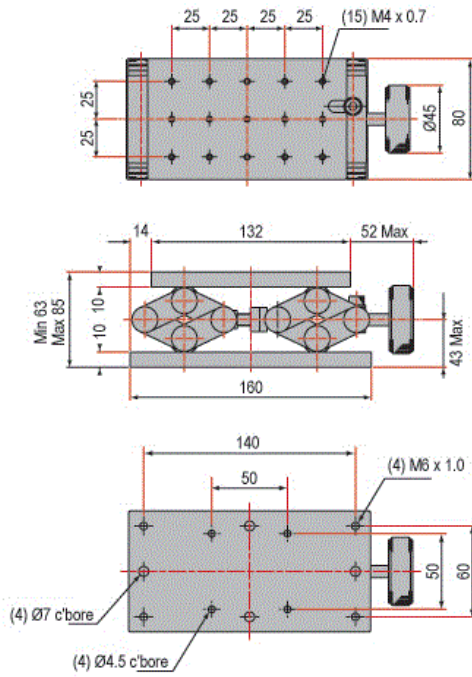

Units: mm

Products

Stage Size (mm)	Type	Height Adjustment (mm)	Minimum Height (mm)	Maximum Height (mm)	Load Capacity (kg)	Stock Number	Price	Buy
Top: 132 x 80 Bottom: 160 x 80	Metric	22	63	85	20	#56-336	A\$1,244.24	4 In Stock
160 x 100	Universal (Metric & English)	42	81	123	25	#54-687	A\$1,499.68	8 In Stock
220 x 160	Metric	70	100	170	30	#62-009	A\$1,779.84	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com