

[All Products](#) / [Optics](#) / [Beamsplitters](#) / [Plate Beamsplitters](#)

Pellicle Beamsplitters






- No Ghost Images from Second Surface Reflections
- No Chromatic Aberration with Converging Beams
- No Change in Optical Path Length
- [Pellicle Beamsplitters for the Infrared \(IR\)](#) Also Available

Common Specifications


Physical & Mechanical Properties			
Construction:	Pellicle	Housing:	Black Anodized Aluminum
Optical Properties			
Index of Refraction (n_d):	1.5	Substrate:	Nitrocellulose
Surface Quality:	40-20		

Technical Information

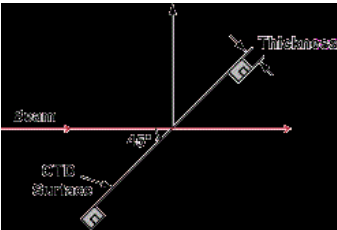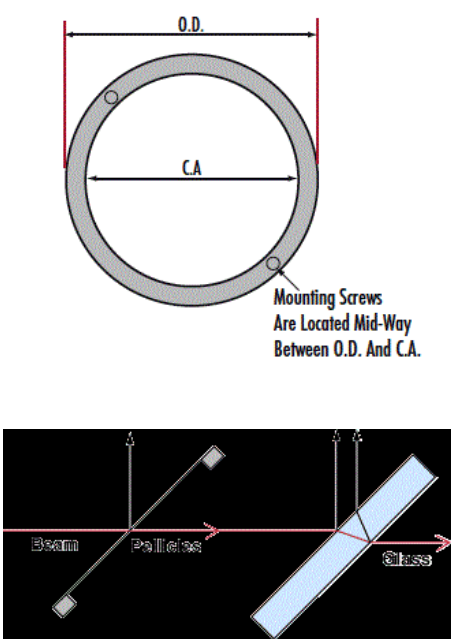


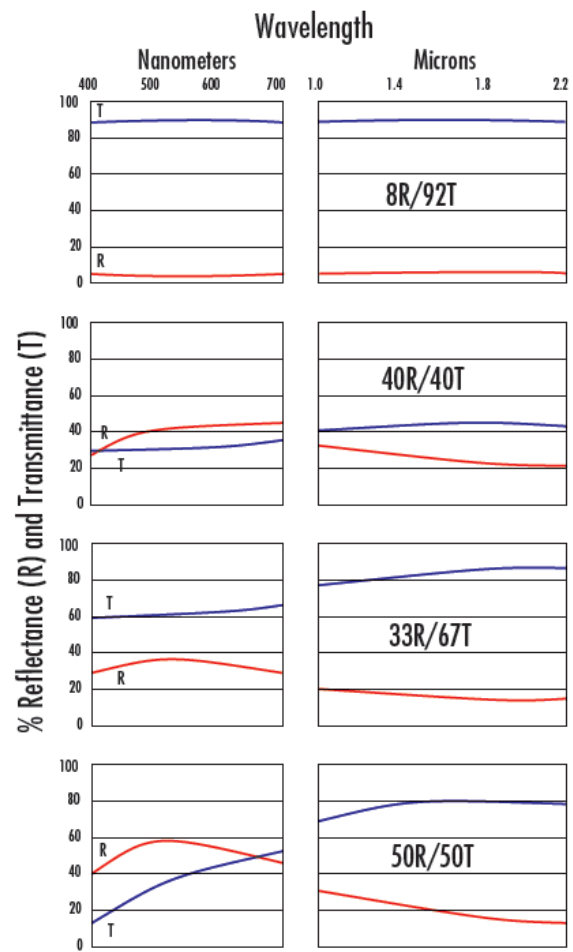


8R/92T Pellicle Beamsplitter

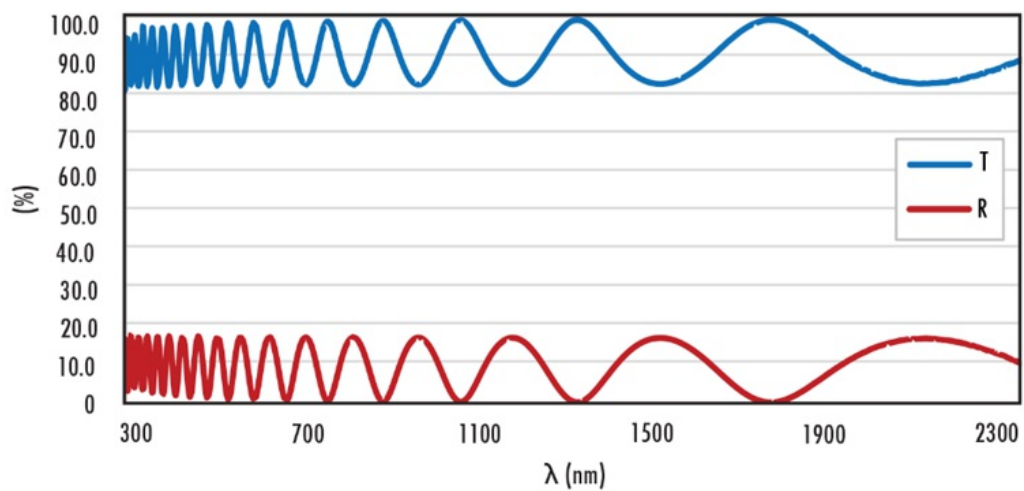


33R/67T Pellicle Beamsplitter

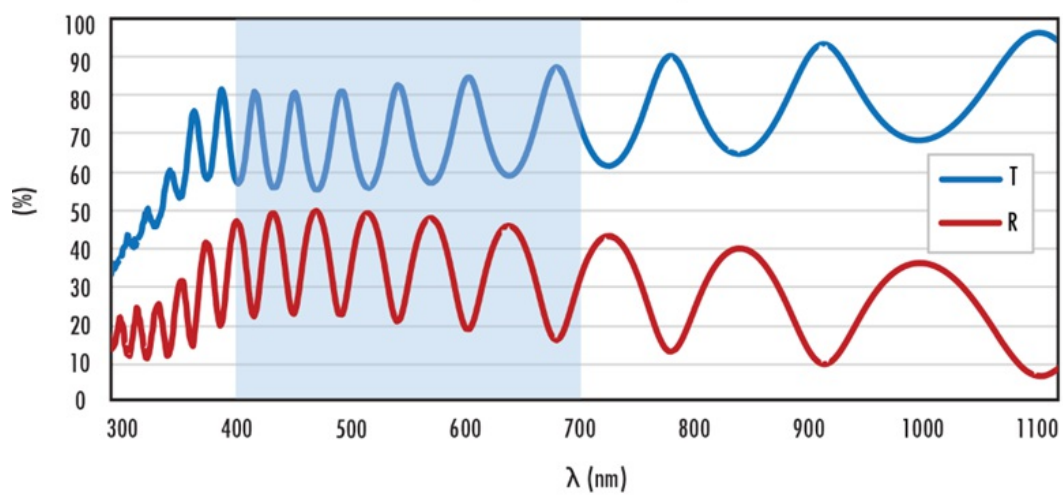


40R/40T Pellicle Beamsplitter

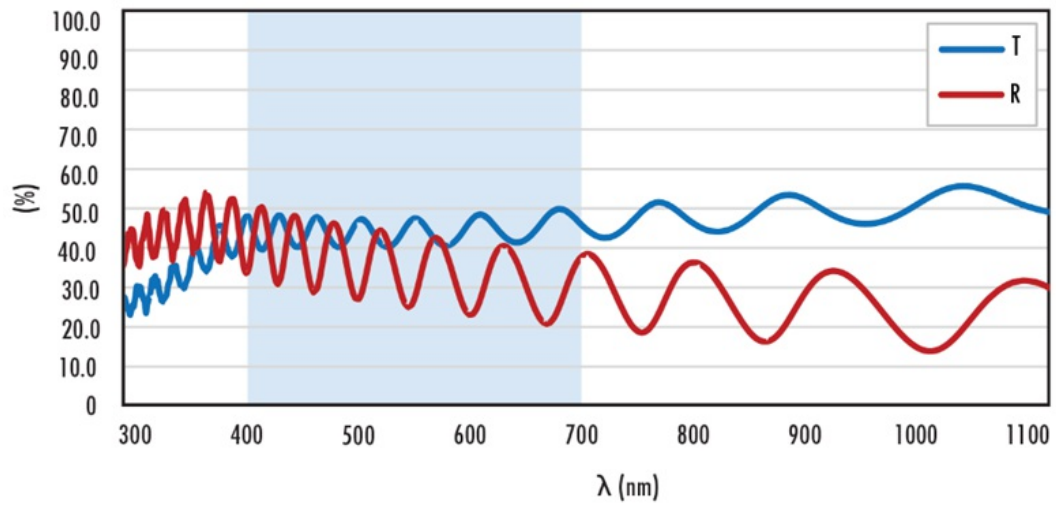

45R/55T Pellicle Beamsplitter

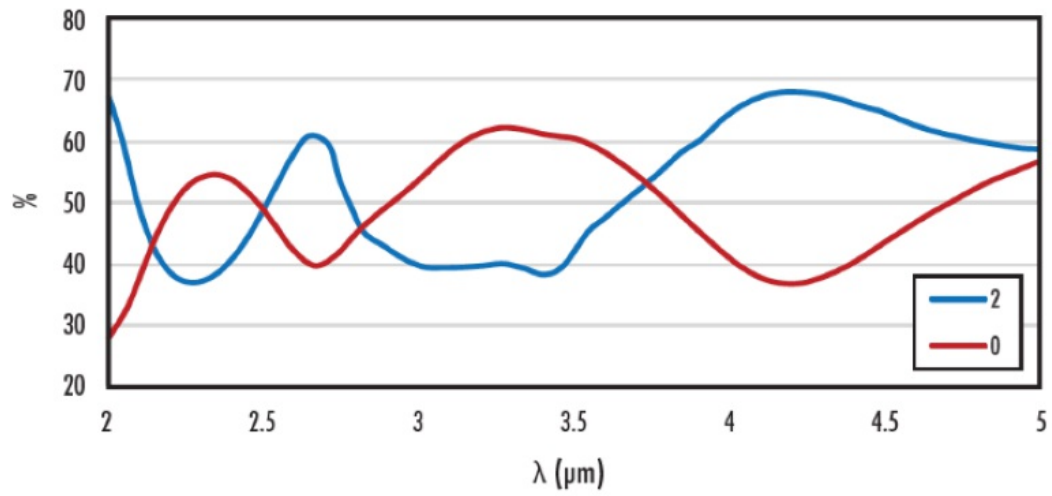

50R/50T Pellicle Beamsplitter

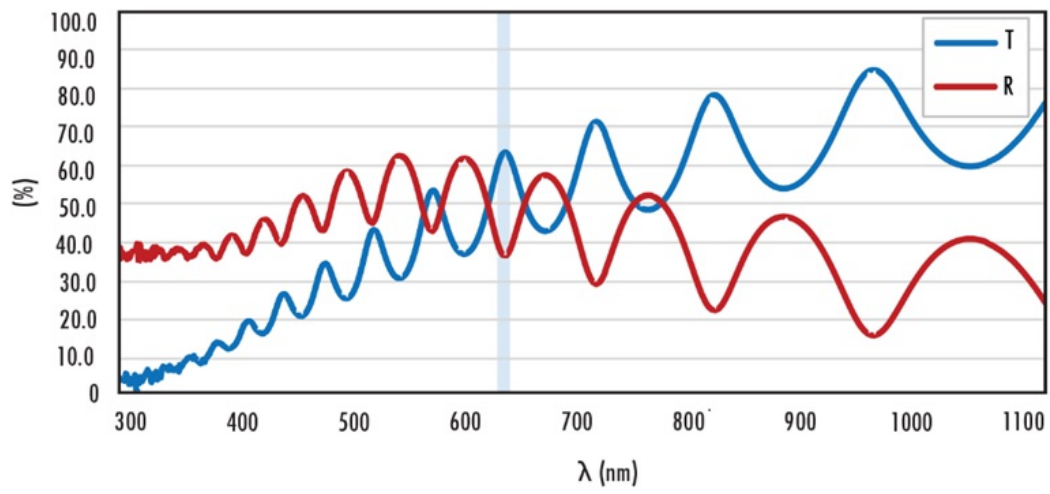

Products

Dia. (mm)	CA (mm)	Substrate	Reflection/Transmission Ratio (R/T)	Wavelength Range (nm)	DWL (nm)	Stock Number	Price	Buy
19.05	12.7	Nitrocellulose	8/92	400 - 2200	-	#19-307	A\$212.59 Volume Pricing	7 In Stock
19.05	12.7	Nitrocellulose	40/40	400 - 700	-	#19-308	A\$362.56 Volume Pricing	4 In Stock
19.05	12.7	Nitrocellulose	33/67	400 - 700	-	#19-309	A\$362.56 Volume Pricing	2 In Stock
19.05	12.7	Nitrocellulose	50/50	-	632.8	#19-310	A\$362.56 Volume Pricing	Contact Us
34.90	25.4	Nitrocellulose	33/67	400 - 700	-	#39-480	A\$372.45 Volume Pricing	Contact Us
34.90	25.4	Nitrocellulose	40/40	400 - 700	-	#39-479	A\$372.45 Volume Pricing	2 In Stock
34.90	25.4	Nitrocellulose	50/50	-	632.8	#39-481	A\$372.45 Volume Pricing	20+ In Stock
34.90	25.4	Nitrocellulose	8/92	400 - 2200	-	#39-478	A\$222.48 Volume Pricing	7 In Stock
63.50	50.8	Nitrocellulose	33/67	400 - 700	-	#39-484	A\$499.34 Volume Pricing	Contact Us
63.50	50.8	Nitrocellulose	40/40	400 - 700	-	#39-483	A\$499.34 Volume Pricing	Contact Us
63.50	50.8	Nitrocellulose	50/50	-	632.8	#39-485	A\$499.34 Volume Pricing	2 In Stock
63.50	50.8	Nitrocellulose	8/92	400 - 2200	-	#39-482	A\$306.53 Volume Pricing	6 In Stock
88.90	76.2	Nitrocellulose	33/67	400 - 700	-	#39-488	A\$609.76 Volume Pricing	Contact Us
88.90	76.2	Nitrocellulose	40/40	400 - 700	-	#39-487	A\$609.76 Volume Pricing	2 In Stock
88.90	76.2	Nitrocellulose	50/50	-	632.8	#39-489	A\$609.76 Volume Pricing	Contact Us
88.90	76.2	Nitrocellulose	8/92	400 - 2200	-	#39-486	A\$412.00 Volume Pricing	Contact Us
114.30	101.6	Nitrocellulose	33/67	400 - 700	-	#39-492	A\$964.08 Volume Pricing	Contact Us
114.30	101.6	Nitrocellulose	40/40	400 - 700	-	#39-491	A\$964.08 Volume Pricing	1 In Stock
114.30	101.6	Nitrocellulose	50/50	-	632.8	#39-493	A\$964.08 Volume Pricing	1 In Stock
114.30	101.6	Nitrocellulose	8/92	400 - 2200	-	#39-490	A\$565.26 Volume Pricing	3 In Stock

165.10	152.4	Nitrocellulose	33/67	400 - 700	-	#39-500	A\$1,697.44 Volume Pricing	2 In Stock
165.10	152.4	Nitrocellulose	40/40	400 - 700	-	#39-499	A\$1,697.44 Volume Pricing	5 In Stock
165.10	152.4	Nitrocellulose	50/50	-	632.8	#39-501	A\$1,697.44 Volume Pricing	Contact Us
165.10	152.4	Nitrocellulose	8/92	400 - 2200	-	#39-498	A\$1,145.36 Volume Pricing	1 In Stock
222.25	203.2	Nitrocellulose	40/40	400 - 700	-	#22-590	A\$3,394.88	1 In Stock
222.25	203.2	Nitrocellulose	50/50	-	632.8	#19-311	A\$3,394.88	Contact Us
222.25	203.2	Nitrocellulose	8/92	400 - 2200	-	#22-589	A\$2,603.84	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com