

[All Products](#) / [Optics](#) / [Prisms](#) / [Image Rotation Prisms](#)
**TECHSPEC® Amici Roof Prisms**


- Ray Deviation of 90°
- Right Handed Image
- 6 Arcsecond Resolution
- Roof Surfaces Available Uncoated or Silver Coated

## Common Specifications


### Physical & Mechanical Properties

Dimensional Tolerance (mm):	+0/-0.1	Resolution (arcsec):	6.00
Bevel:	Protective as needed		

### Optical Properties

Surface Quality:	60-40		
Image Orientation:	Right-Handed	Ray Deviation (°):	90
Wavelength Range (nm):	350 - 2200	Power (fringes) @ 632.8nm:	3.00
Irregularity (fringes) @ 632.8nm:	1.00		

## Technical Information

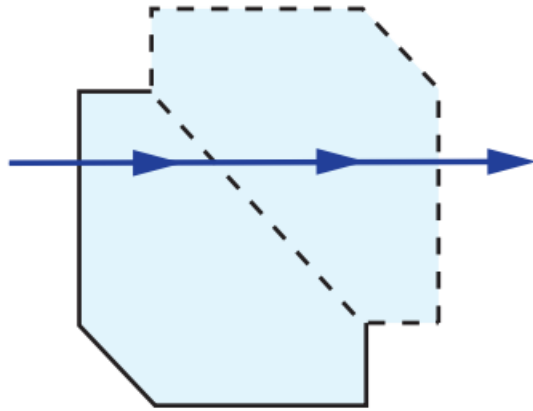

Amici Roof Prism Tunnel Diagram

## Products

Coating	CA (mm)	Wavelength Range (nm)	Stock Number	Price	Buy
Uncoated	8.00	350 - 2200	<a href="#">#45-662</a>	A\$149.14 <a href="#">Volume Pricing</a>	15 In Stock
Silver with protective overcoat	8.00	350 - 2200	<a href="#">#12-638</a>	A\$197.76 <a href="#">Volume Pricing</a>	20+ In Stock
Uncoated	13.00	350 - 2200	<a href="#">#45-261</a>	A\$166.45 <a href="#">Volume Pricing</a>	20+ In Stock
Silver with protective overcoat	13.00	350 - 2200	<a href="#">#12-639</a>	A\$214.24 <a href="#">Volume Pricing</a>	4 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)