

[All Products](#) / [Testing and Detection](#) / [Detectors](#)

InGaAs Photodiodes



- Response Range From 900nm to 1700nm
- Package Supports Single and Multi-Mode Fiber Coupling
- Both Small Area (High Speed) and Large Area
- [Segmented InGaAs Photodiodes](#) Also Available

Common Specifications

Optical Properties


Spectral Response (nm):	900 - 1700
-------------------------	------------

Electrical

Responsivity @ 1310nm (AW):	0.8 minimum / 0.9 typical
-----------------------------	---------------------------

Responsivity @ 1550nm (AW):	0.9 minimum / 0.95 typical
-----------------------------	----------------------------

Technical Information

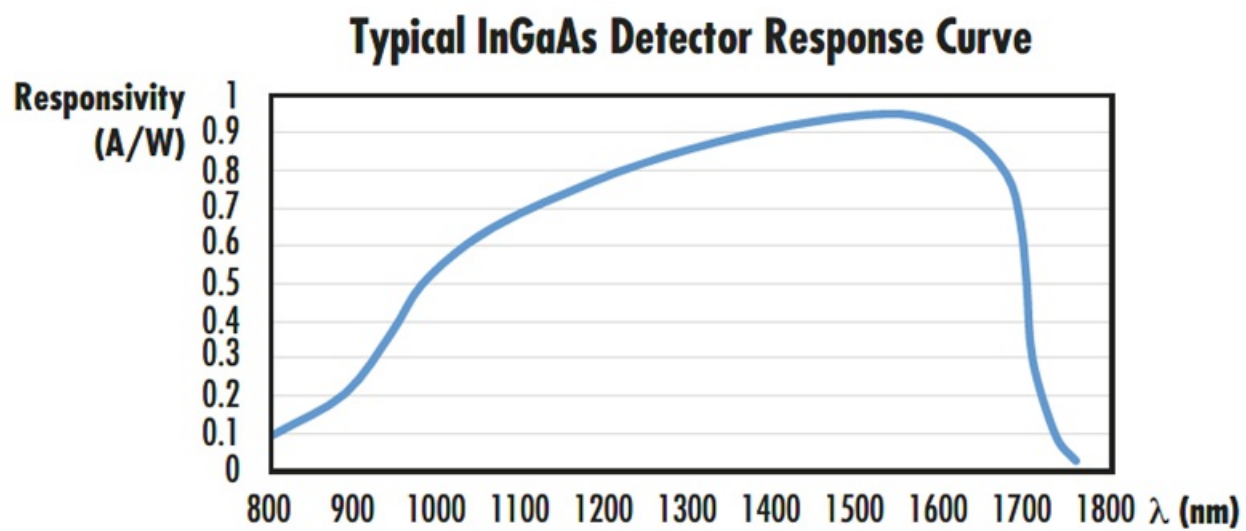

Products

Type	Spectral Response (nm)	Active Area Diameter (mm)	Package	Stock Number	Price	Buy
InGaAs Photodiode	900 - 1700	0.07	TO-46	#55-753	A\$160.80 Volume Pricing	5 In Stock
InGaAs Photodiode	900 - 1700	0.12	TO-46	#55-754	A\$160.80 Volume Pricing	10 In Stock
InGaAs Photodiode	900 - 1700	0.3	TO-46	#17-071	A\$169.60 Volume Pricing	4 In Stock
InGaAs Photodiode	900 - 1700	0.4	TO-46	#17-073	A\$169.60 Volume Pricing	20+ In Stock
InGaAs Photodiode	900 - 1700	0.5	TO-46	#62-271	A\$169.60 Volume Pricing	9 In Stock
InGaAs Photodiode	900 - 1700	1.0	TO-18	#17-075	A\$363.20 Volume Pricing	5 In Stock
InGaAs Photodiode	900 - 1700	1.5	TO-18	#17-076	A\$491.20 Volume Pricing	3 In Stock
InGaAs Photodiode	900 - 1700	3.0	TO-5	#59-140	A\$984.00 Volume Pricing	13 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com