

[All Products](#) / [Optics](#) / [Optical Assemblies](#) / [Laser Optic Assemblies](#)

LightPath® Fiber Optic Collimators

See More by [Lightpath®](#)





- Easy to Integrate
- Models for FC/PC, FC/APC, and SMA Connections Available
- Four Wavelength Ranges Covering 350-1600nm


Common Specifications

Physical & Mechanical Properties			
Bevel:		Protective as needed	
Construction:		304L Stainless Steel Housing	
Optical Properties			
Surface Quality:		40-20	
Conjugate Distance:		Infinite	

Technical Information

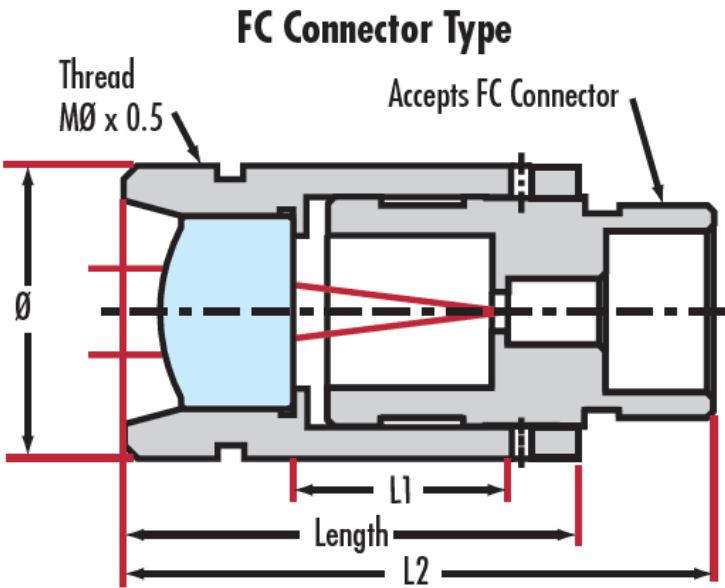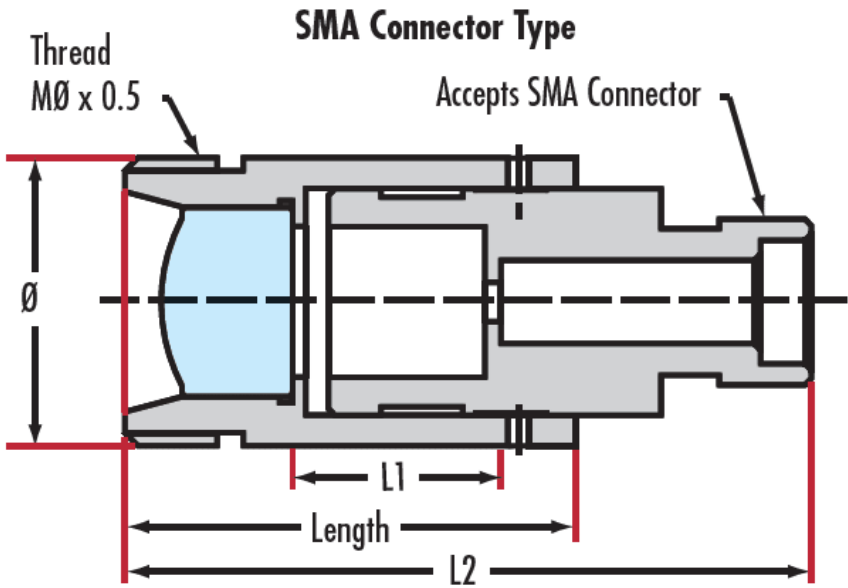

FC/APC Connectors

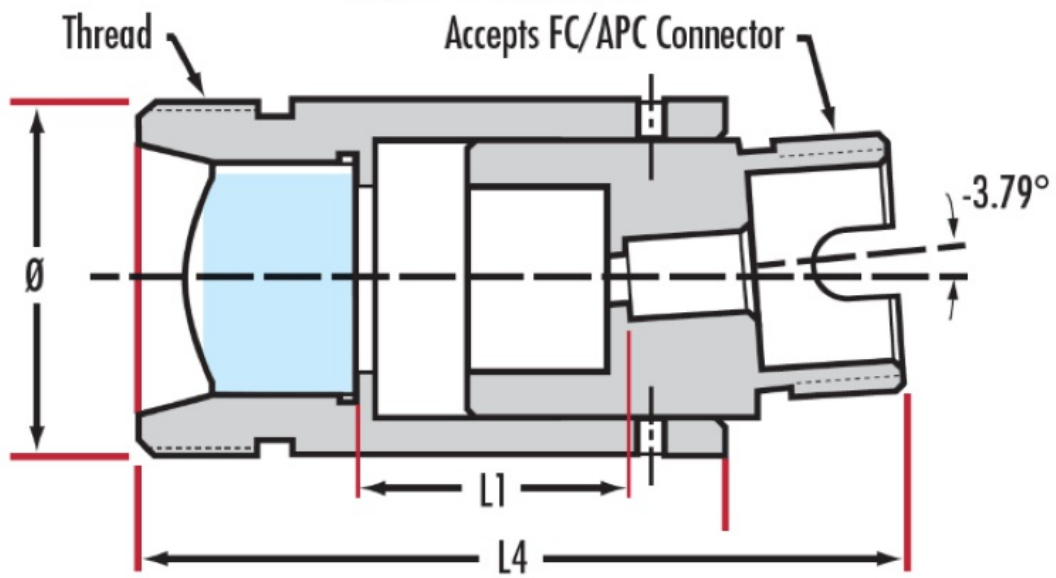

Products

EFL (mm)	NA	Coating	Alignment Wavelength (nm)	Connector	Lens Included	Stock Number	Price	Buy
15.29	0.16	BBAR (350-700nm)	543	FC/PC	#37-098	#47-224	A\$308.18 Volume Pricing	11 In Stock
15.29	0.16	BBAR (350-700nm)	543	SMA	#37-098	#47-227	A\$308.18 Volume Pricing	20+ In Stock
15.29	0.16	BBAR (350-700nm)	543	FC/APC	#37-098	#13-555	A\$463.09 Volume Pricing	20+ In Stock
15.29	0.16	BBAR (600-1050nm)	633	FC/APC	#37-099	#13-556	A\$463.09 Volume Pricing	9 In Stock
15.29	0.16	BBAR (600-1050nm)	633	FC/PC	#37-099	#67-719	A\$308.18 Volume Pricing	5 In Stock
15.29	0.16	BBAR (600-1050nm)	633	SMA	#37-099	#67-724	A\$308.18 Volume Pricing	5 In Stock
15.29	0.16	BBAR (600-1050nm)	780	FC/PC	#37-099	#47-225	A\$308.18 Volume Pricing	11 In Stock
15.29	0.16	BBAR (600-1050nm)	780	SMA	#37-099	#47-228	A\$308.18 Volume Pricing	3 In Stock
15.29	0.16	BBAR (1050-1600nm)	1064	FC/PC	#37-100	#64-765	A\$308.18 Volume Pricing	20+ In Stock

[#64-766 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

15.29	0.16	BBAR (1050-1600nm)	1064	SMA	#37-100	A\$194.38	20+ In Stock
-------	------	-----------------------	------	-----	-------------------------	-----------	--------------

[#47-226 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

15.29	0.16	BBAR (1050-1600nm)	1310	FC/PC	#37-100	A\$194.38	20+ In Stock
-------	------	-----------------------	------	-------	-------------------------	-----------	--------------

[#47-229 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

15.29	0.16	BBAR (1050-1600nm)	1310	SMA	#37-100	A\$194.38	1 In Stock
-------	------	-----------------------	------	-----	-------------------------	-----------	------------

15.29	0.16	BBAR (1050-1600nm)	1550	FC/PC	#37-100	#83-724	A\$308.18 Volume Pricing	5 In Stock
-------	------	-----------------------	------	-------	-------------------------	-------------------------	---	------------

15.29	0.16	BBAR (1050-1600nm)	1550	SMA	#37-100	#83-729	A\$308.18 Volume Pricing	8 In Stock
-------	------	-----------------------	------	-----	-------------------------	-------------------------	---	------------

11.00	0.25	BBAR (350-700nm)	543	FC/PC	#87-117	#47-218	A\$308.18 Volume Pricing	Contact Us
-------	------	---------------------	-----	-------	-------------------------	-------------------------	---	------------

11.00	0.25	BBAR (350-700nm)	543	SMA	#87-117	#47-221	A\$308.18 Volume Pricing	15 In Stock
-------	------	---------------------	-----	-----	-------------------------	-------------------------	---	-------------

11.00	0.25	BBAR (350-700nm)	543	FC/APC	-	#16-705	A\$463.09 Volume Pricing	5 In Stock
-------	------	---------------------	-----	--------	---	-------------------------	---	------------

11.00	0.25	BBAR (600-1050nm)	633	FC/PC	#87-118	#67-720	A\$308.18 Volume Pricing	17 In Stock
-------	------	----------------------	-----	-------	-------------------------	-------------------------	---	-------------

11.00	0.25	BBAR (600-1050nm)	633	SMA	#87-118	#67-725	A\$308.18 Volume Pricing	5 In Stock
-------	------	----------------------	-----	-----	-------------------------	-------------------------	---	------------

11.00	0.25	BBAR (600-1050nm)	633	FC/APC	-	#16-706	A\$463.09 Volume Pricing	6 In Stock
-------	------	----------------------	-----	--------	---	-------------------------	---	------------

11.00	0.25	BBAR (600-1050nm)	780	FC/PC	#87-118	#47-219	A\$308.18 Volume Pricing	20+ In Stock
-------	------	----------------------	-----	-------	-------------------------	-------------------------	---	--------------

11.00	0.25	BBAR (600-1050nm)	780	SMA	#87-118	#47-222	A\$308.18 Volume Pricing	20+ In Stock
-------	------	----------------------	-----	-----	-------------------------	-------------------------	---	--------------

11.00	0.25	BBAR (1050-1600nm)	1064	FC/PC	#87-119	#64-767	A\$308.18 Volume Pricing	20+ In Stock
11.00	0.25	BBAR (1050-1600nm)	1064	SMA	#87-119	#64-768	A\$308.18 Volume Pricing	8 In Stock
11.00	0.25	BBAR (1050-1600nm)	1310	FC/PC	#87-119	#47-220	A\$308.18 Volume Pricing	20+ In Stock
11.00	0.25	BBAR (1050-1600nm)	1310	SMA	#87-119	#47-223	A\$308.18 Volume Pricing	20+ In Stock
11.00	0.25	BBAR (1050-1600nm)	1550	FC/PC	#87-119	#83-725	A\$308.18 Volume Pricing	6 In Stock
11.00	0.25	BBAR (1050-1600nm)	1550	SMA	#87-119	#83-730	A\$308.18 Volume Pricing	20+ In Stock
6.24	0.40	BBAR (350-700nm)	543	FC/APC	#87-125	#13-553	A\$463.09 Volume Pricing	5 In Stock
6.24	0.40	BBAR (350-700nm)	543	FC/PC	#87-125	#64-769	A\$308.18 Volume Pricing	20+ In Stock
6.24	0.40	BBAR (350-700nm)	543	SMA	#87-125	#64-770	A\$308.18 Volume Pricing	7 In Stock
6.24	0.40	BBAR (600-1050nm)	633	FC/APC	#87-126	#13-554	A\$463.09 Volume Pricing	7 In Stock
6.24	0.40	BBAR (600-1050nm)	633	FC/PC	#87-126	#67-721	A\$308.18 Volume Pricing	20+ In Stock
6.24	0.40	BBAR (600-1050nm)	633	SMA	#87-126	#67-726	A\$308.18 Volume Pricing	11 In Stock
6.24	0.40	BBAR (600-1050nm)	780	FC/PC	#87-126	#64-771	A\$308.18 Volume Pricing	20+ In Stock
6.24	0.40	BBAR (600-1050nm)	780	SMA	#87-126	#64-772	A\$308.18 Volume Pricing	8 In Stock

[#64-773 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

6.24	0.40	BBAR (1050-1600nm)	1064	FC/PC	#87-127	A\$194.38	20+ In Stock
------	------	-----------------------	------	-------	-------------------------	-----------	--------------

[#64-775 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

6.24	0.40	BBAR (1050-1600nm)	1310	FC/PC	#87-127	A\$194.38	20+ In Stock
------	------	-----------------------	------	-------	-------------------------	-----------	--------------

6.24	0.40	BBAR (1050-1600nm)	1550	SMA	#87-127	#83-731	A\$308.18 Volume Pricing	20+ In Stock
------	------	-----------------------	------	-----	-------------------------	-------------------------	---	--------------

8.00	0.50	BBAR (350-700nm)	543	FC/PC	#37-102	#64-777	A\$351.02 Volume Pricing	20+ In Stock
------	------	---------------------	-----	-------	-------------------------	-------------------------	---	--------------

8.00	0.50	BBAR (350-700nm)	543	FC/APC	-	#16-709	A\$463.09 Volume Pricing	Contact Us
------	------	---------------------	-----	--------	---	-------------------------	---	------------

8.00	0.50	BBAR (350-700nm)	543	SMA	#37-102	#64-778	A\$351.02 Volume Pricing	9 In Stock
8.00	0.50	BBAR (600-1050nm)	633	FC/PC	#37-103	#67-722	A\$308.18 Volume Pricing	20+ In Stock
8.00	0.50	BBAR (600-1050nm)	633	SMA	#37-103	#67-727	A\$351.02 Volume Pricing	8 In Stock
8.00	0.50	BBAR (600-1050nm)	633	FC/APC	-	#16-710	A\$463.09 Volume Pricing	9 In Stock
8.00	0.50	BBAR (600-1050nm)	780	FC/PC	#37-103	#64-779	A\$351.02 Volume Pricing	20+ In Stock
8.00	0.50	BBAR (600-1050nm)	780	SMA	#37-103	#64-780	A\$351.02 Volume Pricing	4 In Stock
8.00	0.50	BBAR (1050-1600nm)	1064	FC/PC	#37-104	#64-781	A\$351.02 Volume Pricing	15 In Stock
8.00	0.50	BBAR (1050-1600nm)	1064	SMA	#37-104	#64-782	A\$351.02 Volume Pricing	3 In Stock
8.00	0.50	BBAR (1050-1600nm)	1310	FC/PC	#37-104	#64-783	A\$351.02 Volume Pricing	Contact Us
8.00	0.50	BBAR (1050-1600nm)	1310	SMA	#37-104	#64-784	A\$351.02 Volume Pricing	9 In Stock
8.00	0.50	BBAR (1050-1600nm)	1550	FC/PC	#37-104	#83-727	A\$351.02 Volume Pricing	10 In Stock

[#83-732 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

8.00	0.50	BBAR (1050-1600nm)	1550	SMA	#37-104		A\$220.75	5 In Stock
------	------	-----------------------	------	-----	-------------------------	--	-----------	------------

4.51	0.55	BBAR (350-700nm)	543	FC/APC	#87-153	#13-551	A\$463.09 Volume Pricing	20+ In Stock
------	------	---------------------	-----	--------	-------------------------	-------------------------	---	--------------

4.51	0.55	BBAR (350-700nm)	543	FC/PC	#87-153	#64-785	A\$308.18 Volume Pricing	20+ In Stock
------	------	---------------------	-----	-------	-------------------------	-------------------------	---	--------------

4.51	0.55	BBAR (350-700nm)	543	SMA	#87-153	#64-786	A\$308.18 Volume Pricing	20+ In Stock
------	------	---------------------	-----	-----	-------------------------	-------------------------	---	--------------

4.51	0.55	BBAR (600-1050nm)	633	FC/APC	#87-154	#13-552	A\$463.09 Volume Pricing	7 In Stock
------	------	----------------------	-----	--------	-------------------------	-------------------------	---	------------

4.51	0.55	BBAR (600-1050nm)	633	FC/PC	#87-154	#67-723	A\$308.18 Volume Pricing	20+ In Stock
------	------	----------------------	-----	-------	-------------------------	-------------------------	---	--------------

4.51	0.55	BBAR (600-1050nm)	633	SMA	#87-154	#67-728	A\$308.18 Volume Pricing	6 In Stock
------	------	----------------------	-----	-----	-------------------------	-------------------------	---	------------

4.51	0.55	BBAR (600-1050nm)	780	FC/PC	#87-154	#64-787	A\$308.18 Volume Pricing	20+ In Stock
------	------	----------------------	-----	-------	-------------------------	-------------------------	---	--------------

4.51	0.55	BBAR (600-1050nm)	780	SMA	#87-154	#64-788	A\$308.18 Volume Pricing	5 In Stock
------	------	----------------------	-----	-----	-------------------------	-------------------------	---	------------

[#64-791 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

4.51	0.55	BBAR (1050-1600nm)	1310	FC/PC	#87-155	A\$194.38	5 In Stock
------	------	-----------------------	------	-------	-------------------------	-----------	------------

[#64-792 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

4.51	0.55	BBAR (1050-1600nm)	1310	SMA	#87-155	A\$194.38	9 In Stock
------	------	-----------------------	------	-----	-------------------------	-----------	------------

[#83-733 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.



BBAR (350-500nm) 405 FC/APC [#83-990](#) [#13-550](#) A\$463.09 [Volume Pricing](#) 20+ In Stock

Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [QUALITY POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com

4.00	0.60	BBAR (350-500nm)	405	FC/APC	#83-990	#13-550	A\$463.09 Volume Pricing	20+ In Stock
4.02	0.60	BBAR (350-500nm)	405	FC/PC	#83-990	#88-067	A\$308.18 Volume Pricing	20+ In Stock
4.02	0.60	BBAR (350-500nm)	405	SMA	#83-990	#88-068	A\$308.18 Volume Pricing	20+ In Stock