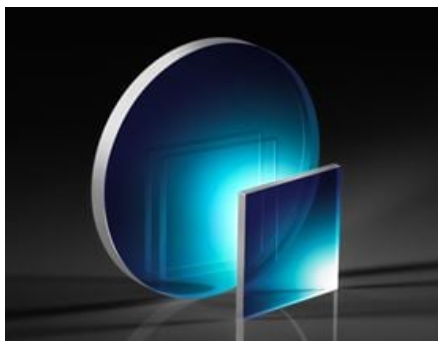


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)
TECHSPEC® $\lambda/10$ UV Fused Silica Windows


- UV, Visible, and NIR Anti-Reflection Coated Versions Available
- $\lambda/10$ Transmitted Wavefront Distortion
- Circular and Square Sizes from 2mm to 150mm
- [1 \$\lambda\$](#) or [\$\lambda/4\$](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm²):	522.00	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		



Optical Properties

Abbe Number (v_d):	67.8
Index of Refraction (n_d):	1.458

Material Properties

Density (g/cm³):	2.20
------------------------------------	------

Technical Information

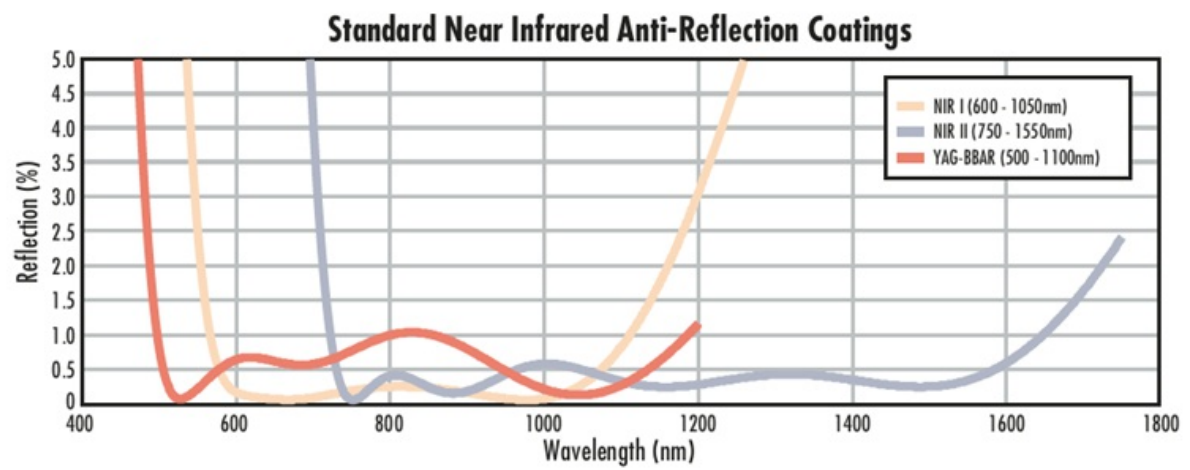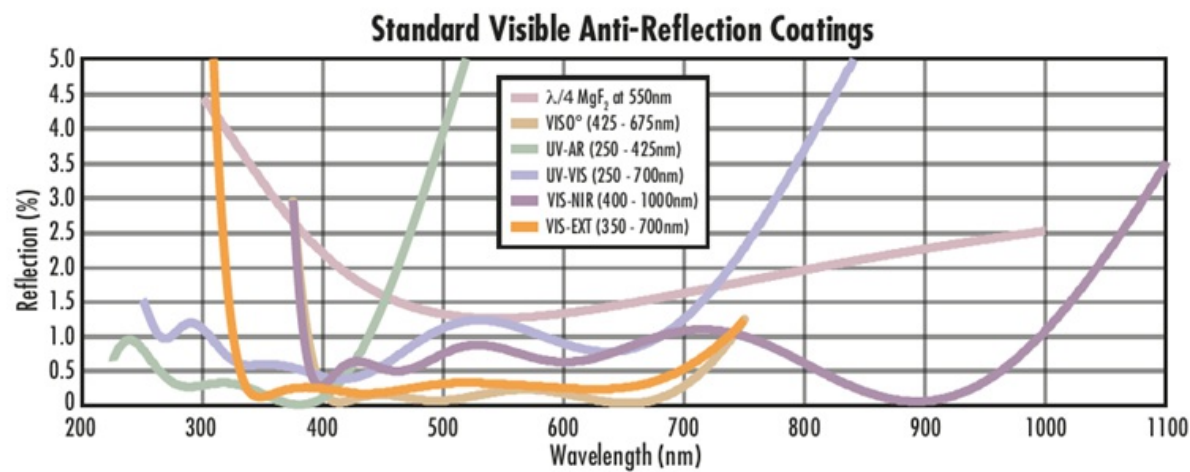

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
2.00	-	1.00	Uncoated	#27-669	A\$156.56 Volume Pricing	5 In Stock
2.50	-	1.00	Uncoated	#27-670	A\$156.56 Volume Pricing	20+ In Stock
3.00	-	1.00	Uncoated	#27-671	A\$164.80 Volume Pricing	20+ In Stock
4.00	-	1.00	Uncoated	#27-672	A\$174.69 Volume Pricing	20+ In Stock
5.00	-	1.00	Uncoated	#47-833	A\$196.11 Volume Pricing	Contact Us
10.00	-	1.25	Uncoated	#47-192	A\$186.22 Volume Pricing	20+ In Stock
12.50	-	1.50	Uncoated	#47-193	A\$191.17 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	Uncoated	#23-136	A\$191.17 Volume Pricing	6 In Stock
12.50	-	2.00	Uncoated	#63-107	A\$191.17 Volume Pricing	20+ In Stock
12.70	-	1.50	Uncoated	#15-402	A\$191.17 Volume Pricing	Contact Us
15.00	-	2.00	Uncoated	#47-194	A\$199.41 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#63-204	A\$212.59 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#11-876	A\$225.78 Volume Pricing	12 In Stock
25.00	-	2.00	Uncoated	#11-877	A\$225.78 Volume Pricing	20+ In Stock
25.00	-	3.00	Uncoated	#47-195	A\$225.78 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	Uncoated	#23-137	A\$225.78 Volume Pricing	20+ In Stock
25.00	-	5.00	Uncoated	#11-878	A\$225.78 Volume Pricing	20+ In Stock

25.40	-	3.00	Uncoated	#15-403	A\$225.78 Volume Pricing	1 In Stock
30.00	-	4.00	Uncoated	#47-834	A\$286.75 Volume Pricing	20+ In Stock
40.00	-	4.00	Uncoated	#47-835	A\$326.30 Volume Pricing	20+ In Stock
50.00	-	1.00	Uncoated	#34-599	A\$395.52 Volume Pricing	20+ In Stock
50.00	-	2.00	Uncoated	#34-600	A\$395.52 Volume Pricing	Contact Us
50.00	-	3.00	Uncoated	#34-601	A\$395.52 Volume Pricing	20+ In Stock
50.00	-	5.00	Uncoated	#47-836	A\$395.52 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	Uncoated	#23-138	A\$395.52 Volume Pricing	2 In Stock
50.00	-	6.00	Uncoated	#34-602	A\$395.52 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#15-404	A\$395.52 Volume Pricing	16 In Stock
75.00	-	3.00	Uncoated	#36-935	A\$660.85 Volume Pricing	20+ In Stock
75.00	-	5.00	Uncoated	#36-936	A\$660.85 Volume Pricing	Contact Us
100.00	-	5.00	Uncoated	#17-561	A\$840.48 Volume Pricing	15 In Stock
125.00	-	6.00	Uncoated	#17-562	A\$1,062.96 Volume Pricing	20+ In Stock
150.00	-	8.00	Uncoated	#17-563	A\$1,474.96 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#65-870	A\$243.90 Volume Pricing	11 In Stock
10.00	-	1.25	UV-AR (250-425nm)	#65-871	A\$234.02 Volume Pricing	6 In Stock
12.50	-	1.50	UV-AR (250-425nm)	#65-872	A\$238.96 Volume Pricing	20+ In Stock

-	12.50 x 12.50	1.50	UV-AR (250-425nm)	#24-296	A\$238.96 Volume Pricing	2 In Stock
12.50	-	2.00	UV-AR (250-425nm)	#68-487	A\$238.96 Volume Pricing	17 In Stock
12.70	-	1.50	UV-AR (250-425nm)	#15-405	A\$238.96 Volume Pricing	Contact Us
15.00	-	2.00	UV-AR (250-425nm)	#65-873	A\$247.20 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#65-874	A\$260.38 Volume Pricing	20+ In Stock
25.00	-	1.00	UV-AR (250-425nm)	#11-879	A\$273.57 Volume Pricing	1 In Stock
25.00	-	2.00	UV-AR (250-425nm)	#11-880	A\$273.57 Volume Pricing	5 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#65-875	A\$273.57 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	UV-AR (250-425nm)	#24-304	A\$273.57 Volume Pricing	8 In Stock
25.00	-	5.00	UV-AR (250-425nm)	#11-881	A\$273.57 Volume Pricing	6 In Stock
25.40	-	3.00	UV-AR (250-425nm)	#15-406	A\$273.57 Volume Pricing	8 In Stock
30.00	-	4.00	UV-AR (250-425nm)	#65-876	A\$342.78 Volume Pricing	8 In Stock
40.00	-	4.00	UV-AR (250-425nm)	#65-877	A\$382.34 Volume Pricing	Contact Us
50.00	-	1.00	UV-AR (250-425nm)	#36-938	A\$451.55 Volume Pricing	3 In Stock

50.00	-	2.00	UV-AR (250-425nm)	#36-943	A\$451.55 Volume Pricing	Contact Us
50.00	-	3.00	UV-AR (250-425nm)	#36-948	A\$451.55 Volume Pricing	6 In Stock
50.00	-	5.00	UV-AR (250-425nm)	#65-878	A\$451.55 Volume Pricing	9 In Stock
-	50.00 x 50.00	5.00	UV-AR (250-425nm)	#24-312	A\$451.55 Volume Pricing	1 In Stock
50.00	-	6.00	UV-AR (250-425nm)	#36-953	A\$451.55 Volume Pricing	5 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#15-407	A\$451.55 Volume Pricing	1 In Stock
75.00	-	3.00	UV-AR (250-425nm)	#36-958	A\$772.91 Volume Pricing	3 In Stock
75.00	-	5.00	UV-AR (250-425nm)	#36-963	A\$772.91 Volume Pricing	4 In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#48-062	A\$243.90 Volume Pricing	15 In Stock
10.00	-	1.25	UV-VIS (250-700nm)	#48-063	A\$234.02 Volume Pricing	20+ In Stock
12.50	-	1.50	UV-VIS (250-700nm)	#48-064	A\$238.96 Volume Pricing	14 In Stock
-	12.50 x 12.50	1.50	UV-VIS (250-700nm)	#24-297	A\$238.96 Volume Pricing	1 In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#68-488	A\$238.96 Volume Pricing	1 In Stock
12.70	-	1.50	UV-VIS (250-700nm)	#15-408	A\$238.96 Volume Pricing	1 In Stock

15.00	-	2.00	UV-VIS (250-700nm)	#48-065	A\$247.20 Volume Pricing	Contact Us
20.00	-	2.00	UV-VIS (250-700nm)	#63-206	A\$260.38 Volume Pricing	12 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#11-882	A\$273.57 Volume Pricing	7 In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#11-883	A\$273.57 Volume Pricing	17 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#48-066	A\$273.57 Volume Pricing	7 In Stock
-	25.00 x 25.00	3.00	UV-VIS (250-700nm)	#24-305	A\$273.57 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#11-884	A\$273.57 Volume Pricing	11 In Stock
25.40	-	3.00	UV-VIS (250-700nm)	#15-409	A\$273.57 Volume Pricing	5 In Stock
30.00	-	4.00	UV-VIS (250-700nm)	#48-067	A\$342.78 Volume Pricing	10 In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#48-068	A\$382.34 Volume Pricing	2 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#36-939	A\$451.55 Volume Pricing	Contact Us
50.00	-	2.00	UV-VIS (250-700nm)	#36-944	A\$451.55 Volume Pricing	Contact Us
50.00	-	3.00	UV-VIS (250-700nm)	#36-949	A\$451.55 Volume Pricing	7 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#48-069	A\$451.55 Volume Pricing	5 In Stock

-	50.00 x 50.00	5.00	UV-VIS (250-700nm)	#24-313	A\$451.55 Volume Pricing	6 In Stock
50.00	-	6.00	UV-VIS (250-700nm)	#36-954	A\$451.55 Volume Pricing	1 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#15-410	A\$451.55 Volume Pricing	3 In Stock
75.00	-	3.00	UV-VIS (250-700nm)	#36-959	A\$772.91 Volume Pricing	20+ In Stock
75.00	-	5.00	UV-VIS (250-700nm)	#36-964	A\$772.91 Volume Pricing	Contact Us
100.00	-	5.00	UV-VIS (250-700nm)	#22-064	A\$1,301.92 Volume Pricing	8 In Stock
125.00	-	6.00	UV-VIS (250-700nm)	#22-065	A\$1,672.72 Volume Pricing	5 In Stock
150.00	-	8.00	UV-VIS (250-700nm)	#22-066	A\$2,216.56 Volume Pricing	2 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#13-330	A\$247.20 Volume Pricing	5 In Stock
10.00	-	1.25	VIS-EXT (350-700nm)	#13-331	A\$238.96 Volume Pricing	5 In Stock
-	12.50 x 12.50	1.50	VIS-EXT (350-700nm)	#24-301	A\$243.90 Volume Pricing	4 In Stock
12.50	-	1.50	VIS-EXT (350-700nm)	#13-332	A\$243.90 Volume Pricing	7 In Stock
12.50	-	2.00	VIS-EXT (350-700nm)	#13-333	A\$243.90 Volume Pricing	5 In Stock
12.70	-	1.50	VIS-EXT (350-700nm)	#15-781	A\$243.90 Volume Pricing	11 In Stock

15.00	-	2.00	VIS-EXT (350-700nm)	#13-334	A\$252.14 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#13-335	A\$265.33 Volume Pricing	9 In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#13-336	A\$278.51 Volume Pricing	Contact Us
25.00	-	2.00	VIS-EXT (350-700nm)	#13-337	A\$278.51 Volume Pricing	Contact Us
-	25.00 x 25.00	3.00	VIS-EXT (350-700nm)	#24-309	A\$278.51 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#13-338	A\$278.51 Volume Pricing	5 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#13-339	A\$278.51 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-EXT (350-700nm)	#15-782	A\$278.51 Volume Pricing	4 In Stock
30.00	-	4.00	VIS-EXT (350-700nm)	#16-461	A\$347.73 Volume Pricing	2 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#13-341	A\$387.28 Volume Pricing	Contact Us
50.00	-	1.00	VIS-EXT (350-700nm)	#13-342	A\$456.50 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-EXT (350-700nm)	#13-343	A\$456.50 Volume Pricing	Contact Us
50.00	-	3.00	VIS-EXT (350-700nm)	#13-344	A\$456.50 Volume Pricing	2 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#13-345	A\$456.50 Volume Pricing	Contact Us

-	50.00 x 50.00	5.00	VIS-EXT (350-700nm)	#24-317	A\$456.50 Volume Pricing	7 In Stock
50.00	-	6.00	VIS-EXT (350-700nm)	#13-346	A\$456.50 Volume Pricing	Contact Us
50.80	-	5.00	VIS-EXT (350-700nm)	#15-783	A\$456.50 Volume Pricing	Contact Us
75.00	-	3.00	VIS-EXT (350-700nm)	#15-799	A\$782.80 Volume Pricing	2 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#15-800	A\$782.80 Volume Pricing	Contact Us
5.00	-	1.00	VIS-NIR (400-1000nm)	#84-449	A\$247.20 Volume Pricing	4 In Stock
10.00	-	1.25	VIS-NIR (400-1000nm)	#84-450	A\$238.96 Volume Pricing	9 In Stock
12.50	-	1.50	VIS-NIR (400-1000nm)	#84-451	A\$243.90 Volume Pricing	11 In Stock
-	12.50 x 12.50	1.50	VIS-NIR (400-1000nm)	#24-302	A\$243.90 Volume Pricing	1 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#84-452	A\$243.90 Volume Pricing	2 In Stock
12.70	-	1.50	VIS-NIR (400-1000nm)	#15-414	A\$243.90 Volume Pricing	1 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#84-453	A\$252.14 Volume Pricing	Contact Us
20.00	-	2.00	VIS-NIR (400-1000nm)	#84-454	A\$265.33 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#11-888	A\$278.51 Volume Pricing	20+ In Stock

25.00	-	2.00	VIS-NIR (400-1000nm)	#11-889	A\$278.51 Volume Pricing	9 In Stock
-	25.00 x 25.00	3.00	VIS-NIR (400-1000nm)	#24-310	A\$278.51 Volume Pricing	5 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#84-455	A\$278.51 Volume Pricing	20+ In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#11-890	A\$278.51 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-NIR (400-1000nm)	#15-415	A\$278.51 Volume Pricing	6 In Stock
30.00	-	4.00	VIS-NIR (400-1000nm)	#84-456	A\$347.73 Volume Pricing	10 In Stock
40.00	-	4.00	VIS-NIR (400-1000nm)	#84-457	A\$387.28 Volume Pricing	13 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#36-941	A\$456.50 Volume Pricing	6 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#36-946	A\$456.50 Volume Pricing	7 In Stock
50.00	-	3.00	VIS-NIR (400-1000nm)	#36-951	A\$456.50 Volume Pricing	1 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#84-458	A\$456.50 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	VIS-NIR (400-1000nm)	#24-318	A\$456.50 Volume Pricing	1 In Stock
50.00	-	6.00	VIS-NIR (400-1000nm)	#36-956	A\$456.50 Volume Pricing	13 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#15-416	A\$456.50 Volume Pricing	4 In Stock

75.00	-	3.00	VIS-NIR (400-1000nm)	#36-961	A\$782.80 Volume Pricing	5 In Stock
75.00	-	5.00	VIS-NIR (400-1000nm)	#36-966	A\$782.80 Volume Pricing	13 In Stock
100.00	-	5.00	VIS-NIR (400-1000nm)	#22-070	A\$1,301.92 Volume Pricing	4 In Stock
125.00	-	6.00	VIS-NIR (400-1000nm)	#22-071	A\$1,672.72 Volume Pricing	15 In Stock
150.00	-	8.00	VIS-NIR (400-1000nm)	#22-072	A\$2,216.56 Volume Pricing	5 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#47-837	A\$238.96 Volume Pricing	Contact Us
10.00	-	1.25	VIS 0° (425-675nm)	#47-196	A\$230.72 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	VIS 0° (425-675nm)	#24-298	A\$234.02 Volume Pricing	1 In Stock
12.50	-	1.50	VIS 0° (425-675nm)	#47-197	A\$234.02 Volume Pricing	20+ In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#68-489	A\$234.02 Volume Pricing	10 In Stock
12.70	-	1.50	VIS 0° (425-675nm)	#15-411	A\$234.02 Volume Pricing	4 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#47-198	A\$243.90 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS 0° (425-675nm)	#63-205	A\$257.09 Volume Pricing	7 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#11-885	A\$270.27 Volume Pricing	8 In Stock

25.00	-	2.00	VIS 0° (425-675nm)	#11-886	A\$270.27 Volume Pricing	17 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#47-199	A\$270.27 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	VIS 0° (425-675nm)	#24-306	A\$270.27 Volume Pricing	4 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#11-887	A\$270.27 Volume Pricing	6 In Stock
25.40	-	3.00	VIS 0° (425-675nm)	#15-412	A\$270.27 Volume Pricing	20+ In Stock
30.00	-	4.00	VIS 0° (425-675nm)	#47-838	A\$339.49 Volume Pricing	8 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#47-839	A\$377.39 Volume Pricing	13 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#36-940	A\$448.26 Volume Pricing	10 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#36-945	A\$448.26 Volume Pricing	14 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#36-950	A\$448.26 Volume Pricing	11 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#47-840	A\$448.26 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	VIS 0° (425-675nm)	#24-314	A\$448.26 Volume Pricing	2 In Stock
50.00	-	6.00	VIS 0° (425-675nm)	#36-955	A\$448.26 Volume Pricing	4 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#15-413	A\$448.26 Volume Pricing	4 In Stock

75.00	-	3.00	VIS 0° (425-675nm)	#36-960	A\$764.67 Volume Pricing	2 In Stock
75.00	-	5.00	VIS 0° (425-675nm)	#36-965	A\$764.67 Volume Pricing	2 In Stock
100.00	-	5.00	VIS 0° (425-675nm)	#22-067	A\$1,277.20 Volume Pricing	10 In Stock
125.00	-	6.00	VIS 0° (425-675nm)	#22-068	A\$1,623.28 Volume Pricing	4 In Stock
150.00	-	8.00	VIS 0° (425-675nm)	#22-069	A\$2,175.36 Volume Pricing	3 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#13-347	A\$247.20 Volume Pricing	15 In Stock
10.00	-	1.25	YAG-BBAR (500-1100nm)	#13-348	A\$238.96 Volume Pricing	13 In Stock
-	12.50 x 12.50	1.50	YAG-BBAR (500-1100nm)	#24-303	A\$243.90 Volume Pricing	8 In Stock
12.50	-	1.50	YAG-BBAR (500-1100nm)	#13-349	A\$243.90 Volume Pricing	1 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#13-350	A\$243.90 Volume Pricing	9 In Stock
12.70	-	1.50	YAG-BBAR (500-1100nm)	#15-784	A\$243.90 Volume Pricing	4 In Stock
15.00	-	2.00	YAG-BBAR (500-1100nm)	#13-351	A\$252.14 Volume Pricing	1 In Stock

20.00	-	2.00	YAG-BBAR (500-1100nm)	#13-352	A\$265.33 Volume Pricing	9 In Stock
25.00	-	1.00	YAG-BBAR (500-1100nm)	#13-353	A\$278.51 Volume Pricing	Contact Us
25.00	-	2.00	YAG-BBAR (500-1100nm)	#13-354	A\$278.51 Volume Pricing	6 In Stock
-	25.00 x 25.00	3.00	YAG-BBAR (500-1100nm)	#24-311	A\$278.51 Volume Pricing	3 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#13-355	A\$278.51 Volume Pricing	3 In Stock
25.00	-	5.00	YAG-BBAR (500-1100nm)	#13-356	A\$278.51 Volume Pricing	3 In Stock
25.40	-	3.00	YAG-BBAR (500-1100nm)	#15-785	A\$278.51 Volume Pricing	9 In Stock
30.00	-	4.00	YAG-BBAR (500-1100nm)	#13-357	A\$347.73 Volume Pricing	17 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#13-358	A\$387.28 Volume Pricing	15 In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#13-359	A\$456.50 Volume Pricing	Contact Us
50.00	-	2.00	YAG-BBAR (500-1100nm)	#13-360	A\$456.50 Volume Pricing	Contact Us

50.00	-	3.00	YAG-BBAR (500-1100nm)	#13-361	A\$456.50 Volume Pricing	13 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#13-362	A\$456.50 Volume Pricing	14 In Stock
-	50.00 x 50.00	5.00	YAG-BBAR (500-1100nm)	#24-319	A\$456.50 Volume Pricing	5 In Stock
50.00	-	6.00	YAG-BBAR (500-1100nm)	#13-363	A\$456.50 Volume Pricing	12 In Stock
50.80	-	5.00	YAG-BBAR (500-1100nm)	#15-786	A\$456.50 Volume Pricing	4 In Stock
75.00	-	3.00	YAG-BBAR (500-1100nm)	#15-801	A\$782.80 Volume Pricing	Contact Us
75.00	-	5.00	YAG-BBAR (500-1100nm)	#15-802	A\$782.80 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR I (600-1050nm)	#84-459	A\$238.96 Volume Pricing	Contact Us
10.00	-	1.25	NIR I (600-1050nm)	#84-460	A\$230.72 Volume Pricing	20+ In Stock
12.50	-	1.50	NIR I (600-1050nm)	#84-461	A\$234.02 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	NIR I (600-1050nm)	#24-299	A\$234.02 Volume Pricing	5 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#84-462	A\$234.02 Volume Pricing	20+ In Stock

12.70	-	1.50	NIR I (600- 1050nm)	#15-417	A\$234.02 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600- 1050nm)	#84-463	A\$243.90 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR I (600- 1050nm)	#84-464	A\$257.09 Volume Pricing	20+ In Stock
25.00	-	1.00	NIR I (600- 1050nm)	#11-891	A\$270.27 Volume Pricing	15 In Stock
25.00	-	2.00	NIR I (600- 1050nm)	#11-892	A\$270.27 Volume Pricing	2 In Stock
25.00	-	3.00	NIR I (600- 1050nm)	#84-465	A\$270.27 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600- 1050nm)	#11-893	A\$270.27 Volume Pricing	1 In Stock
25.40	-	3.00	NIR I (600- 1050nm)	#15-418	A\$270.27 Volume Pricing	5 In Stock
-	25.00 x 25.00	3.00	NIR I (600- 1050nm)	#24-307	A\$270.27 Volume Pricing	Contact Us
30.00	-	4.00	NIR I (600- 1050nm)	#84-466	A\$339.49 Volume Pricing	10 In Stock
40.00	-	4.00	NIR I (600- 1050nm)	#84-467	A\$377.39 Volume Pricing	4 In Stock
50.00	-	1.00	NIR I (600- 1050nm)	#36-937	A\$448.26 Volume Pricing	5 In Stock
50.00	-	2.00	NIR I (600- 1050nm)	#36-942	A\$448.26 Volume Pricing	14 In Stock
50.00	-	3.00	NIR I (600- 1050nm)	#36-947	A\$448.26 Volume Pricing	5 In Stock

50.00	-	5.00	NIR I (600-1050nm)	#84-468	A\$448.26 Volume Pricing	Contact Us
-	50.00 x 50.00	5.00	NIR I (600-1050nm)	#24-315	A\$448.26 Volume Pricing	2 In Stock
50.00	-	6.00	NIR I (600-1050nm)	#36-952	A\$448.26 Volume Pricing	20+ In Stock
50.80	-	5.00	NIR I (600-1050nm)	#15-419	A\$448.26 Volume Pricing	2 In Stock
75.00	-	3.00	NIR I (600-1050nm)	#36-957	A\$764.67 Volume Pricing	Contact Us
75.00	-	5.00	NIR I (600-1050nm)	#36-962	A\$764.67 Volume Pricing	Contact Us
5.00	-	1.00	NIR II (750-1550nm)	#11-894	A\$238.96 Volume Pricing	Contact Us
10.00	-	1.25	NIR II (750-1550nm)	#11-895	A\$230.72 Volume Pricing	5 In Stock
12.50	-	1.50	NIR II (750-1550nm)	#11-896	A\$234.02 Volume Pricing	Contact Us
-	12.50 x 12.50	1.50	NIR II (750-1550nm)	#24-300	A\$234.02 Volume Pricing	2 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#11-897	A\$234.02 Volume Pricing	1 In Stock
12.70	-	1.50	NIR II (750-1550nm)	#15-420	A\$234.02 Volume Pricing	Contact Us
15.00	-	2.00	NIR II (750-1550nm)	#11-898	A\$243.90 Volume Pricing	11 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#11-899	A\$257.09 Volume Pricing	17 In Stock

25.00	-	1.00	NIR II (750-1550nm)	#11-900	A\$270.27 Volume Pricing	8 In Stock
25.00	-	2.00	NIR II (750-1550nm)	#11-901	A\$270.27 Volume Pricing	Contact Us
-	25.00 x 25.00	3.00	NIR II (750-1550nm)	#24-308	A\$270.27 Volume Pricing	4 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#11-902	A\$270.27 Volume Pricing	8 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#11-903	A\$270.27 Volume Pricing	8 In Stock
25.40	-	3.00	NIR II (750-1550nm)	#15-421	A\$270.27 Volume Pricing	5 In Stock
30.00	-	4.00	NIR II (750-1550nm)	#11-904	A\$339.49 Volume Pricing	5 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#11-905	A\$377.39 Volume Pricing	1 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#11-906	A\$448.26 Volume Pricing	7 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#11-907	A\$448.26 Volume Pricing	12 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#11-908	A\$448.26 Volume Pricing	20+ In Stock
50.00	-	5.00	NIR II (750-1550nm)	#11-909	A\$448.26 Volume Pricing	4 In Stock
-	50.00 x 50.00	5.00	NIR II (750-1550nm)	#24-316	A\$448.26 Volume Pricing	6 In Stock
50.00	-	6.00	NIR II (750-1550nm)	#11-910	A\$448.26 Volume Pricing	9 In Stock

50.80	-	5.00	NIR II (750-1550nm)	#15-422	A\$448.26 Volume Pricing	5 In Stock
75.00	-	3.00	NIR II (750-1550nm)	#11-911	A\$764.67 Volume Pricing	20+ In Stock
75.00	-	5.00	NIR II (750-1550nm)	#11-912	A\$764.67 Volume Pricing	6 In Stock
100.00	-	5.00	UV-AR (250-425nm)	#29-604	A\$1,301.92 Volume Pricing	Contact Us
100.00	-	5.00	VIS-EXT (350-700nm)	#29-607	A\$1,301.92 Volume Pricing	Contact Us
100.00	-	5.00	NIR I (600-1050nm)	#29-605	A\$1,277.20 Volume Pricing	Contact Us
100.00	-	5.00	NIR II (750-1550nm)	#29-606	A\$1,277.20 Volume Pricing	11 In Stock
#29-608 New						
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
100.00	-	5.00	YAG-BBAR (500-1100nm)		A\$1,301.92 Volume Pricing	Contact Us
100.00	-	10.00	Uncoated	#29-508	A\$1,013.52 Volume Pricing	20+ In Stock
125.00	-	6.00	UV-AR (250-425nm)	#29-609	A\$1,672.72 Volume Pricing	2 In Stock

125.00	-	6.00	VIS-EXT (350-700nm)	#29-612	A\$1,672.72 Volume Pricing	Contact Us
125.00	-	6.00	NIR I (600-1050nm)	#29-610	A\$1,623.28 Volume Pricing	1 In Stock
125.00	-	6.00	NIR II (750-1550nm)	#29-611	A\$1,623.28 Volume Pricing	5 In Stock
125.00	-	6.00	YAG-BBAR (500-1100nm)	#29-613	A\$1,672.72 Volume Pricing	2 In Stock
125.00	-	12.50	Uncoated	#29-509	A\$1,301.92 Volume Pricing	1 In Stock
150.00	-	8.00	UV-AR (250-425nm)	#29-614	A\$2,216.56 Volume Pricing	1 In Stock
150.00	-	8.00	VIS-EXT (350-700nm)	#29-617	A\$2,216.56 Volume Pricing	1 In Stock
150.00	-	8.00	NIR I (600-1050nm)	#29-615	A\$2,175.36 Volume Pricing	Contact Us
150.00	-	8.00	NIR II (750-1550nm)	#29-616	A\$2,175.36 Volume Pricing	3 In Stock

[#29-618 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

150.00 - 8.00 YAG-BBAR (500-1100nm)

A\$2,216.56
[Volume Pricing](#)

1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com

150.00 - 15.00 Uncoated [#29-510](#)

A\$2,060.00
[Volume Pricing](#)

5 In Stock