

[All Products](#) / [Imaging Lenses](#) / [M12 Lenses \(S-Mount Lenses\)](#)

TECHSPEC® Red Series M12 Lenses




- Up to 1/2", S-Mount Lens
- Up to 1.3 MegaPixels, 5µm Pixel Size Sensors
- Board Camera Lens Optimized Long WD and Infinite Conjugate
- 3.6mm to 8mm Focal Lengths


Common Specifications

General			
Series:	Red Series	IR Cut Filter:	No
Imaging Lens Type:	Standard Lens		
Physical & Mechanical Properties			
Iris Option:	Fixed		
Maximum Diameter (mm):	14	Outer Diameter (mm):	14
Optical Properties			
Wavelength Range (nm):	400 - 700	Working Distance (mm):	400 - ∞
Sensor			
Pixel Size (µm):	5.00		
Threading & Mounting			
Filter Thread:	N/A		
Mount:	S-Mount (M12 x 0.5)		


Technical Information

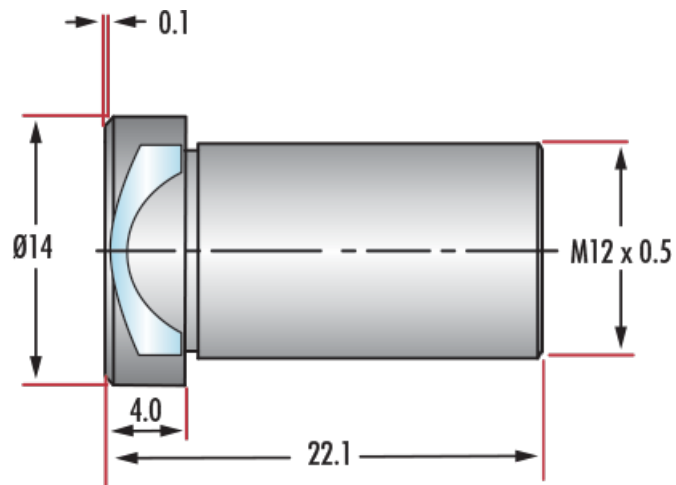


#57-910

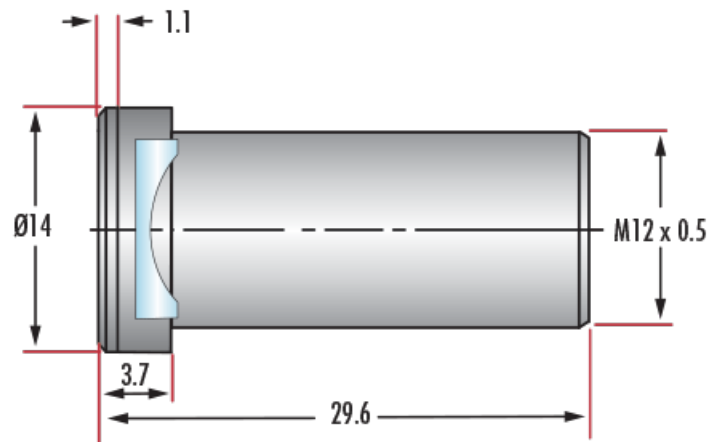

#57-909

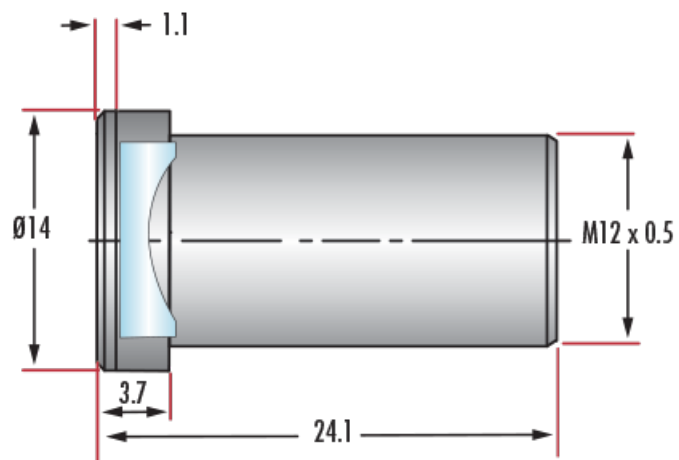

#57-908

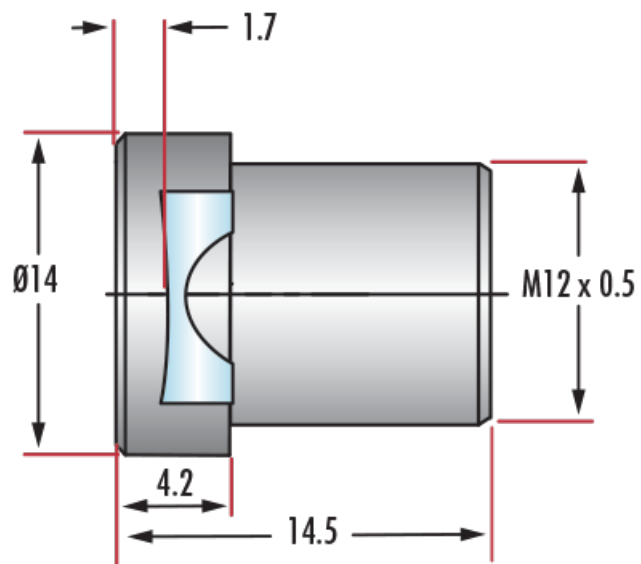

#57-907

Products

FL (mm)	Aperture (f/#)	Max. Sensor Format	WD (mm)	IR Cut Filter	Stock Number	Price	Buy
3.60	f/2.5	1/3.2"	400 - ∞	No	#57-907	A\$144.00	20+ In Stock
4.40	f/1.9	1/3"	400 - ∞	No	#57-908	A\$144.00	20+ In Stock
6.40	f/1.9	1/3"	400 - ∞	No	#57-909	A\$144.00	20+ In Stock
7.20	f/1.8	1/3"	400 - ∞	No	#57-910	A\$144.00	Contact Us
8.00	f/2.5	1/2"	400 - ∞	No	#69-255	A\$144.00	14 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com