

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® MgF₂ Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <1.75% Reflectance per Surface for 400 - 700nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)
- Also Available [Pre-Mounted in Engraved C-Mount Housings](#)

Common Specifications

Physical & Mechanical Properties



Bevel:	Protective as needed
--------	----------------------

Optical Properties

Focal Length Tolerance (%):	±1
-----------------------------	----

Wavelength Range (nm):	400 - 700
------------------------	-----------

Technical Information

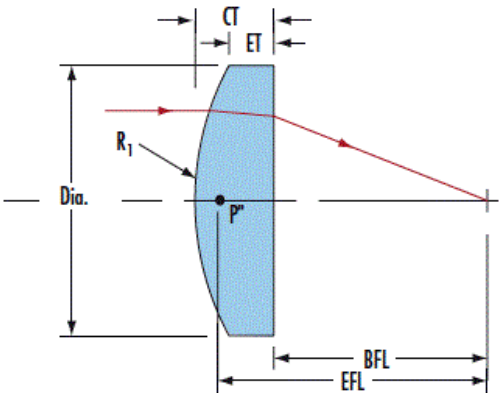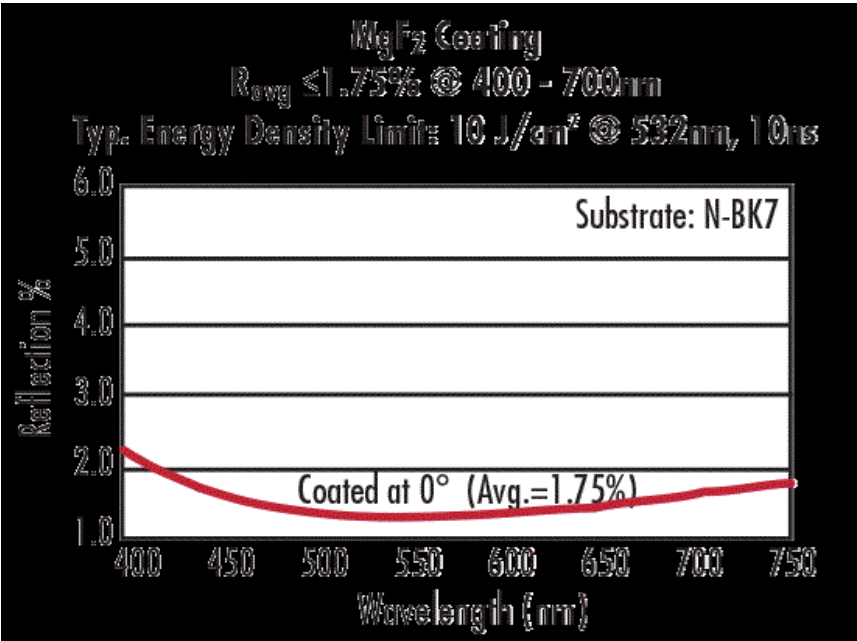

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	MgF ₂ (400-700nm)	N-LASF9	#65-257	A\$119.48 Volume Pricing	4 In Stock
1.00	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-258	A\$119.48 Volume Pricing	16 In Stock
1.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-259	A\$119.48 Volume Pricing	Contact Us
1.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-260	A\$119.48 Volume Pricing	1 In Stock
1.50	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-261	A\$119.48 Volume Pricing	2 In Stock
1.50	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-262	A\$119.48 Volume Pricing	1 In Stock
1.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-263	A\$119.48 Volume Pricing	14 In Stock
2.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-264	A\$117.83 Volume Pricing	6 In Stock
2.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-265	A\$117.83 Volume Pricing	9 In Stock
2.00	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-266	A\$117.83 Volume Pricing	2 In Stock
2.00	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-267	A\$117.83 Volume Pricing	8 In Stock
2.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-268	A\$117.83 Volume Pricing	6 In Stock

2.50	2.50	2.05	MgF ₂ (400-700nm)	N-LASF9	#65-269	A\$117.83 Volume Pricing	7 In Stock
2.50	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-270	A\$117.83 Volume Pricing	7 In Stock
2.50	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-271	A\$117.83 Volume Pricing	5 In Stock
2.50	5.00	4.57	MgF ₂ (400-700nm)	N-LASF9	#65-272	A\$117.83 Volume Pricing	5 In Stock
3.00	3.00	1.88	MgF ₂ (400-700nm)	N-SF11	#45-118	A\$97.23 Volume Pricing	20+ In Stock
3.00	4.50	3.50	MgF ₂ (400-700nm)	N-LASF44	#45-142	A\$97.23 Volume Pricing	Contact Us
3.00	6.00	4.81	MgF ₂ (400-700nm)	N-BK7	#32-953	A\$88.99 Volume Pricing	20+ In Stock
3.00	7.50	6.51	MgF ₂ (400-700nm)	N-BK7	#48-910	A\$88.99 Volume Pricing	5 In Stock
3.00	9.00	8.01	MgF ₂ (400-700nm)	N-BK7	#32-955	A\$88.99 Volume Pricing	10 In Stock
3.00	12.00	11.29	MgF ₂ (400-700nm)	N-BK7	#45-273	A\$88.99 Volume Pricing	14 In Stock
3.00	15.00	14.17	MgF ₂ (400-700nm)	N-BK7	#45-426	A\$88.99 Volume Pricing	12 In Stock
4.00	4.00	3.06	MgF ₂ (400-700nm)	N-LASF44	#45-224	A\$88.99 Volume Pricing	20+ In Stock
4.00	6.00	4.51	MgF ₂ (400-700nm)	N-BK7	#45-428	A\$88.99 Volume Pricing	20+ In Stock
4.00	8.00	7.17	MgF ₂ (400-700nm)	N-BAF10	#45-226	A\$81.99 Volume Pricing	20+ In Stock

4.00	10.00	8.92	MgF ₂ (400-700nm)	N-BK7	#45-430	A\$81.99 Volume Pricing	Contact Us
4.00	12.00	11.00	MgF ₂ (400-700nm)	N-BK7	#45-432	A\$81.99 Volume Pricing	20+ In Stock
4.50	4.50	3.05	MgF ₂ (400-700nm)	N-LASF44	#45-144	A\$88.99 Volume Pricing	9 In Stock
4.50	9.00	7.41	MgF ₂ (400-700nm)	N-BK7	#45-148	A\$81.99 Volume Pricing	20+ In Stock
5.00	5.00	3.96	MgF ₂ (400-700nm)	N-LASF44	#45-228	A\$71.28 Volume Pricing	20+ In Stock
5.00	7.50	6.43	MgF ₂ (400-700nm)	N-SF11	#48-655	A\$70.45 Volume Pricing	15 In Stock
5.00	10.00	8.91	MgF ₂ (400-700nm)	N-BK7	#45-230	A\$70.45 Volume Pricing	20+ In Stock
5.00	12.00	10.83	MgF ₂ (400-700nm)	N-BK7	#45-434	A\$70.45 Volume Pricing	20+ In Stock
5.00	15.00	13.94	MgF ₂ (400-700nm)	N-BK7	#45-355	A\$70.45 Volume Pricing	5 In Stock
5.00	20.00	19.02	MgF ₂ (400-700nm)	N-BK7	#49-883	A\$70.45 Volume Pricing	20+ In Stock
5.00	25.00	23.95	MgF ₂ (400-700nm)	N-BK7	#87-913	A\$70.45 Volume Pricing	5 In Stock
5.00	30.00	28.95	MgF ₂ (400-700nm)	N-BK7	#87-914	A\$70.45 Volume Pricing	2 In Stock
6.00	6.00	4.60	MgF ₂ (400-700nm)	N-SF11	#45-078	A\$57.68 Volume Pricing	14 In Stock
6.00	7.50	6.10	MgF ₂ (400-700nm)	N-SF11	#49-884	A\$56.86 Volume Pricing	20+ In Stock

6.00	9.00	7.95	MgF ₂ (400-700nm)	N-SF5	#32-470	A\$56.86 Volume Pricing	20+ In Stock
6.00	10.00	8.82	MgF ₂ (400-700nm)	N-BK7	#38-215	A\$56.86 Volume Pricing	7 In Stock
6.00	12.00	10.94	MgF ₂ (400-700nm)	N-BK7	#32-472	A\$55.21 Volume Pricing	20+ In Stock
6.00	15.00	13.68	MgF ₂ (400-700nm)	N-BK7	#45-080	A\$55.21 Volume Pricing	20+ In Stock
6.00	18.00	17.07	MgF ₂ (400-700nm)	N-BK7	#32-474	A\$55.21 Volume Pricing	20+ In Stock
6.00	20.00	19.04	MgF ₂ (400-700nm)	N-BK7	#38-216	A\$55.21 Volume Pricing	1 In Stock
6.00	21.00	20.06	MgF ₂ (400-700nm)	N-BK7	#45-232	A\$55.21 Volume Pricing	20+ In Stock
6.00	24.00	23.01	MgF ₂ (400-700nm)	N-BK7	#32-957	A\$55.21 Volume Pricing	20+ In Stock
6.00	25.00	24.04	MgF ₂ (400-700nm)	N-BK7	#38-217	A\$55.21 Volume Pricing	2 In Stock
6.00	30.00	29.14	MgF ₂ (400-700nm)	N-BK7	#45-120	A\$55.21 Volume Pricing	6 In Stock
6.00	36.00	34.95	MgF ₂ (400-700nm)	N-BK7	#32-849	A\$55.21 Volume Pricing	14 In Stock
6.00	48.00	46.95	MgF ₂ (400-700nm)	N-BK7	#45-234	A\$55.21 Volume Pricing	5 In Stock
6.00	60.00	58.95	MgF ₂ (400-700nm)	N-BK7	#67-154	A\$55.21 Volume Pricing	1 In Stock
6.00	72.00	70.97	MgF ₂ (400-700nm)	N-BK7	#32-851	A\$55.21 Volume Pricing	20+ In Stock

7.00	7.00	5.50	MgF ₂ (400-700nm)	N-SF11	#71-293	A\$57.68 Volume Pricing	3 In Stock
7.00	10.00	8.10	MgF ₂ (400-700nm)	N-BK7	#71-300	A\$56.86 Volume Pricing	5 In Stock
7.00	12.00	10.30	MgF ₂ (400-700nm)	N-BK7	#71-307	A\$56.86 Volume Pricing	3 In Stock
8.00	8.00	6.40	MgF ₂ (400-700nm)	N-SF11	#71-314	A\$57.68 Volume Pricing	20+ In Stock
8.00	10.00	7.60	MgF ₂ (400-700nm)	N-BK7	#71-321	A\$56.86 Volume Pricing	9 In Stock
8.00	12.00	10.00	MgF ₂ (400-700nm)	N-BK7	#71-328	A\$56.86 Volume Pricing	7 In Stock
9.00	9.00	7.32	MgF ₂ (400-700nm)	N-SF11	#45-082	A\$58.50 Volume Pricing	7 In Stock
9.00	10.00	8.49	MgF ₂ (400-700nm)	N-SF11	#38-218	A\$58.50 Volume Pricing	20+ In Stock
9.00	12.00	10.60	MgF ₂ (400-700nm)	N-SF11	#49-885	A\$58.50 Volume Pricing	20+ In Stock
9.00	13.50	11.94	MgF ₂ (400-700nm)	N-SF5	#32-010	A\$58.50 Volume Pricing	20+ In Stock
9.00	15.00	13.02	MgF ₂ (400-700nm)	N-BK7	#49-886	A\$58.50 Volume Pricing	20+ In Stock
9.00	18.00	16.41	MgF ₂ (400-700nm)	N-BK7	#31-854	A\$56.86 Volume Pricing	20+ In Stock
9.00	20.00	18.55	MgF ₂ (400-700nm)	N-BK7	#38-219	A\$56.86 Volume Pricing	1 In Stock
9.00	22.00	20.73	MgF ₂ (400-700nm)	N-BK7	#45-236	A\$56.86 Volume Pricing	11 In Stock

9.00	25.00	23.68	MgF ₂ (400-700nm)	N-BK7	#38-220	A\$56.86 Volume Pricing	3 In Stock
9.00	27.00	25.35	MgF ₂ (400-700nm)	N-BK7	#32-959	A\$56.86 Volume Pricing	20+ In Stock
9.00	36.00	34.48	MgF ₂ (400-700nm)	N-BK7	#45-122	A\$56.86 Volume Pricing	20+ In Stock
9.00	45.00	43.98	MgF ₂ (400-700nm)	N-BK7	#45-357	A\$56.86 Volume Pricing	7 In Stock
9.00	54.00	52.69	MgF ₂ (400-700nm)	N-BK7	#67-155	A\$56.86 Volume Pricing	6 In Stock
9.00	72.00	70.68	MgF ₂ (400-700nm)	N-BK7	#67-156	A\$56.86 Volume Pricing	20+ In Stock
9.00	90.00	88.68	MgF ₂ (400-700nm)	N-BK7	#67-157	A\$56.86 Volume Pricing	6 In Stock
10.00	10.00	8.18	MgF ₂ (400-700nm)	N-SF11	#63-484	A\$58.50 Volume Pricing	20+ In Stock
10.00	12.50	10.99	MgF ₂ (400-700nm)	N-SF11	#38-223	A\$58.50 Volume Pricing	20+ In Stock
10.00	15.00	13.32	MgF ₂ (400-700nm)	N-SF11	#63-485	A\$58.50 Volume Pricing	20+ In Stock
10.00	17.50	15.66	MgF ₂ (400-700nm)	N-BK7	#38-224	A\$56.86 Volume Pricing	20+ In Stock
10.00	20.00	18.03	MgF ₂ (400-700nm)	N-BK7	#63-486	A\$56.86 Volume Pricing	20+ In Stock
10.00	25.00	23.02	MgF ₂ (400-700nm)	N-BK7	#63-487	A\$56.86 Volume Pricing	20+ In Stock
10.00	30.00	28.01	MgF ₂ (400-700nm)	N-BK7	#63-488	A\$56.86 Volume Pricing	20+ In Stock

10.00	40.00	38.02	MgF ₂ (400-700nm)	N-BK7	#63-489	A\$56.86 Volume Pricing	Contact Us
10.00	50.00	48.02	MgF ₂ (400-700nm)	N-BK7	#63-490	A\$56.86 Volume Pricing	4 In Stock
10.00	75.00	73.02	MgF ₂ (400-700nm)	N-BK7	#63-491	A\$56.86 Volume Pricing	16 In Stock
10.00	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#63-492	A\$56.86 Volume Pricing	Contact Us
12.00	12.00	9.76	MgF ₂ (400-700nm)	N-SF11	#45-084	A\$61.80 Volume Pricing	20+ In Stock
12.00	15.00	12.03	MgF ₂ (400-700nm)	N-BK7	#45-303	A\$61.80 Volume Pricing	20+ In Stock
12.00	18.00	16.22	MgF ₂ (400-700nm)	N-SF5	#32-007	A\$61.80 Volume Pricing	20+ In Stock
12.00	20.00	17.69	MgF ₂ (400-700nm)	N-BK7	#49-887	A\$61.80 Volume Pricing	20+ In Stock
12.00	24.00	22.15	MgF ₂ (400-700nm)	N-BK7	#31-855	A\$60.15 Volume Pricing	20+ In Stock
12.00	25.00	23.22	MgF ₂ (400-700nm)	N-BK7	#38-226	A\$60.15 Volume Pricing	2 In Stock
12.00	30.00	28.02	MgF ₂ (400-700nm)	N-BK7	#45-086	A\$60.15 Volume Pricing	20+ In Stock
12.00	36.00	34.02	MgF ₂ (400-700nm)	N-BK7	#33-353	A\$60.15 Volume Pricing	20+ In Stock
12.00	42.00	40.22	MgF ₂ (400-700nm)	N-BK7	#45-124	A\$60.15 Volume Pricing	2 In Stock
12.00	48.00	46.36	MgF ₂ (400-700nm)	N-BK7	#32-853	A\$60.15 Volume Pricing	20+ In Stock

12.00	50.00	48.75	MgF ₂ (400-700nm)	N-BK7	#38-230	A\$60.15 Volume Pricing	4 In Stock
12.00	54.00	52.02	MgF ₂ (400-700nm)	N-BK7	#45-305	A\$60.15 Volume Pricing	20+ In Stock
12.00	60.00	58.37	MgF ₂ (400-700nm)	N-BK7	#32-855	A\$60.15 Volume Pricing	20+ In Stock
12.00	72.00	70.42	MgF ₂ (400-700nm)	N-BK7	#45-126	A\$60.15 Volume Pricing	14 In Stock
12.00	84.00	82.39	MgF ₂ (400-700nm)	N-BK7	#32-857	A\$60.15 Volume Pricing	20+ In Stock
12.00	100.00	98.35	MgF ₂ (400-700nm)	N-BK7	#45-275	A\$60.15 Volume Pricing	3 In Stock
12.50	12.50	10.40	MgF ₂ (400-700nm)	N-SF11	#38-231	A\$60.15 Volume Pricing	Contact Us
12.50	15.00	13.26	MgF ₂ (400-700nm)	N-SF11	#38-232	A\$60.15 Volume Pricing	13 In Stock
12.50	17.50	15.00	MgF ₂ (400-700nm)	N-BK7	#38-233	A\$60.15 Volume Pricing	2 In Stock
12.50	20.00	17.69	MgF ₂ (400-700nm)	N-BK7	#38-234	A\$60.15 Volume Pricing	8 In Stock
12.50	25.00	22.96	MgF ₂ (400-700nm)	N-BK7	#38-235	A\$58.50 Volume Pricing	1 In Stock
12.50	30.00	28.22	MgF ₂ (400-700nm)	N-BK7	#38-237	A\$58.50 Volume Pricing	1 In Stock
12.50	35.00	33.42	MgF ₂ (400-700nm)	N-BK7	#38-238	A\$58.50 Volume Pricing	6 In Stock
12.50	40.00	38.55	MgF ₂ (400-700nm)	N-BK7	#38-239	A\$58.50 Volume Pricing	4 In Stock

12.50	45.00	43.68	MgF ₂ (400-700nm)	N-BK7	#38-240	A\$58.50 Volume Pricing	1 In Stock
12.50	50.00	48.68	MgF ₂ (400-700nm)	N-BK7	#38-241	A\$58.50 Volume Pricing	4 In Stock
12.50	75.00	73.88	MgF ₂ (400-700nm)	N-BK7	#38-242	A\$58.50 Volume Pricing	5 In Stock
12.50	100.00	98.95	MgF ₂ (400-700nm)	N-BK7	#38-243	A\$58.50 Volume Pricing	3 In Stock
12.70	12.70	10.46	MgF ₂ (400-700nm)	N-SF11	#49-854	A\$60.15 Volume Pricing	8 In Stock
12.70	15.00	11.53	MgF ₂ (400-700nm)	N-BK7	#49-855	A\$60.15 Volume Pricing	20+ In Stock
12.70	19.10	16.46	MgF ₂ (400-700nm)	N-BK7	#49-856	A\$60.15 Volume Pricing	Contact Us
12.70	20.00	17.49	MgF ₂ (400-700nm)	N-BK7	#38-244	A\$60.15 Volume Pricing	4 In Stock
12.70	25.40	23.43	MgF ₂ (400-700nm)	N-BK7	#49-857	A\$58.50 Volume Pricing	20+ In Stock
12.70	30.00	28.22	MgF ₂ (400-700nm)	N-BK7	#38-245	A\$58.50 Volume Pricing	3 In Stock
12.70	31.80	29.81	MgF ₂ (400-700nm)	N-BK7	#49-858	A\$58.50 Volume Pricing	20+ In Stock
12.70	38.10	36.12	MgF ₂ (400-700nm)	N-BK7	#49-859	A\$58.50 Volume Pricing	20+ In Stock
12.70	40.00	38.48	MgF ₂ (400-700nm)	N-BK7	#38-246	A\$58.50 Volume Pricing	3 In Stock
12.70	44.50	42.69	MgF ₂ (400-700nm)	N-BK7	#49-860	A\$58.50 Volume Pricing	20+ In Stock

12.70	50.80	49.15	MgF ₂ (400-700nm)	N-BK7	#49-861	A\$58.50 Volume Pricing	20+ In Stock
12.70	100.00	98.88	MgF ₂ (400-700nm)	N-BK7	#38-247	A\$58.50 Volume Pricing	20+ In Stock
15.00	15.00	11.71	MgF ₂ (400-700nm)	N-SF5	#45-094	A\$61.80 Volume Pricing	Contact Us
15.00	18.00	15.61	MgF ₂ (400-700nm)	N-SF5	#49-888	A\$61.80 Volume Pricing	20+ In Stock
15.00	20.00	17.74	MgF ₂ (400-700nm)	N-SF5	#63-493	A\$61.80 Volume Pricing	20+ In Stock
15.00	22.50	20.50	MgF ₂ (400-700nm)	N-SF5	#32-005	A\$61.80 Volume Pricing	20+ In Stock
15.00	25.00	22.50	MgF ₂ (400-700nm)	N-BK7	#38-248	A\$60.15 Volume Pricing	1 In Stock
15.00	30.00	27.90	MgF ₂ (400-700nm)	N-BK7	#31-856	A\$60.15 Volume Pricing	20+ In Stock
15.00	40.00	38.02	MgF ₂ (400-700nm)	N-BK7	#45-096	A\$60.15 Volume Pricing	20+ In Stock
15.00	45.00	43.35	MgF ₂ (400-700nm)	N-BK7	#49-889	A\$60.15 Volume Pricing	20+ In Stock
15.00	50.00	48.35	MgF ₂ (400-700nm)	N-BK7	#38-249	A\$60.15 Volume Pricing	20+ In Stock
15.00	60.00	58.65	MgF ₂ (400-700nm)	N-BK7	#45-436	A\$60.15 Volume Pricing	10 In Stock
15.00	75.00	73.79	MgF ₂ (400-700nm)	N-BK7	#45-359	A\$60.15 Volume Pricing	20+ In Stock
15.00	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#45-260	A\$60.15 Volume Pricing	7 In Stock

15.00	200.00	197.89	MgF ₂ (400-700nm)	N-BK7	#14-375	A\$60.15 Volume Pricing	Contact Us
15.00	250.00	248.02	MgF ₂ (400-700nm)	N-BK7	#14-383	A\$60.15 Volume Pricing	6 In Stock
#45-438 Clearance							
 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
18.00	18.00	11.20	MgF ₂ (400-700nm)	N-BK7		A\$34.53	20+ In Stock
18.00	18.00	15.20	MgF ₂ (400-700nm)	N-SF11	#48-424	A\$62.62 Volume Pricing	13 In Stock
18.00	20.00	17.59	MgF ₂ (400-700nm)	N-SF11	#38-250	A\$61.80 Volume Pricing	1 In Stock
18.00	22.50	20.26	MgF ₂ (400-700nm)	N-SF11	#49-890	A\$61.80 Volume Pricing	20+ In Stock
18.00	25.00	21.51	MgF ₂ (400-700nm)	N-BK7	#38-251	A\$61.80 Volume Pricing	4 In Stock
18.00	27.00	24.73	MgF ₂ (400-700nm)	N-SF5	#32-002	A\$61.80 Volume Pricing	20+ In Stock
18.00	30.00	27.10	MgF ₂ (400-700nm)	N-BK7	#38-252	A\$59.33 Volume Pricing	5 In Stock

18.00	36.00	33.65	MgF ₂ (400-700nm)	N-BK7	#31-857	A\$59.33 Volume Pricing	20+ In Stock
18.00	50.00	48.09	MgF ₂ (400-700nm)	N-BK7	#38-253	A\$59.33 Volume Pricing	4 In Stock
18.00	54.00	52.02	MgF ₂ (400-700nm)	N-BK7	#45-307	A\$59.33 Volume Pricing	20+ In Stock
18.00	72.00	70.05	MgF ₂ (400-700nm)	N-BK7	#32-860	A\$59.33 Volume Pricing	6 In Stock
20.00	20.00	17.42	MgF ₂ (400-700nm)	N-SF11	#45-238	A\$63.45 Volume Pricing	20+ In Stock
20.00	25.00	22.76	MgF ₂ (400-700nm)	N-SF11	#49-891	A\$62.62 Volume Pricing	20+ In Stock
20.00	30.00	27.30	MgF ₂ (400-700nm)	N-BAF10	#45-240	A\$62.62 Volume Pricing	20+ In Stock
20.00	35.00	32.04	MgF ₂ (400-700nm)	N-BK7	#49-892	A\$62.62 Volume Pricing	20+ In Stock
20.00	40.00	36.77	MgF ₂ (400-700nm)	N-BK7	#32-961	A\$60.15 Volume Pricing	20+ In Stock
20.00	50.00	47.87	MgF ₂ (400-700nm)	N-BK7	#45-361	A\$60.15 Volume Pricing	20+ In Stock
20.00	60.00	57.03	MgF ₂ (400-700nm)	N-BK7	#32-963	A\$60.15 Volume Pricing	20+ In Stock
20.00	70.00	68.03	MgF ₂ (400-700nm)	N-BK7	#32-937	A\$60.15 Volume Pricing	5 In Stock
20.00	80.00	78.45	MgF ₂ (400-700nm)	N-BK7	#45-440	A\$60.15 Volume Pricing	20+ In Stock
20.00	100.00	97.13	MgF ₂ (400-700nm)	N-BK7	#32-476	A\$60.15 Volume Pricing	Contact Us

20.00	150.00	148.02	MgF ₂ (400-700nm)	N-BK7	#45-277	A\$60.15 Volume Pricing	11 In Stock
25.00	25.00	20.22	MgF ₂ (400-700nm)	N-SF5	#45-098	A\$63.45 Volume Pricing	20+ In Stock
25.00	30.00	24.69	MgF ₂ (400-700nm)	N-BK7	#45-363	A\$63.45 Volume Pricing	20+ In Stock
25.00	35.00	30.42	MgF ₂ (400-700nm)	N-BK7	#45-146	A\$63.45 Volume Pricing	20+ In Stock
25.00	40.00	36.31	MgF ₂ (400-700nm)	N-BK7	#45-279	A\$63.45 Volume Pricing	20+ In Stock
25.00	50.00	46.75	MgF ₂ (400-700nm)	N-BK7	#32-478	A\$60.15 Volume Pricing	20+ In Stock
25.00	60.00	56.90	MgF ₂ (400-700nm)	N-BK7	#45-128	A\$60.15 Volume Pricing	20+ In Stock
25.00	75.00	72.00	MgF ₂ (400-700nm)	N-BK7	#32-480	A\$60.15 Volume Pricing	20+ In Stock
25.00	85.00	82.17	MgF ₂ (400-700nm)	N-BK7	#45-365	A\$60.15 Volume Pricing	20+ In Stock
25.00	100.00	97.17	MgF ₂ (400-700nm)	N-BK7	#32-482	A\$60.15 Volume Pricing	20+ In Stock
25.00	125.00	122.70	MgF ₂ (400-700nm)	N-BK7	#32-862	A\$60.15 Volume Pricing	17 In Stock
25.00	150.00	147.81	MgF ₂ (400-700nm)	N-BK7	#32-864	A\$60.15 Volume Pricing	7 In Stock
25.00	175.00	172.85	MgF ₂ (400-700nm)	N-BK7	#32-866	A\$60.15 Volume Pricing	Contact Us
25.00	200.00	197.89	MgF ₂ (400-700nm)	N-BK7	#33-359	A\$60.15 Volume Pricing	7 In Stock

25.00	250.00	248.02	MgF ₂ (400-700nm)	N-BK7	#67-158	A\$60.15 Volume Pricing	5 In Stock
25.00	300.00	298.02	MgF ₂ (400-700nm)	N-BK7	#67-159	A\$60.15 Volume Pricing	17 In Stock
25.00	400.00	397.89	MgF ₂ (400-700nm)	N-BK7	#33-365	A\$60.15 Volume Pricing	4 In Stock
25.00	500.00	497.89	MgF ₂ (400-700nm)	N-BK7	#45-281	A\$60.15 Volume Pricing	20+ In Stock
25.00	750.00	747.89	MgF ₂ (400-700nm)	N-BK7	#45-283	A\$60.15 Volume Pricing	Contact Us
25.40	25.40	21.48	MgF ₂ (400-700nm)	N-SF11	#49-862	A\$63.45 Volume Pricing	20+ In Stock
25.40	35.00	30.46	MgF ₂ (400-700nm)	N-BK7	#38-254	A\$63.45 Volume Pricing	9 In Stock
25.40	38.10	33.48	MgF ₂ (400-700nm)	N-BK7	#49-863	A\$63.45 Volume Pricing	14 In Stock
25.40	40.00	36.11	MgF ₂ (400-700nm)	N-BK7	#38-255	A\$63.45 Volume Pricing	4 In Stock
25.40	50.80	47.50	MgF ₂ (400-700nm)	N-BK7	#49-864	A\$60.15 Volume Pricing	20+ In Stock
25.40	63.50	60.37	MgF ₂ (400-700nm)	N-BK7	#49-865	A\$60.15 Volume Pricing	20+ In Stock
25.40	75.00	72.69	MgF ₂ (400-700nm)	N-BK7	#38-262	A\$60.15 Volume Pricing	4 In Stock
25.40	76.20	73.56	MgF ₂ (400-700nm)	N-BK7	#49-866	A\$60.15 Volume Pricing	20+ In Stock
25.40	88.90	86.26	MgF ₂ (400-700nm)	N-BK7	#49-867	A\$60.15 Volume Pricing	20+ In Stock

25.40	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#38-264	A\$60.15 Volume Pricing	2 In Stock
25.40	101.60	98.97	MgF ₂ (400-700nm)	N-BK7	#49-868	A\$60.15 Volume Pricing	Contact Us
25.40	125.00	123.02	MgF ₂ (400-700nm)	N-BK7	#38-265	A\$60.15 Volume Pricing	3 In Stock
25.40	150.00	148.02	MgF ₂ (400-700nm)	N-BK7	#38-266	A\$60.15 Volume Pricing	20+ In Stock
30.00	30.00	26.13	MgF ₂ (400-700nm)	N-SF11	#48-656	A\$82.81 Volume Pricing	20+ In Stock
30.00	40.00	37.20	MgF ₂ (400-700nm)	N-SF11	#67-160	A\$80.34 Volume Pricing	14 In Stock
30.00	50.00	46.17	MgF ₂ (400-700nm)	N-SF5	#32-484	A\$80.34 Volume Pricing	20+ In Stock
30.00	60.00	56.03	MgF ₂ (400-700nm)	N-BK7	#45-242	A\$77.87 Volume Pricing	20+ In Stock
30.00	75.00	70.95	MgF ₂ (400-700nm)	N-BK7	#32-486	A\$77.87 Volume Pricing	20+ In Stock
30.00	100.00	96.01	MgF ₂ (400-700nm)	N-BK7	#32-488	A\$77.87 Volume Pricing	20+ In Stock
30.00	120.00	116.04	MgF ₂ (400-700nm)	N-BK7	#45-244	A\$77.87 Volume Pricing	10 In Stock
35.00	35.00	30.52	MgF ₂ (400-700nm)	N-SF11	#38-267	A\$85.70 Volume Pricing	4 In Stock
35.00	50.00	44.40	MgF ₂ (400-700nm)	N-BK7	#38-268	A\$82.81 Volume Pricing	5 In Stock
35.00	70.00	66.04	MgF ₂ (400-700nm)	N-BK7	#38-269	A\$82.81 Volume Pricing	20+ In Stock

35.00	100.00	97.03	MgF ₂ (400-700nm)	N-BK7	#38-270	A\$82.81 Volume Pricing	2 In Stock
40.00	40.00	35.13	MgF ₂ (400-700nm)	N-SF11	#48-657	A\$89.82 Volume Pricing	20+ In Stock
40.00	60.00	53.90	MgF ₂ (400-700nm)	N-BK7	#45-150	A\$89.82 Volume Pricing	16 In Stock
40.00	80.00	74.73	MgF ₂ (400-700nm)	N-BK7	#33-383	A\$88.17 Volume Pricing	20+ In Stock
40.00	100.00	95.39	MgF ₂ (400-700nm)	N-BK7	#33-371	A\$88.17 Volume Pricing	20+ In Stock
40.00	200.00	196.7	MgF ₂ (400-700nm)	N-BK7	#33-377	A\$88.17 Volume Pricing	5 In Stock
40.00	300.00	296.70	MgF ₂ (400-700nm)	N-BK7	#45-285	A\$88.17 Volume Pricing	20+ In Stock
40.00	400.00	396.70	MgF ₂ (400-700nm)	N-BK7	#45-287	A\$88.17 Volume Pricing	13 In Stock
50.00	50.00	43.28	MgF ₂ (400-700nm)	N-SF11	#32-971	A\$98.06 Volume Pricing	20+ In Stock
50.00	75.00	67.75	MgF ₂ (400-700nm)	N-BK7	#45-246	A\$94.76 Volume Pricing	20+ In Stock
50.00	100.00	93.41	MgF ₂ (400-700nm)	N-BK7	#32-973	A\$90.64 Volume Pricing	20+ In Stock
50.00	125.00	118.39	MgF ₂ (400-700nm)	N-BK7	#45-248	A\$90.64 Volume Pricing	9 In Stock
50.00	150.00	144.07	MgF ₂ (400-700nm)	N-BK7	#32-975	A\$90.64 Volume Pricing	20+ In Stock
50.00	175.00	169.05	MgF ₂ (400-700nm)	N-BK7	#45-250	A\$90.64 Volume Pricing	12 In Stock

50.00	200.00	196.66	MgF ₂ (400-700nm)	N-BK7	#45-152	A\$90.64 Volume Pricing	3 In Stock
50.00	250.00	246.74	MgF ₂ (400-700nm)	N-BK7	#45-154	A\$90.64 Volume Pricing	20+ In Stock
50.00	500.00	496.70	MgF ₂ (400-700nm)	N-BK7	#45-289	A\$90.64 Volume Pricing	20+ In Stock
50.80	50.81	44.08	MgF ₂ (400-700nm)	N-SF11	#71-335	A\$98.06 Volume Pricing	5 In Stock
50.80	76.20	68.95	MgF ₂ (400-700nm)	N-BK7	#71-342	A\$94.76 Volume Pricing	2 In Stock
75.00	75.00	53.49	MgF ₂ (400-700nm)	N-BK7	#45-368	A\$163.98 Volume Pricing	7 In Stock
75.00	100.00	87.57	MgF ₂ (400-700nm)	N-BK7	#71-840	A\$160.68 Volume Pricing	4 In Stock
75.00	125.00	115.99	MgF ₂ (400-700nm)	N-BK7	#71-841	A\$160.68 Volume Pricing	2 In Stock
75.00	150.00	142.45	MgF ₂ (400-700nm)	N-BK7	#45-370	A\$160.68 Volume Pricing	13 In Stock
75.00	175.00	168.68	MgF ₂ (400-700nm)	N-BK7	#71-842	A\$160.68 Volume Pricing	2 In Stock
75.00	200.00	194.24	MgF ₂ (400-700nm)	N-BK7	#45-372	A\$160.68 Volume Pricing	1 In Stock
75.00	250.00	244.73	MgF ₂ (400-700nm)	N-BK7	#63-495	A\$160.68 Volume Pricing	20+ In Stock
75.00	300.00	294.4	MgF ₂ (400-700nm)	N-BK7	#71-843	A\$160.68 Volume Pricing	5 In Stock
75.00	400.00	394.4	MgF ₂ (400-700nm)	N-BK7	#71-844	A\$160.68 Volume Pricing	2 In Stock

75.00	500.00	494.73	MgF ₂ (400-700nm)	N-BK7	#63-496	A\$160.68 Volume Pricing	20+ In Stock
75.00	750.00	745.35	MgF ₂ (400-700nm)	N-BK7	#71-845	A\$160.68 Volume Pricing	5 In Stock
100.00	200.00	190.77	MgF ₂ (400-700nm)	N-BK7	#17-900	A\$510.88 Volume Pricing	Contact Us
150.00	300.00	285.50	MgF ₂ (400-700nm)	N-BK7	#17-916	A\$939.36 Volume Pricing	Contact Us
200.00	400.00	381.54	MgF ₂ (400-700nm)	N-BK7	#17-932	A\$1,763.36 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com