

Transmission Gratings



- Low Polarization Sensitivity
- Ideal for In-Line Configurations



Common Specifications



Physical & Mechanical Properties

Clear Aperture (%):	90	Construction:	Blazed (Ruled) Grating
Thickness (mm):	3.00 ±0.5	Alignment of Grooves to Edge (°):	±0.5

Optical Properties

Wavelength Range (nm):	400 - 700	Substrate:	B270
Wavelength:	VIS		

Technical Information

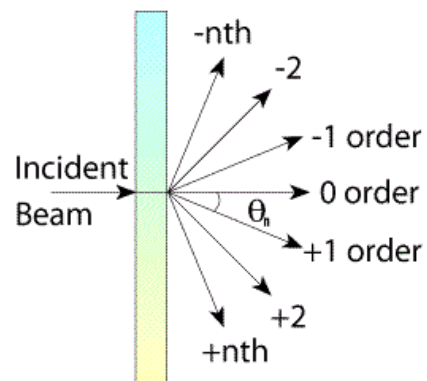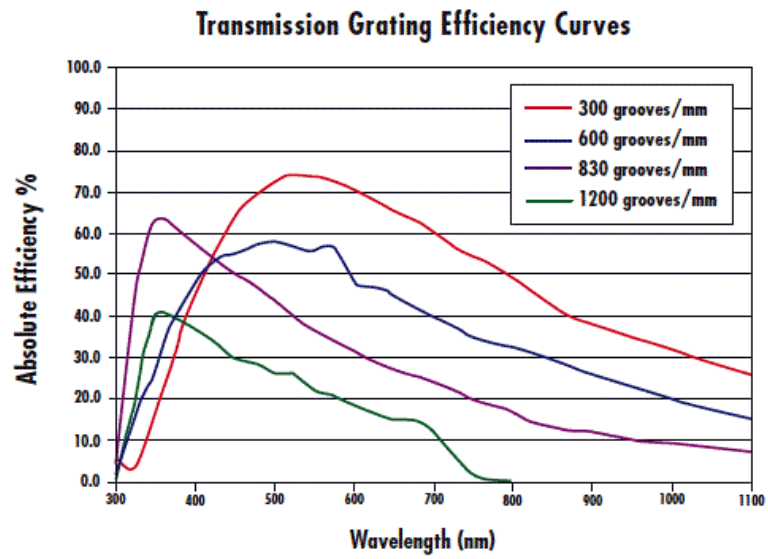

Products

Dimensions (mm)	Groove Angle (°)	Groove Density (grooves/mm)	Wavelength Range (nm)	Stock Number	Price	Buy
12.70 x 12.70	17.5	300	400 - 700	#49-575	A\$168.10 Volume Pricing	7 In Stock
25.00 x 25.00	17.5	300	400 - 700	#49-579	A\$201.06 Volume Pricing	8 In Stock
50.00 x 50.00	17.5	300	400 - 700	#49-583	A\$379.04 Volume Pricing	5 In Stock
12.70 x 12.70	28.7	600	400 - 700	#49-576	A\$168.10 Volume Pricing	6 In Stock
25.00 x 25.00	28.7	600	400 - 700	#49-580	A\$201.06 Volume Pricing	1 In Stock
50.00 x 50.00	28.7	600	400 - 700	#49-584	A\$379.04 Volume Pricing	2 In Stock
12.70 x 12.70	29.9	830	400 - 700	#49-577	A\$168.10 Volume Pricing	1 In Stock
25.00 x 25.00	29.9	830	400 - 700	#49-581	A\$201.06 Volume Pricing	5 In Stock
50.00 x 50.00	29.9	830	400 - 700	#49-585	A\$379.04 Volume Pricing	Contact Us
12.70 x 12.70	36.9	1200	400 - 700	#49-578	A\$168.10 Volume Pricing	6 In Stock
25.00 x 25.00	36.9	1200	400 - 700	#49-582	A\$201.06 Volume Pricing	Contact Us
50.00 x 50.00	36.9	1200	400 - 700	#49-586	A\$379.04 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com