


[All Products](#) / [Test Targets](#) / [Distortion Test Targets](#)

Diffuse Reflectance Grid Distortion Targets

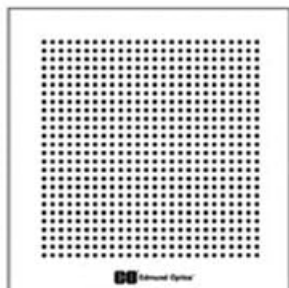

- Diffuse Reflectance Treatment Mimics Ceramic Targets
- Chrome Pattern on Substrate
- No Glare with On or Off Axis Lighting
- Perfect for Front Illuminated Measuring

Common Specifications

General

NIST Certification:	No
---------------------	----

Physical & Mechanical Properties

Thickness (mm):	2.00 ±0.2
-----------------	-----------

Center to Center Spacing Tolerance (μm):	± 1
--	-----

Dot Diameter Tolerance (μm):	±3
---------------------------------	----

Optical Properties

Coating:	Low Reflective Chrome
----------	-----------------------

Substrate:	Float Glass
------------	-------------

Technical Information

Products

Title	Stock Number	Price	Buy
2" x 2" 0.0625mm Dot, Low Reflect Grid Distortion Target	#62-949	A\$1,170.08 Volume Pricing	7 In Stock
2" x 2" 0.125mm Dot, Low Reflect Grid Distortion Target	#62-950	A\$1,128.88 Volume Pricing	6 In Stock
2" x 2" 0.25mm Dot, Low Reflect Grid Distortion Target	#62-951	A\$1,095.92 Volume Pricing	3 In Stock
3" x 3" 0.125mm Dot, Low Reflect Grid Distortion Target	#62-952	A\$1,409.04 Volume Pricing	3 In Stock
3" x 3" 0.25mm Dot, Low Reflect Grid Distortion Target	#62-953	A\$1,343.12 Volume Pricing	Contact Us
3" x 3" 0.5mm Dot, Low Reflect Grid Distortion Target	#62-954	A\$1,293.68 Volume Pricing	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com