

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters



- Ideal for Life Sciences or Chemical Analysis
- Available in UV, VIS, and IR Center Wavelengths
- Feature High Performance Hard Coatings
- Hard Coated OD 4.0 [5nm](#), [25nm](#), and [50nm](#) Bandpass Filters Also Available

Common Specifications

Physical & Mechanical Properties



Construction:	Mounted in Black Anodized Ring	Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2
---------------	--------------------------------	----------------------	--


Optical Properties			
Angle of Incidence (°):	0	Optical Density OD (Average):	≥4.0
Full Width-Half Max FWHM (nm):	10.00 ±2.0	Full Width-Half Max FWHM Tolerance (nm):	±2.0
Coating:	Hard Coated	Surface Quality:	80-50

Threading & Mounting	
Mount Thickness (mm):	5.0 ±0.1

Environmental & Durability Factors	
Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7


Technical Information

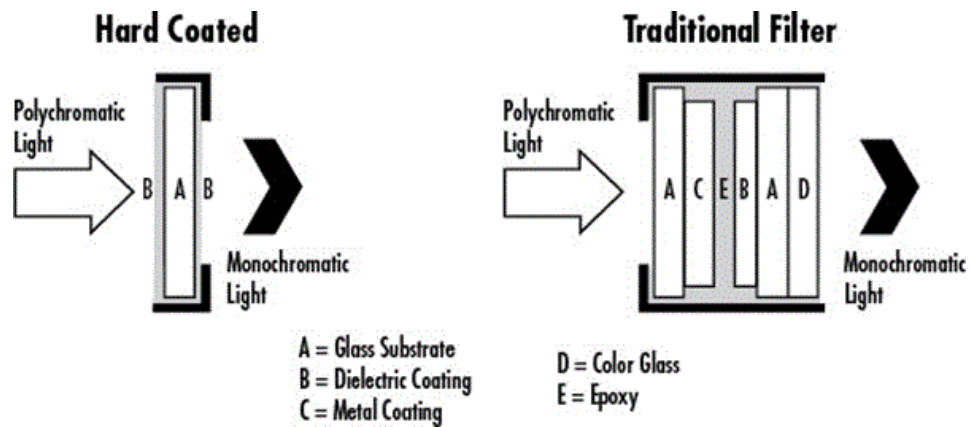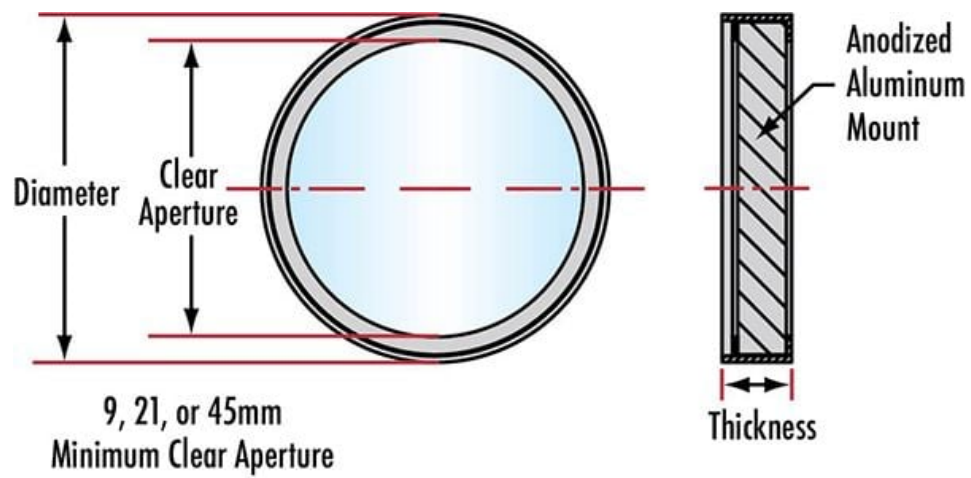

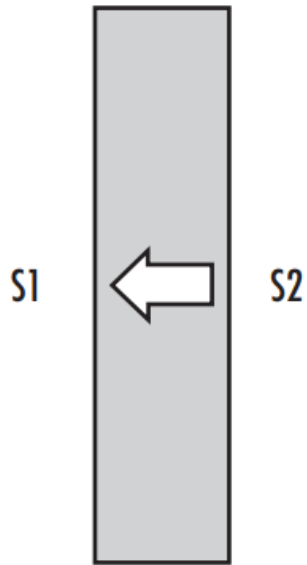


All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.


TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters UV

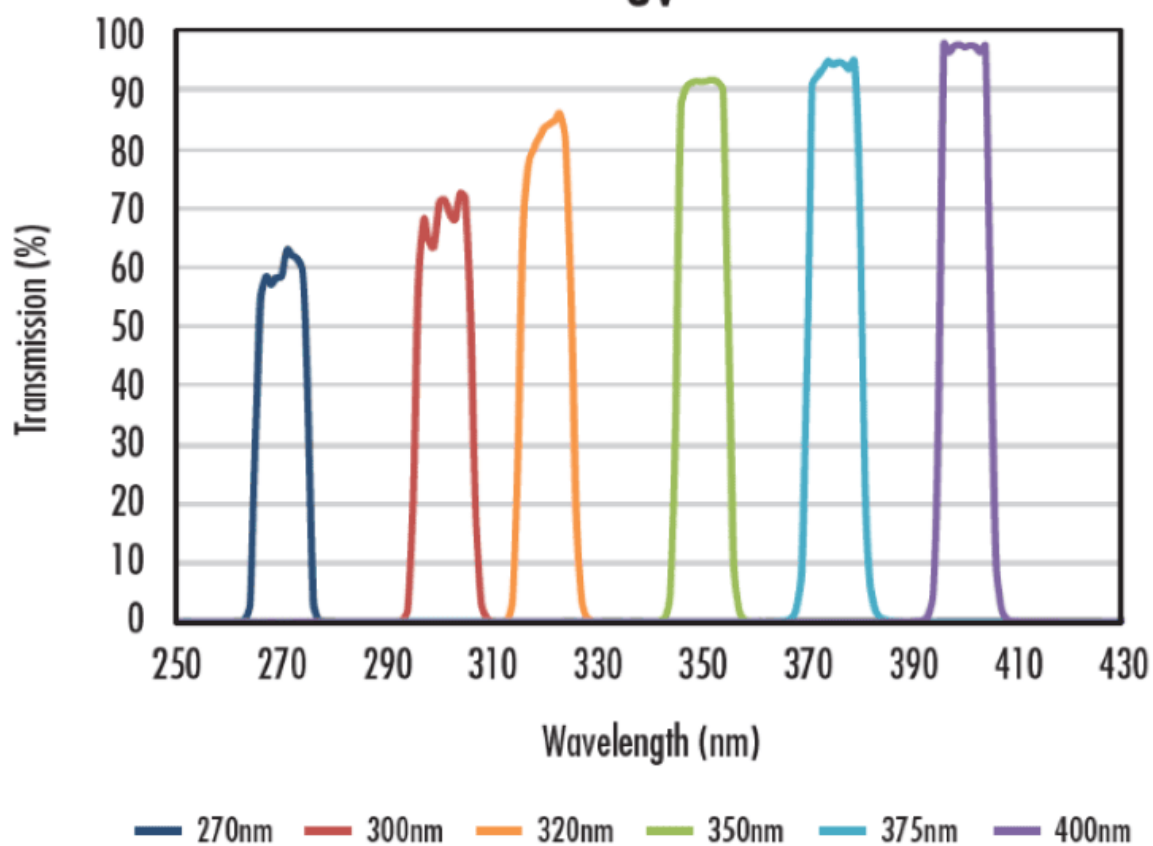

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters
VIS

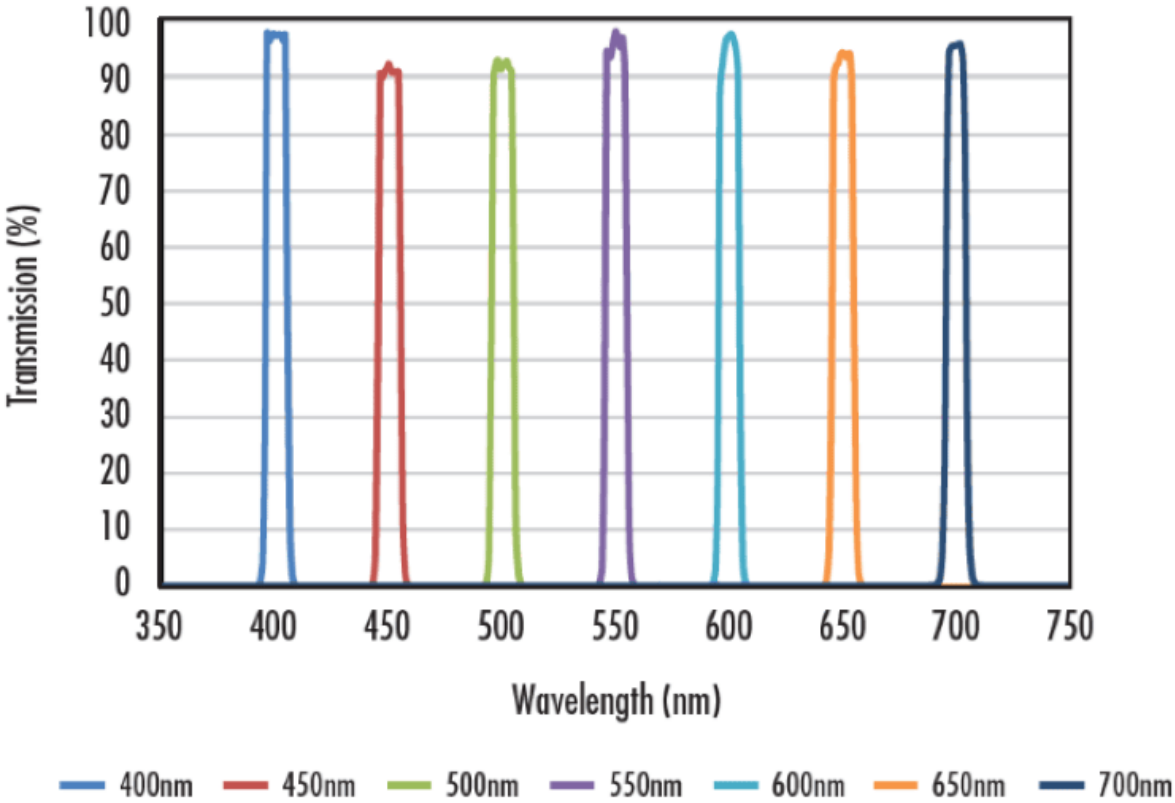

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters IR

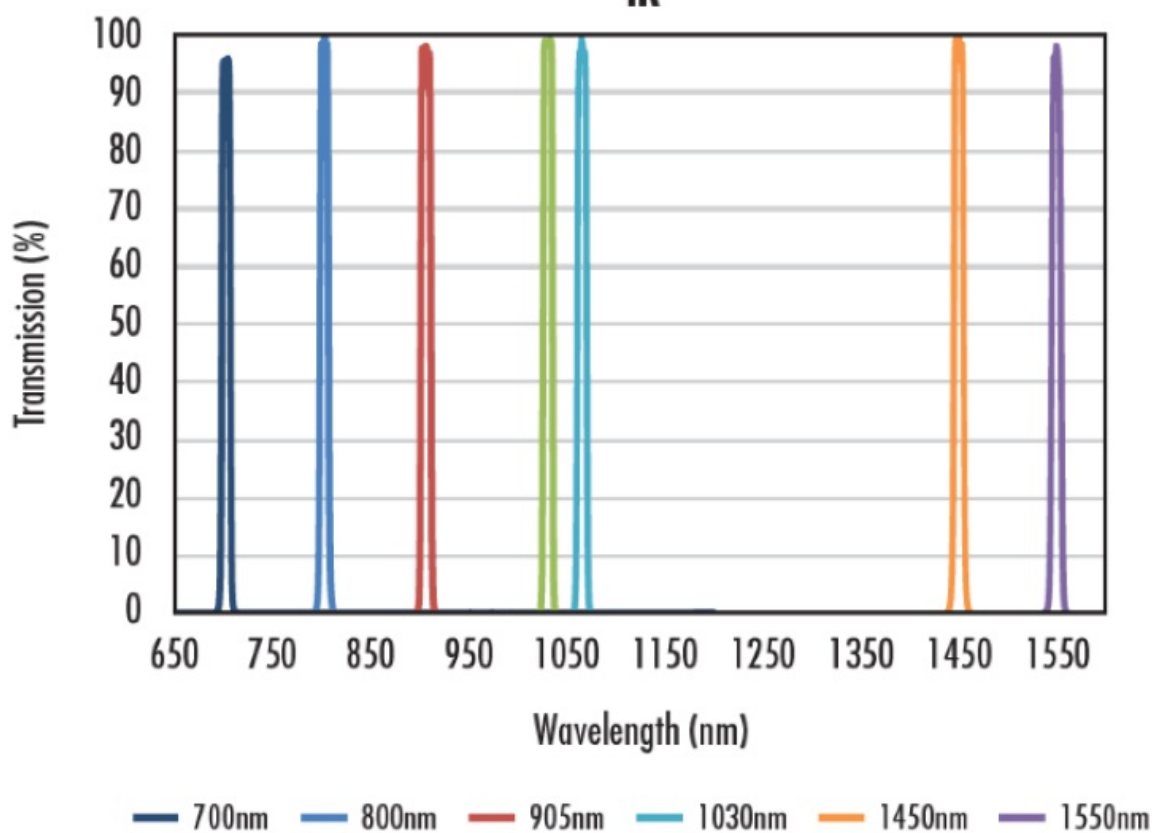

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Stock Number	Price	Buy
12.50	250.00	10.00	>50	200 - 650	#35-871	A\$342.78 Volume Pricing	6 In Stock
25.00	250.00	10.00	>50	200 - 650	#35-878	A\$515.82 Volume Pricing	3 In Stock
50.00	250.00	10.00	>50	200 - 650	#35-885	A\$1,232.70 Volume Pricing	4 In Stock
12.50	254.00	10.00	≥50	200 - 650	#39-305	A\$342.78 Volume Pricing	5 In Stock
25.00	254.00	10.00	≥50	200 - 650	#39-312	A\$515.82 Volume Pricing	5 In Stock
50.00	254.00	10.00	≥50	200 - 650	#39-319	A\$1,232.70 Volume Pricing	1 In Stock
12.50	260.00	10.00	>50	200 - 650	#35-872	A\$342.78 Volume Pricing	5 In Stock
25.00	260.00	10.00	>50	200 - 650	#35-879	A\$515.82 Volume Pricing	14 In Stock
12.50	266.00	10.00	≥50	200 - 650	#39-306	A\$342.78 Volume Pricing	8 In Stock
25.00	266.00	10.00	≥50	200 - 650	#39-313	A\$515.82 Volume Pricing	8 In Stock
50.00	266.00	10.00	≥50	200 - 650	#39-320	A\$1,232.70 Volume Pricing	Contact Us
12.50	270.00	10.00	>60	200 - 650	#35-873	A\$342.78 Volume Pricing	20+ In Stock
25.00	270.00	10.00	>60	200 - 650	#35-880	A\$515.82 Volume Pricing	1 In Stock
50.00	270.00	10.00	>60	200 - 650	#35-887	A\$1,232.70 Volume Pricing	1 In Stock
12.50	280.00	10.00	>60	200 - 650	#35-874	A\$342.78 Volume Pricing	14 In Stock
25.00	280.00	10.00	>60	200 - 650	#35-881	A\$515.82 Volume Pricing	14 In Stock
50.00	280.00	10.00	>60	200 - 650	#35-888	A\$1,232.70 Volume Pricing	1 In Stock

12.50	285.00	10.00	>65	200 - 650	#35-875	A\$342.78 Volume Pricing	3 In Stock
25.00	285.00	10.00	>65	200 - 650	#35-882	A\$515.82 Volume Pricing	20+ In Stock
50.00	285.00	10.00	>65	200 - 650	#35-889	A\$1,232.70 Volume Pricing	1 In Stock
12.50	290.00	10.00	>70	200 - 700	#35-876	A\$342.78 Volume Pricing	5 In Stock
25.00	290.00	10.00	>70	200 - 700	#35-883	A\$515.82 Volume Pricing	8 In Stock
50.00	290.00	10.00	>70	200 - 700	#35-890	A\$1,232.70 Volume Pricing	5 In Stock
12.50	300.00	10.00	>65	200 - 700	#35-877	A\$342.78 Volume Pricing	3 In Stock
25.00	300.00	10.00	>65	200 - 700	#35-884	A\$515.82 Volume Pricing	14 In Stock
50.00	300.00	10.00	>65	200 - 700	#35-891	A\$1,232.70 Volume Pricing	1 In Stock
12.50	310.00	10.00	≥70	200 - 1200	#34-972	A\$311.47 Volume Pricing	11 In Stock
25.00	310.00	10.00	≥70	200 - 1200	#34-976	A\$451.55 Volume Pricing	1 In Stock
50.00	310.00	10.00	≥70	200 - 1200	#34-980	A\$1,071.20 Volume Pricing	5 In Stock
12.50	313.00	10.00	≥75	200 - 1200	#34-973	A\$311.47 Volume Pricing	2 In Stock
25.00	313.00	10.00	≥75	200 - 1200	#34-977	A\$451.55 Volume Pricing	20+ In Stock
50.00	313.00	10.00	≥75	200 - 1200	#34-981	A\$1,071.20 Volume Pricing	5 In Stock
12.50	320.00	10.00	≥75	200 - 1200	#34-974	A\$311.47 Volume Pricing	20+ In Stock
25.00	320.00	10.00	≥75	200 - 1200	#34-978	A\$451.55 Volume Pricing	5 In Stock
50.00	320.00	10.00	≥75	200 - 1200	#34-982	A\$1,071.20 Volume Pricing	1 In Stock
12.50	330.00	10.00	≥75	200 - 1200	#34-975	A\$311.47 Volume Pricing	3 In Stock
25.00	330.00	10.00	≥75	200 - 1200	#34-979	A\$451.55 Volume Pricing	2 In Stock

50.00	330.00	10.00	≥75	200 - 1200	#34-983	A\$1,071.20 Volume Pricing	11 In Stock
12.50	337.00	10.00	≥85	200 - 1200	#65-067	A\$311.47 Volume Pricing	10 In Stock
25.00	337.00	10.00	≥85	200 - 1200	#65-128	A\$451.55 Volume Pricing	5 In Stock
50.00	337.00	10.00	≥85	200 - 1200	#65-189	A\$1,071.20 Volume Pricing	4 In Stock
12.50	340.00	10.00	≥85	200 - 1200	#65-068	A\$311.47 Volume Pricing	20+ In Stock
25.00	340.00	10.00	≥85	200 - 1200	#65-129	A\$451.55 Volume Pricing	3 In Stock
50.00	340.00	10.00	≥85	200 - 1200	#65-190	A\$1,071.20 Volume Pricing	1 In Stock
12.50	343.00	10.00	≥85	200 - 1200	#39-307	A\$311.47 Volume Pricing	14 In Stock
25.00	343.00	10.00	≥85	200 - 1200	#39-314	A\$451.55 Volume Pricing	2 In Stock
50.00	343.00	10.00	≥85	200 - 1200	#39-321	A\$1,071.20 Volume Pricing	1 In Stock
12.50	350.00	10.00	>50	200 - 1200	#39-183	A\$311.47 Volume Pricing	5 In Stock
25.00	350.00	10.00	>50	200 - 1200	#39-184	A\$451.55 Volume Pricing	2 In Stock
50.00	350.00	10.00	>50	200 - 1200	#39-185	A\$1,071.20 Volume Pricing	3 In Stock
12.50	355.00	10.00	≥85	200 - 1200	#34-490	A\$311.47 Volume Pricing	1 In Stock
25.00	355.00	10.00	≥85	200 - 1200	#34-491	A\$451.55 Volume Pricing	4 In Stock
50.00	355.00	10.00	≥85	200 - 1200	#34-492	A\$1,071.20 Volume Pricing	8 In Stock
12.50	365.00	10.00	≥85	200 - 1200	#65-069	A\$311.47 Volume Pricing	5 In Stock
25.00	365.00	10.00	≥85	200 - 1200	#65-130	A\$451.55 Volume Pricing	6 In Stock
50.00	365.00	10.00	≥85	200 - 1200	#65-191	A\$1,071.20 Volume Pricing	3 In Stock
12.50	372.00	10.00	≥85	200 - 1200	#12-147	A\$311.47 Volume Pricing	20+ In Stock

25.00	372.00	10.00	≥85	200 - 1200	#12-151	A\$451.55 Volume Pricing	20+ In Stock
50.00	372.00	10.00	≥85	200 - 1200	#12-155	A\$1,071.20 Volume Pricing	1 In Stock
12.50	375.00	10.00	≥85	200 - 1200	#86-732	A\$311.47 Volume Pricing	10 In Stock
25.00	375.00	10.00	≥85	200 - 1200	#86-736	A\$451.55 Volume Pricing	2 In Stock
50.00	375.00	10.00	≥85	200 - 1200	#86-740	A\$1,071.20 Volume Pricing	1 In Stock
12.50	394.00	10.00	≥85	200 - 1200	#65-070	A\$311.47 Volume Pricing	20+ In Stock
25.00	394.00	10.00	≥85	200 - 1200	#65-131	A\$451.55 Volume Pricing	3 In Stock
50.00	394.00	10.00	≥85	200 - 1200	#65-192	A\$1,071.20 Volume Pricing	6 In Stock
12.50	400.00	10.00	≥85	200 - 1200	#65-071	A\$283.46 Volume Pricing	5 In Stock
25.00	400.00	10.00	≥85	200 - 1200	#65-132	A\$423.54 Volume Pricing	2 In Stock
50.00	400.00	10.00	≥85	200 - 1200	#65-193	A\$1,025.06 Volume Pricing	5 In Stock
12.50	405.00	10.00	≥85	200 - 1200	#65-072	A\$283.46 Volume Pricing	20+ In Stock
25.00	405.00	10.00	≥85	200 - 1200	#65-133	A\$423.54 Volume Pricing	20+ In Stock
50.00	405.00	10.00	≥85	200 - 1200	#65-194	A\$1,025.06 Volume Pricing	6 In Stock
12.50	413.00	10.00	≥85	200 - 1200	#34-493	A\$283.46 Volume Pricing	10 In Stock
25.00	413.00	10.00	≥85	200 - 1200	#34-494	A\$423.54 Volume Pricing	20+ In Stock
50.00	413.00	10.00	≥85	200 - 1200	#34-495	A\$1,025.06 Volume Pricing	8 In Stock
12.50	420.00	10.00	≥85	200 - 1200	#65-075	A\$283.46 Volume Pricing	4 In Stock
25.00	420.00	10.00	≥85	200 - 1200	#65-136	A\$423.54 Volume Pricing	20+ In Stock
50.00	420.00	10.00	≥85	200 - 1200	#65-197	A\$1,025.06 Volume Pricing	12 In Stock

12.50	422.00	10.00	≥85	200 - 1200	#34-496	A\$283.46 Volume Pricing	5 In Stock
25.00	422.00	10.00	≥85	200 - 1200	#34-497	A\$423.54 Volume Pricing	5 In Stock
50.00	422.00	10.00	≥85	200 - 1200	#34-498	A\$1,025.06 Volume Pricing	10 In Stock
12.50	430.00	10.00	≥85	200 - 1200	#65-076	A\$283.46 Volume Pricing	10 In Stock
25.00	430.00	10.00	≥85	200 - 1200	#65-137	A\$423.54 Volume Pricing	4 In Stock
50.00	430.00	10.00	≥85	200 - 1200	#65-198	A\$1,025.06 Volume Pricing	1 In Stock
12.50	436.00	10.00	≥85	200 - 1200	#65-077	A\$283.46 Volume Pricing	12 In Stock
25.00	436.00	10.00	≥85	200 - 1200	#65-138	A\$423.54 Volume Pricing	2 In Stock
50.00	436.00	10.00	≥85	200 - 1200	#65-199	A\$1,025.06 Volume Pricing	7 In Stock
12.50	440.00	10.00	>85	200 - 1200	#88-567	A\$283.46 Volume Pricing	3 In Stock
25.00	440.00	10.00	>85	200 - 1200	#88-570	A\$423.54 Volume Pricing	16 In Stock
50.00	440.00	10.00	>85	200 - 1200	#88-573	A\$1,025.06 Volume Pricing	1 In Stock
12.50	442.00	10.00	≥85	200 - 1200	#65-078	A\$283.46 Volume Pricing	2 In Stock
25.00	442.00	10.00	≥85	200 - 1200	#65-139	A\$423.54 Volume Pricing	3 In Stock
50.00	442.00	10.00	≥85	200 - 1200	#65-200	A\$1,025.06 Volume Pricing	1 In Stock
12.50	445.00	10.00	≥85	200 - 1200	#34-499	A\$283.46 Volume Pricing	3 In Stock
25.00	445.00	10.00	≥85	200 - 1200	#34-500	A\$423.54 Volume Pricing	2 In Stock
50.00	445.00	10.00	≥85	200 - 1200	#34-501	A\$1,025.06 Volume Pricing	1 In Stock
12.50	450.00	10.00	≥85	200 - 1200	#65-079	A\$283.46 Volume Pricing	20+ In Stock
25.00	450.00	10.00	≥85	200 - 1200	#65-140	A\$423.54 Volume Pricing	6 In Stock

50.00	450.00	10.00	≥85	200 - 1200	#65-201	A\$1,025.06 Volume Pricing	6 In Stock
12.50	455.00	10.00	≥85	200 - 1200	#65-080	A\$283.46 Volume Pricing	20+ In Stock
25.00	455.00	10.00	≥85	200 - 1200	#65-141	A\$423.54 Volume Pricing	20+ In Stock
50.00	455.00	10.00	≥85	200 - 1200	#65-202	A\$1,025.06 Volume Pricing	3 In Stock
12.50	458.00	10.00	≥85	200 - 1200	#65-081	A\$283.46 Volume Pricing	16 In Stock
25.00	458.00	10.00	≥85	200 - 1200	#65-142	A\$423.54 Volume Pricing	1 In Stock
50.00	458.00	10.00	≥85	200 - 1200	#65-203	A\$1,025.06 Volume Pricing	3 In Stock
12.50	460.00	10.00	>85	200 - 1200	#87-886	A\$283.46 Volume Pricing	3 In Stock
25.00	460.00	10.00	>85	200 - 1200	#88-010	A\$423.54 Volume Pricing	14 In Stock
50.00	460.00	10.00	>85	200 - 1200	#88-016	A\$1,025.06 Volume Pricing	9 In Stock
12.50	467.00	10.00	≥85	200 - 1200	#39-308	A\$283.46 Volume Pricing	4 In Stock
25.00	467.00	10.00	≥85	200 - 1200	#39-315	A\$423.54 Volume Pricing	20+ In Stock
50.00	467.00	10.00	≥85	200 - 1200	#39-322	A\$1,025.06 Volume Pricing	2 In Stock
12.50	470.00	10.00	≥85	200 - 1200	#65-083	A\$283.46 Volume Pricing	20+ In Stock
25.00	470.00	10.00	≥85	200 - 1200	#65-144	A\$423.54 Volume Pricing	20+ In Stock
50.00	470.00	10.00	≥85	200 - 1200	#65-205	A\$1,025.06 Volume Pricing	1 In Stock
12.50	473.00	10.00	≥85	200 - 1200	#34-502	A\$283.46 Volume Pricing	2 In Stock
25.00	473.00	10.00	≥85	200 - 1200	#34-503	A\$423.54 Volume Pricing	5 In Stock
50.00	473.00	10.00	≥85	200 - 1200	#34-504	A\$1,025.06 Volume Pricing	11 In Stock
12.50	480.00	10.00	≥85	200 - 1200	#65-084	A\$283.46 Volume Pricing	20+ In Stock

25.00	480.00	10.00	≥85	200 - 1200	#65-145	A\$423.54 Volume Pricing	20+ In Stock
50.00	480.00	10.00	≥85	200 - 1200	#65-206	A\$1,025.06 Volume Pricing	1 In Stock
12.50	486.00	10.00	≥85	200 - 1200	#65-085	A\$283.46 Volume Pricing	3 In Stock
25.00	486.00	10.00	≥85	200 - 1200	#65-146	A\$423.54 Volume Pricing	13 In Stock
50.00	486.00	10.00	≥85	200 - 1200	#65-207	A\$1,025.06 Volume Pricing	5 In Stock
12.50	488.00	10.00	≥85	200 - 1200	#65-086	A\$283.46 Volume Pricing	1 In Stock
25.00	488.00	10.00	≥85	200 - 1200	#65-147	A\$423.54 Volume Pricing	6 In Stock
50.00	488.00	10.00	≥85	200 - 1200	#65-208	A\$1,025.06 Volume Pricing	5 In Stock
12.50	492.00	10.00	≥85	200 - 1200	#65-087	A\$283.46 Volume Pricing	9 In Stock
25.00	492.00	10.00	≥85	200 - 1200	#65-148	A\$423.54 Volume Pricing	2 In Stock
50.00	492.00	10.00	≥85	200 - 1200	#65-209	A\$1,025.06 Volume Pricing	6 In Stock
12.50	500.00	10.00	≥85	200 - 1200	#65-088	A\$283.46 Volume Pricing	20+ In Stock
25.00	500.00	10.00	≥85	200 - 1200	#65-149	A\$423.54 Volume Pricing	20+ In Stock
50.00	500.00	10.00	≥85	200 - 1200	#65-210	A\$1,025.06 Volume Pricing	3 In Stock
12.50	505.00	10.00	≥85	200 - 1200	#34-505	A\$283.46 Volume Pricing	7 In Stock
25.00	505.00	10.00	≥85	200 - 1200	#34-506	A\$423.54 Volume Pricing	3 In Stock
50.00	505.00	10.00	≥85	200 - 1200	#34-507	A\$1,025.06 Volume Pricing	5 In Stock
12.50	508.00	10.00	≥85	200 - 1200	#65-090	A\$283.46 Volume Pricing	20+ In Stock
25.00	508.00	10.00	≥85	200 - 1200	#65-151	A\$423.54 Volume Pricing	1 In Stock
12.50	510.00	10.00	≥85	200 - 1200	#65-091	A\$283.46 Volume Pricing	20+ In Stock

25.00	510.00	10.00	≥85	200 - 1200	#65-152	A\$423.54 Volume Pricing	1 In Stock
50.00	510.00	10.00	≥85	200 - 1200	#65-213	A\$1,025.06 Volume Pricing	1 In Stock
12.50	515.00	10.00	≥85	200 - 1200	#65-092	A\$283.46 Volume Pricing	2 In Stock
25.00	515.00	10.00	≥85	200 - 1200	#65-153	A\$423.54 Volume Pricing	5 In Stock
50.00	515.00	10.00	≥85	200 - 1200	#65-214	A\$1,025.06 Volume Pricing	Contact Us
12.50	520.00	10.00	≥85	200 - 1200	#65-093	A\$283.46 Volume Pricing	20+ In Stock
25.00	520.00	10.00	≥85	200 - 1200	#65-154	A\$423.54 Volume Pricing	5 In Stock
50.00	520.00	10.00	≥85	200 - 1200	#65-215	A\$1,025.06 Volume Pricing	4 In Stock
12.50	532.00	10.00	≥85	200 - 1200	#65-094	A\$283.46 Volume Pricing	20+ In Stock
25.00	532.00	10.00	≥85	200 - 1200	#65-155	A\$423.54 Volume Pricing	Contact Us
50.00	532.00	10.00	≥85	200 - 1200	#65-216	A\$1,025.06 Volume Pricing	6 In Stock
12.50	535.00	10.00	≥85	200 - 1200	#65-095	A\$283.46 Volume Pricing	3 In Stock
25.00	535.00	10.00	≥85	200 - 1200	#65-156	A\$423.54 Volume Pricing	8 In Stock
50.00	535.00	10.00	≥85	200 - 1200	#65-217	A\$1,025.06 Volume Pricing	3 In Stock
12.50	540.00	10.00	≥85	200 - 1200	#65-096	A\$283.46 Volume Pricing	20+ In Stock
25.00	540.00	10.00	≥85	200 - 1200	#65-157	A\$423.54 Volume Pricing	20+ In Stock
50.00	540.00	10.00	≥85	200 - 1200	#65-218	A\$1,025.06 Volume Pricing	8 In Stock
12.50	546.00	10.00	≥85	200 - 1200	#65-097	A\$283.46 Volume Pricing	8 In Stock
25.00	546.00	10.00	≥85	200 - 1200	#65-158	A\$423.54 Volume Pricing	16 In Stock
50.00	546.00	10.00	≥85	200 - 1200	#65-219	A\$1,025.06 Volume Pricing	5 In Stock

12.50	550.00	10.00	≥85	200 - 1200	#65-098	A\$283.46 Volume Pricing	20+ In Stock
25.00	550.00	10.00	≥85	200 - 1200	#65-159	A\$423.54 Volume Pricing	20+ In Stock
50.00	550.00	10.00	≥85	200 - 1200	#65-220	A\$1,025.06 Volume Pricing	4 In Stock
12.50	560.00	10.00	>85	200 - 1200	#87-887	A\$283.46 Volume Pricing	20+ In Stock
25.00	560.00	10.00	>85	200 - 1200	#88-011	A\$423.54 Volume Pricing	Contact Us
50.00	560.00	10.00	>85	200 - 1200	#88-017	A\$1,025.06 Volume Pricing	2 In Stock
12.50	561.00	10.00	≥85	200 - 1200	#12-148	A\$283.46 Volume Pricing	20+ In Stock
25.00	561.00	10.00	≥85	200 - 1200	#12-152	A\$423.54 Volume Pricing	3 In Stock
50.00	561.00	10.00	≥85	200 - 1200	#12-156	A\$1,025.06 Volume Pricing	2 In Stock
12.50	568.00	10.00	≥85	200 - 1200	#65-099	A\$283.46 Volume Pricing	20+ In Stock
25.00	568.00	10.00	≥85	200 - 1200	#65-160	A\$423.54 Volume Pricing	11 In Stock
50.00	568.00	10.00	≥85	200 - 1200	#65-221	A\$1,025.06 Volume Pricing	10 In Stock
12.50	580.00	10.00	≥85	200 - 1200	#65-100	A\$283.46 Volume Pricing	17 In Stock
25.00	580.00	10.00	≥85	200 - 1200	#65-161	A\$423.54 Volume Pricing	3 In Stock
50.00	580.00	10.00	≥85	200 - 1200	#65-222	A\$1,025.06 Volume Pricing	Contact Us
12.50	589.00	10.00	≥85	200 - 1200	#65-101	A\$283.46 Volume Pricing	20+ In Stock
25.00	589.00	10.00	≥85	200 - 1200	#65-162	A\$423.54 Volume Pricing	Contact Us
50.00	589.00	10.00	≥85	200 - 1200	#65-223	A\$1,025.06 Volume Pricing	2 In Stock
12.50	594.00	10.00	≥85	200 - 1200	#86-733	A\$283.46 Volume Pricing	Contact Us
25.00	594.00	10.00	≥85	200 - 1200	#86-737	A\$423.54 Volume Pricing	2 In Stock

50.00	594.00	10.00	≥85	200 - 1200	#86-741	A\$1,025.06 Volume Pricing	1 In Stock
12.50	600.00	10.00	≥85	200 - 1200	#65-102	A\$283.46 Volume Pricing	20+ In Stock
25.00	600.00	10.00	≥85	200 - 1200	#65-163	A\$423.54 Volume Pricing	20+ In Stock
50.00	600.00	10.00	≥85	200 - 1200	#65-224	A\$1,025.06 Volume Pricing	1 In Stock
12.50	610.00	10.00	≥85	200 - 1200	#65-103	A\$283.46 Volume Pricing	15 In Stock
25.00	610.00	10.00	≥85	200 - 1200	#65-164	A\$423.54 Volume Pricing	4 In Stock
50.00	610.00	10.00	≥85	200 - 1200	#65-225	A\$1,025.06 Volume Pricing	4 In Stock
12.50	620.00	10.00	≥85	200 - 1200	#65-104	A\$283.46 Volume Pricing	20+ In Stock
25.00	620.00	10.00	≥85	200 - 1200	#65-165	A\$423.54 Volume Pricing	12 In Stock
50.00	620.00	10.00	≥85	200 - 1200	#65-226	A\$1,025.06 Volume Pricing	15 In Stock
12.50	632.00	10.00	≥85	200 - 1200	#65-105	A\$283.46 Volume Pricing	3 In Stock
25.00	632.00	10.00	≥85	200 - 1200	#65-166	A\$423.54 Volume Pricing	8 In Stock
50.00	632.00	10.00	≥85	200 - 1200	#65-227	A\$1,025.06 Volume Pricing	Contact Us
12.50	636.00	10.00	≥85	200 - 1200	#65-106	A\$283.46 Volume Pricing	4 In Stock
25.00	636.00	10.00	≥85	200 - 1200	#65-167	A\$423.54 Volume Pricing	2 In Stock
50.00	636.00	10.00	≥85	200 - 1200	#65-228	A\$1,025.06 Volume Pricing	3 In Stock
12.50	640.00	10.00	≥85	200 - 1200	#65-107	A\$283.46 Volume Pricing	20+ In Stock
25.00	640.00	10.00	≥85	200 - 1200	#65-168	A\$423.54 Volume Pricing	20+ In Stock
50.00	640.00	10.00	≥85	200 - 1200	#65-229	A\$1,025.06 Volume Pricing	8 In Stock
12.50	647.00	10.00	≥85	200 - 1200	#65-108	A\$283.46 Volume Pricing	9 In Stock

25.00	647.00	10.00	≥85	200 - 1200	#65-169	A\$423.54 Volume Pricing	10 In Stock
50.00	647.00	10.00	≥85	200 - 1200	#65-230	A\$1,025.06 Volume Pricing	1 In Stock
12.50	650.00	10.00	≥85	200 - 1200	#65-109	A\$283.46 Volume Pricing	4 In Stock
25.00	650.00	10.00	≥85	200 - 1200	#65-170	A\$423.54 Volume Pricing	20+ In Stock
50.00	650.00	10.00	≥85	200 - 1200	#65-231	A\$1,025.06 Volume Pricing	4 In Stock
12.50	656.00	10.00	≥85	200 - 1200	#65-110	A\$283.46 Volume Pricing	20+ In Stock
25.00	656.00	10.00	≥85	200 - 1200	#65-171	A\$423.54 Volume Pricing	4 In Stock
50.00	656.00	10.00	≥85	200 - 1200	#65-232	A\$1,025.06 Volume Pricing	3 In Stock
12.50	660.00	10.00	≥85	200 - 1200	#86-086	A\$283.46 Volume Pricing	16 In Stock
25.00	660.00	10.00	≥85	200 - 1200	#86-089	A\$423.54 Volume Pricing	20+ In Stock
50.00	660.00	10.00	≥85	200 - 1200	#86-092	A\$1,025.06 Volume Pricing	6 In Stock
12.50	671.00	10.00	≥85	200 - 1200	#65-111	A\$283.46 Volume Pricing	8 In Stock
25.00	671.00	10.00	≥85	200 - 1200	#65-172	A\$423.54 Volume Pricing	6 In Stock
50.00	671.00	10.00	≥85	200 - 1200	#65-233	A\$1,025.06 Volume Pricing	3 In Stock
12.50	676.00	10.00	≥85	200 - 1200	#65-112	A\$283.46 Volume Pricing	11 In Stock
25.00	676.00	10.00	≥85	200 - 1200	#65-173	A\$423.54 Volume Pricing	5 In Stock
50.00	676.00	10.00	≥85	200 - 1200	#65-234	A\$1,025.06 Volume Pricing	Contact Us
12.50	680.00	10.00	>85	200 - 1200	#88-568	A\$283.46 Volume Pricing	2 In Stock
25.00	680.00	10.00	>85	200 - 1200	#88-571	A\$423.54 Volume Pricing	2 In Stock
50.00	680.00	10.00	>85	200 - 1200	#88-574	A\$1,025.06 Volume Pricing	1 In Stock

12.50	685.00	10.00	≥85	200 - 1200	#86-734	A\$283.46 Volume Pricing	9 In Stock
25.00	685.00	10.00	≥85	200 - 1200	#86-738	A\$423.54 Volume Pricing	15 In Stock
50.00	685.00	10.00	≥85	200 - 1200	#86-742	A\$1,025.06 Volume Pricing	5 In Stock
12.50	690.00	10.00	≥85	200 - 1200	#65-113	A\$283.46 Volume Pricing	2 In Stock
25.00	690.00	10.00	≥85	200 - 1200	#65-174	A\$423.54 Volume Pricing	20+ In Stock
50.00	690.00	10.00	≥85	200 - 1200	#65-235	A\$1,025.06 Volume Pricing	5 In Stock
12.50	694.00	10.00	≥85	200 - 1200	#65-114	A\$283.46 Volume Pricing	14 In Stock
25.00	694.00	10.00	≥85	200 - 1200	#65-175	A\$423.54 Volume Pricing	4 In Stock
50.00	694.00	10.00	≥85	200 - 1200	#65-236	A\$1,025.06 Volume Pricing	3 In Stock
12.50	700.00	10.00	>85	200 - 1200	#87-888	A\$311.47 Volume Pricing	20+ In Stock
25.00	700.00	10.00	>85	200 - 1200	#88-012	A\$451.55 Volume Pricing	20+ In Stock
50.00	700.00	10.00	>85	200 - 1200	#88-018	A\$1,071.20 Volume Pricing	7 In Stock
12.50	730.00	10.00	≥85	200 - 1200	#65-115	A\$311.47 Volume Pricing	20+ In Stock
25.00	730.00	10.00	≥85	200 - 1200	#65-176	A\$451.55 Volume Pricing	4 In Stock
50.00	730.00	10.00	≥85	200 - 1200	#65-237	A\$1,071.20 Volume Pricing	1 In Stock
12.50	750.00	10.00	>85	200 - 1200	#87-889	A\$311.47 Volume Pricing	20+ In Stock
25.00	750.00	10.00	>85	200 - 1200	#88-013	A\$451.55 Volume Pricing	1 In Stock
50.00	750.00	10.00	>85	200 - 1200	#88-019	A\$1,071.20 Volume Pricing	5 In Stock
12.50	752.00	10.00	≥85	200 - 1200	#12-149	A\$311.47 Volume Pricing	6 In Stock
25.00	752.00	10.00	≥85	200 - 1200	#12-153	A\$451.55 Volume Pricing	16 In Stock

50.00	752.00	10.00	≥85	200 - 1200	#12-157	A\$1,071.20 Volume Pricing	2 In Stock
12.50	766.00	10.00	≥85	200 - 1200	#65-116	A\$311.47 Volume Pricing	Contact Us
25.00	766.00	10.00	≥85	200 - 1200	#65-177	A\$451.55 Volume Pricing	20+ In Stock
50.00	766.00	10.00	≥85	200 - 1200	#65-238	A\$1,071.20 Volume Pricing	1 In Stock
12.50	770.00	10.00	>85	200 - 1200	#87-890	A\$311.47 Volume Pricing	1 In Stock
25.00	770.00	10.00	>85	200 - 1200	#88-014	A\$451.55 Volume Pricing	Contact Us
50.00	770.00	10.00	>85	200 - 1200	#88-020	A\$1,071.20 Volume Pricing	3 In Stock
12.50	780.00	10.00	≥85	200 - 1200	#65-117	A\$311.47 Volume Pricing	4 In Stock
25.00	780.00	10.00	≥85	200 - 1200	#65-178	A\$451.55 Volume Pricing	20+ In Stock
50.00	780.00	10.00	≥85	200 - 1200	#65-239	A\$1,071.20 Volume Pricing	11 In Stock
12.50	785.00	10.00	≥85	200 - 1200	#86-735	A\$311.47 Volume Pricing	20+ In Stock
25.00	785.00	10.00	≥85	200 - 1200	#86-739	A\$451.55 Volume Pricing	5 In Stock
50.00	785.00	10.00	≥85	200 - 1200	#86-743	A\$1,071.20 Volume Pricing	1 In Stock
12.50	800.00	10.00	≥85	200 - 1200	#65-118	A\$311.47 Volume Pricing	3 In Stock
25.00	800.00	10.00	≥85	200 - 1200	#65-179	A\$451.55 Volume Pricing	4 In Stock
50.00	800.00	10.00	≥85	200 - 1200	#65-240	A\$1,071.20 Volume Pricing	Contact Us
12.50	808.00	10.00	≥85	200 - 1200	#39-309	A\$311.47 Volume Pricing	20+ In Stock
25.00	808.00	10.00	≥85	200 - 1200	#39-316	A\$451.55 Volume Pricing	20+ In Stock
50.00	808.00	10.00	≥85	200 - 1200	#39-323	A\$1,071.20 Volume Pricing	13 In Stock
12.50	810.00	10.00	>85	200 - 1200	#87-891	A\$311.47 Volume Pricing	Contact Us

25.00	810.00	10.00	>85	200 - 1200	#88-015	A\$451.55 Volume Pricing	20+ In Stock
50.00	810.00	10.00	>85	200 - 1200	#88-021	A\$1,071.20 Volume Pricing	Contact Us
12.50	830.00	10.00	≥85	200 - 1200	#65-119	A\$311.47 Volume Pricing	20+ In Stock
25.00	830.00	10.00	≥85	200 - 1200	#65-180	A\$451.55 Volume Pricing	4 In Stock
50.00	830.00	10.00	≥85	200 - 1200	#65-241	A\$1,071.20 Volume Pricing	9 In Stock
12.50	850.00	10.00	≥85	200 - 1200	#86-087	A\$311.47 Volume Pricing	20+ In Stock
25.00	850.00	10.00	≥85	200 - 1200	#86-090	A\$451.55 Volume Pricing	20+ In Stock
50.00	850.00	10.00	≥85	200 - 1200	#86-093	A\$1,071.20 Volume Pricing	5 In Stock
12.50	852.00	10.00	≥85	200 - 1200	#65-120	A\$311.47 Volume Pricing	20+ In Stock
25.00	852.00	10.00	≥85	200 - 1200	#65-181	A\$451.55 Volume Pricing	14 In Stock
50.00	852.00	10.00	≥85	200 - 1200	#65-242	A\$1,071.20 Volume Pricing	5 In Stock
12.50	880.00	10.00	≥85	200 - 1200	#65-122	A\$311.47 Volume Pricing	Contact Us
25.00	880.00	10.00	≥85	200 - 1200	#65-183	A\$451.55 Volume Pricing	20+ In Stock
50.00	880.00	10.00	≥85	200 - 1200	#65-244	A\$1,071.20 Volume Pricing	1 In Stock
12.50	905.00	10.00	≥85	200 - 1200	#65-123	A\$311.47 Volume Pricing	20+ In Stock
25.00	905.00	10.00	≥85	200 - 1200	#65-184	A\$451.55 Volume Pricing	20+ In Stock
50.00	905.00	10.00	≥85	200 - 1200	#65-245	A\$1,071.20 Volume Pricing	4 In Stock
12.50	940.00	10.00	≥85	200 - 1200	#65-124	A\$311.47 Volume Pricing	20+ In Stock
25.00	940.00	10.00	≥85	200 - 1200	#65-185	A\$451.55 Volume Pricing	Contact Us
50.00	940.00	10.00	≥85	200 - 1200	#65-246	A\$1,071.20 Volume Pricing	11 In Stock

12.50	950.00	10.00	>85	200 - 1200	#88-569	A\$311.47 Volume Pricing	3 In Stock	
25.00	950.00	10.00	>85	200 - 1200	#88-572	A\$451.55 Volume Pricing	14 In Stock	
50.00	950.00	10.00	>85	200 - 1200	#88-575	A\$1,071.20 Volume Pricing	1 In Stock	
12.50	980.00	10.00	≥85	200 - 1200	#65-125	A\$311.47 Volume Pricing	20+ In Stock	
25.00	980.00	10.00	≥85	200 - 1200	#65-186	A\$451.55 Volume Pricing	17 In Stock	
50.00	980.00	10.00	≥85	200 - 1200	#65-247	A\$1,071.20 Volume Pricing	1 In Stock	
12.50	1,030.00	10.00	≥85	200 - 1200	#39-310	A\$311.47 Volume Pricing	3 In Stock	
25.00	1,030.00	10.00	≥85	200 - 1200	#39-317	A\$451.55 Volume Pricing	5 In Stock	
50.00	1,030.00	10.00	≥85	200 - 1200	#39-324	A\$1,071.20 Volume Pricing	20+ In Stock	
12.50	1,064.00	10.00	≥85	200 - 1200	#65-126	A\$311.47 Volume Pricing	4 In Stock	
25.00	1,064.00	10.00	≥85	200 - 1200	#65-187	A\$451.55 Volume Pricing	Contact Us	
50.00	1,064.00	10.00	≥85	200 - 1200	#65-248	A\$1,071.20 Volume Pricing	2 In Stock	
12.50	1,450.00	10.00	≥85	400 - 1800	#39-311	A\$367.50 Volume Pricing	1 In Stock	
25.00	1,450.00	10.00	≥85	400 - 1800	#39-318	A\$550.43 Volume Pricing	2 In Stock	
50.00	1,450.00	10.00	≥85	400 - 1800	#39-326	A\$1,311.81 Volume Pricing	Contact Us	
12.50	1,550.00	10.00	≥85	200 - 1800	#86-088	A\$367.50 Volume Pricing	20+ In Stock	
					200 - 1800	#86-091	A\$550.43 Volume Pricing	9 In Stock
Copyright © 2020 Edmund Optics Singapore Pte Ltd 1800 Woodlands Loop #04-00 Singapore 738100					200 - 1800	#86-091	A\$1,311.81 Volume Pricing	12 In Stock

Copyright © 2020 Edmund Optics Singapore Pte Ltd 1800 Woodlands Loop #04-00 Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com