

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Achromatic Lenses](#)
TECHSPEC® Plastic Hybrid Aspheric Lenses


- Color-Corrected Plastic Aspheres
- Diffractive Surface Minimizes Chromatic Aberration
- Low-Cost, Molded Design

Common Specifications

Physical & Mechanical Properties

Bevel: Protective as needed

Shape of Back Surface: Convex

Optical Properties

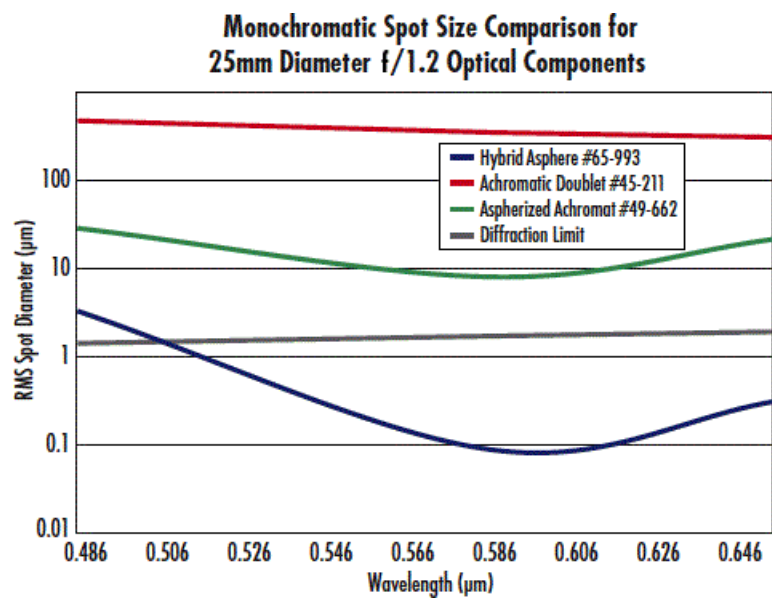
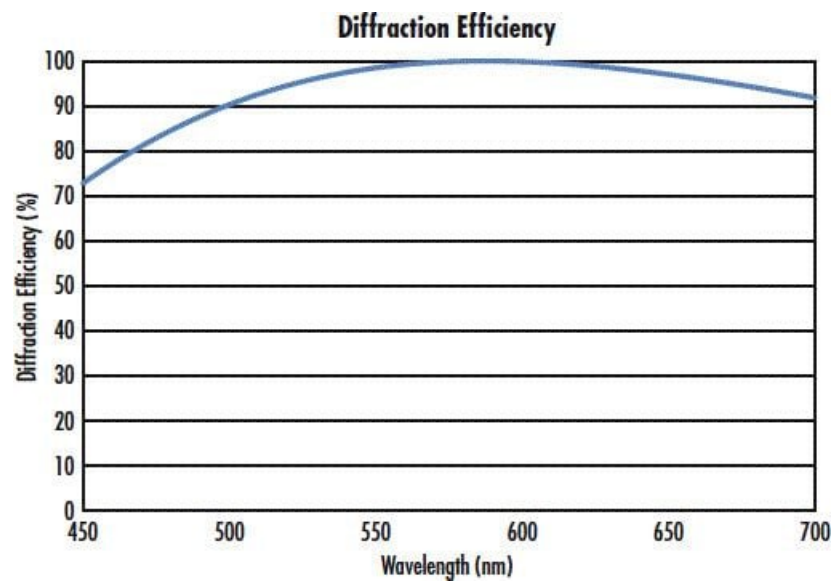
Aspheric Design Wavelength (nm): 587.6

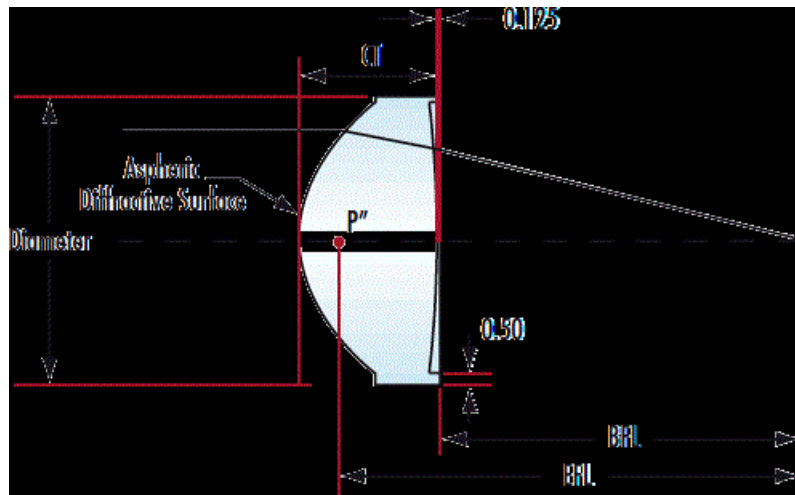
Conjugate Distance: Infinite

Environmental & Durability Factors



Operating Temperature (°C): -30 to +70

Technical Information





Products

Dia. (mm)	EFL (mm)	NA	Coating	Stock Number	Price	Buy
12.00	9.00	0.67	Uncoated	#21-222	A\$144.20 Volume Pricing	20+ In Stock
<hr/>						
				#65-986 Clearance		
						
				Clearance		
12.00	9.00	0.67	Uncoated	Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	A\$98.80	20+ In Stock
<hr/>						
				#65-987 Clearance		
						
				Clearance		
12.00	12.00	0.50	Uncoated	Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	A\$98.80	20+ In Stock
<hr/>						
12.00	15.00	0.40	Uncoated	#21-224	A\$144.20 Volume Pricing	20+ In Stock

[#65-988 Clearance](#)



Clearance

12.00 15.00 0.40 Uncoated

Availability is limited,
so buy before these
products disappear.
Sorry, we cannot
accept returns. Receive
up to 80% off select
products.

A\$98.80

20+ In Stock

25.00 20.00 0.63 Uncoated

[#21-225](#)

A\$144.20
[Volume Pricing](#)

20+ In Stock

[#65-991 Clearance](#)



Clearance

25.00 20.00 0.63 Uncoated

Availability is limited,
so buy before these
products disappear.
Sorry, we cannot
accept returns. Receive
up to 80% off select
products.

A\$98.80

20+ In Stock

25.00 30.00 0.42 Uncoated

[#21-226](#)

A\$144.20
[Volume Pricing](#)

20+ In Stock

[#65-993 Clearance](#)



Clearance

25.00 30.00 0.42 Uncoated

Availability is limited,
so buy before these
products disappear.
Sorry, we cannot
accept returns. Receive
up to 80% off select
products.

A\$98.80

20+ In Stock

12.00	9.00	0.67	BBAR (425-675nm)	#21-227	A\$169.74 Volume Pricing	20+ In Stock
-------	------	------	---------------------	-------------------------	---	--------------

[#65-998 Clearance](#)



Clearance

12.00	15.00	0.40	BBAR (425-675nm)	Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	A\$115.28	20+ In Stock
-------	-------	------	---------------------	--	-----------	--------------

12.00	15.00	0.40	BBAR (425-675nm)	#21-229	A\$169.74 Volume Pricing	20+ In Stock
-------	-------	------	---------------------	-------------------------	---	--------------

[#66-001 Clearance](#)



Clearance

25.00	20.00	0.63	BBAR (425-675nm)	Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	A\$115.28	20+ In Stock
-------	-------	------	---------------------	--	-----------	--------------

25.00	20.00	0.63	BBAR (425-675nm)	#21-230	A\$169.74 Volume Pricing	5 In Stock
-------	-------	------	---------------------	-------------------------	---	------------

[#66-003 Clearance](#)



Clearance

25.00	30.00	0.42	BBAR (425-675nm)	Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	A\$115.28	20+ In Stock
-------	-------	------	---------------------	--	-----------	--------------

25.00	30.00	0.42	BBAR (425-675nm)	#21-231	A\$169.74 Volume Pricing	4 In Stock
-------	-------	------	---------------------	-------------------------	---	------------



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com