

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [UV Lenses](#)

TECHSPEC® Laser Grade Plano-Convex (PCX) Lenses



- Guaranteed Laser Damage Threshold
- 10-5 Surface Quality
- $\lambda/10$ Surface Accuracy

Common Specifications

Physical & Mechanical Properties




Bevel: Protective as needed

Optical Properties


Substrate: [Fused Silica](#) (Corning 7980)

Power (P-V) @ 632.8nm: λ

Technical Information

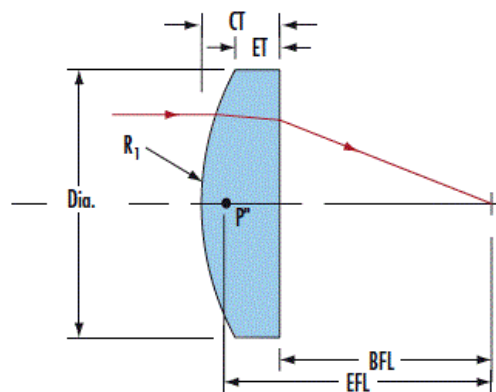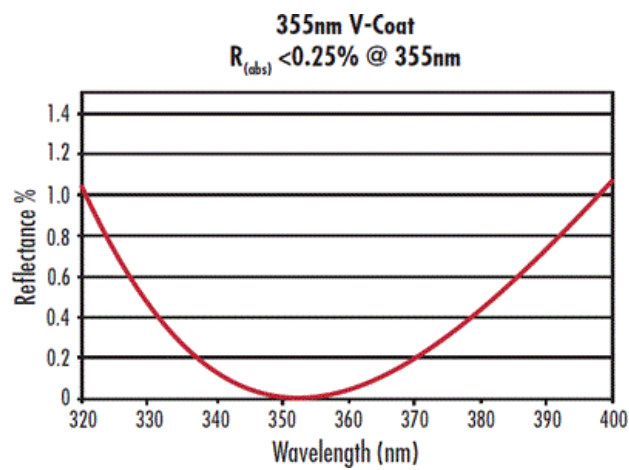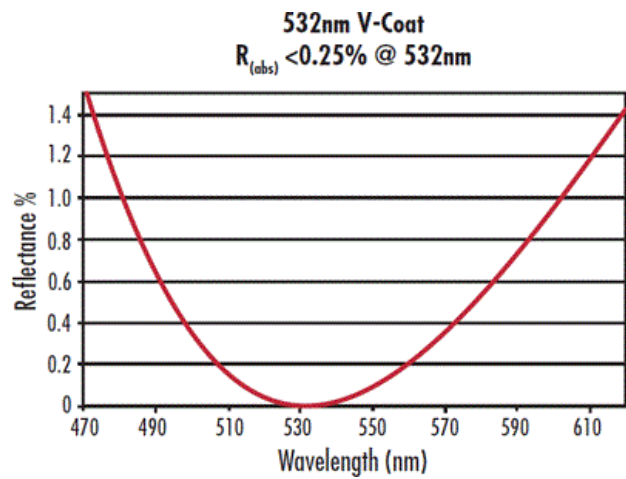

1064nm V-Coat
 $R_{(obs)} < 0.25\%$ @ 1064nm

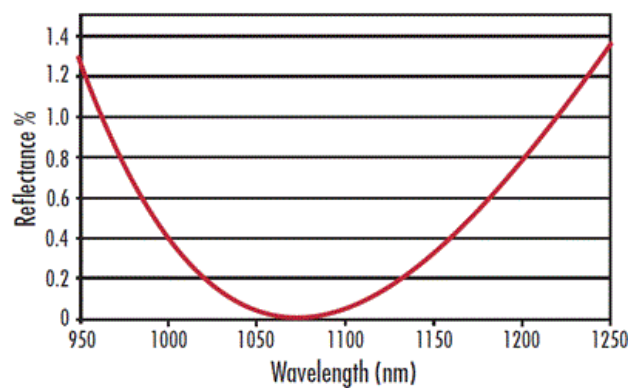

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	12.00	10.63	Uncoated	Fused Silica	#87-924	A\$229.07 Volume Pricing	20+ In Stock
6.00	12.00	10.63	Laser V-Coat (266nm)	Fused Silica	#87-928	A\$281.81 Volume Pricing	11 In Stock
6.00	12.00	10.63	Laser V-Coat (355nm)	Fused Silica	#87-932	A\$281.81 Volume Pricing	7 In Stock
6.00	12.00	10.63	Laser V-Coat (532nm)	Fused Silica	#87-936	A\$281.81 Volume Pricing	20+ In Stock
6.00	12.00	10.63	Laser V-Coat (1064nm)	Fused Silica	#87-940	A\$281.81 Volume Pricing	20+ In Stock
6.00	18.00	16.62	Uncoated	Fused Silica	#87-925	A\$229.07 Volume Pricing	20+ In Stock
6.00	18.00	16.62	Laser V-Coat (266nm)	Fused Silica	#87-929	A\$281.81 Volume Pricing	11 In Stock
6.00	18.00	16.62	Laser V-Coat (355nm)	Fused Silica	#87-933	A\$281.81 Volume Pricing	13 In Stock
6.00	18.00	16.62	Laser V-Coat (532nm)	Fused Silica	#87-937	A\$281.81 Volume Pricing	13 In Stock
6.00	18.00	16.62	Laser V-Coat (1064nm)	Fused Silica	#87-941	A\$281.81 Volume Pricing	5 In Stock
6.00	24.00	22.63	Uncoated	Fused Silica	#87-926	A\$229.07 Volume Pricing	20+ In Stock
6.00	24.00	22.63	Laser V-Coat (266nm)	Fused Silica	#87-930	A\$281.81 Volume Pricing	14 In Stock
6.00	24.00	22.63	Laser V-Coat (355nm)	Fused Silica	#87-934	A\$281.81 Volume Pricing	13 In Stock

6.00	24.00	22.63	Laser V-Coat (532nm)	Fused Silica	#87-938	A\$281.81 Volume Pricing	12 In Stock
6.00	24.00	22.63	Laser V-Coat (1064nm)	Fused Silica	#87-942	A\$281.81 Volume Pricing	5 In Stock
12.00	18.00	15.23	Uncoated	Fused Silica	#67-090	A\$245.55 Volume Pricing	5 In Stock
12.00	18.00	15.23	Laser V-Coat (266nm)	Fused Silica	#67-939	A\$309.82 Volume Pricing	6 In Stock
12.00	18.00	15.23	Laser V-Coat (355nm)	Fused Silica	#67-949	A\$309.82 Volume Pricing	7 In Stock
12.00	18.00	15.23	Laser V-Coat (532nm)	Fused Silica	#67-959	A\$309.82 Volume Pricing	7 In Stock
12.00	18.00	15.23	Laser V-Coat (1064nm)	Fused Silica	#67-969	A\$309.82 Volume Pricing	20+ In Stock
12.00	25.00	22.31	Uncoated	Fused Silica	#67-091	A\$245.55 Volume Pricing	20+ In Stock
12.00	25.00	22.31	Laser V-Coat (266nm)	Fused Silica	#67-940	A\$309.82 Volume Pricing	3 In Stock
12.00	25.00	22.31	Laser V-Coat (355nm)	Fused Silica	#67-950	A\$309.82 Volume Pricing	4 In Stock
12.00	25.00	22.31	Laser V-Coat (532nm)	Fused Silica	#67-960	A\$309.82 Volume Pricing	Contact Us
12.00	25.00	22.31	Laser V-Coat (1064nm)	Fused Silica	#67-970	A\$309.82 Volume Pricing	8 In Stock
12.00	36.00	34.29	Uncoated	Fused Silica	#67-092	A\$245.55 Volume Pricing	20+ In Stock
12.00	36.00	34.29	Laser V-Coat (266nm)	Fused Silica	#67-941	A\$309.82 Volume Pricing	8 In Stock
12.00	36.00	34.29	Laser V-Coat (355nm)	Fused Silica	#67-951	A\$309.82 Volume Pricing	1 In Stock

12.00	36.00	34.29	Laser V-Coat (532nm)	Fused Silica	#67-961	A\$309.82 Volume Pricing	3 In Stock
12.00	36.00	34.29	Laser V-Coat (1064nm)	Fused Silica	#67-971	A\$309.82 Volume Pricing	1 In Stock
12.00	50.00	48.01	Uncoated	Fused Silica	#67-093	A\$245.55 Volume Pricing	20+ In Stock
12.00	50.00	48.01	Laser V-Coat (266nm)	Fused Silica	#67-942	A\$309.82 Volume Pricing	9 In Stock
12.00	50.00	48.01	Laser V-Coat (355nm)	Fused Silica	#67-952	A\$309.82 Volume Pricing	3 In Stock
12.00	50.00	48.01	Laser V-Coat (532nm)	Fused Silica	#67-962	A\$309.82 Volume Pricing	8 In Stock
12.00	50.00	48.01	Laser V-Coat (1064nm)	Fused Silica	#67-972	A\$309.82 Volume Pricing	2 In Stock
12.70	25.00	21.62	Uncoated	Fused Silica	#38-634	A\$245.55 Volume Pricing	6 In Stock
12.70	25.00	21.62	Laser V-Coat (266nm)	Fused Silica	#38-656	A\$309.82 Volume Pricing	6 In Stock
12.70	25.00	21.62	Laser V-Coat (355nm)	Fused Silica	#38-681	A\$309.82 Volume Pricing	Contact Us
12.70	25.00	21.62	Laser V-Coat (532nm)	Fused Silica	#38-707	A\$309.82 Volume Pricing	3 In Stock
12.70	25.00	21.62	Laser V-Coat (1064nm)	Fused Silica	#38-733	A\$309.82 Volume Pricing	6 In Stock
12.70	35.00	32.30	Uncoated	Fused Silica	#38-635	A\$245.55 Volume Pricing	4 In Stock
12.70	35.00	32.30	Laser V-Coat (266nm)	Fused Silica	#38-658	A\$309.82 Volume Pricing	7 In Stock
12.70	35.00	32.30	Laser V-Coat (355nm)	Fused Silica	#38-684	A\$309.82 Volume Pricing	5 In Stock

12.70	35.00	32.30	Laser V-Coat (532nm)	Fused Silica	#38-708	A\$309.82 Volume Pricing	13 In Stock
12.70	35.00	32.30	Laser V-Coat (1064nm)	Fused Silica	#38-734	A\$309.82 Volume Pricing	2 In Stock
12.70	50.00	47.30	Uncoated	Fused Silica	#38-636	A\$245.55 Volume Pricing	14 In Stock
12.70	50.00	47.30	Laser V-Coat (266nm)	Fused Silica	#38-660	A\$309.82 Volume Pricing	5 In Stock
12.70	50.00	47.30	Laser V-Coat (355nm)	Fused Silica	#38-685	A\$309.82 Volume Pricing	3 In Stock
12.70	50.00	47.30	Laser V-Coat (532nm)	Fused Silica	#38-709	A\$309.82 Volume Pricing	20+ In Stock
12.70	50.00	47.30	Laser V-Coat (1064nm)	Fused Silica	#38-735	A\$309.82 Volume Pricing	2 In Stock
12.70	75.00	72.31	Uncoated	Fused Silica	#38-637	A\$245.55 Volume Pricing	20+ In Stock
12.70	75.00	72.31	Laser V-Coat (266nm)	Fused Silica	#38-661	A\$309.82 Volume Pricing	4 In Stock
12.70	75.00	72.31	Laser V-Coat (355nm)	Fused Silica	#38-686	A\$309.82 Volume Pricing	4 In Stock
12.70	75.00	72.31	Laser V-Coat (532nm)	Fused Silica	#38-711	A\$309.82 Volume Pricing	2 In Stock
12.70	75.00	72.31	Laser V-Coat (1064nm)	Fused Silica	#38-736	A\$309.82 Volume Pricing	16 In Stock
12.70	100.00	97.32	Uncoated	Fused Silica	#38-638	A\$245.55 Volume Pricing	6 In Stock
12.70	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-662	A\$309.82 Volume Pricing	3 In Stock
12.70	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-687	A\$309.82 Volume Pricing	6 In Stock

12.70	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-712	A\$309.82 Volume Pricing	5 In Stock
12.70	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-737	A\$309.82 Volume Pricing	5 In Stock
12.70	150.00	147.33	Uncoated	Fused Silica	#38-639	A\$245.55 Volume Pricing	20+ In Stock
12.70	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-665	A\$309.82 Volume Pricing	7 In Stock
12.70	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-688	A\$309.82 Volume Pricing	17 In Stock
12.70	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-715	A\$309.82 Volume Pricing	5 In Stock
12.70	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-738	A\$309.82 Volume Pricing	20+ In Stock
12.70	200.00	197.35	Uncoated	Fused Silica	#38-640	A\$245.55 Volume Pricing	20+ In Stock
12.70	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-666	A\$309.82 Volume Pricing	4 In Stock
12.70	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-689	A\$309.82 Volume Pricing	6 In Stock
12.70	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-716	A\$309.82 Volume Pricing	5 In Stock
12.70	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-739	A\$309.82 Volume Pricing	11 In Stock
12.70	250.00	247.36	Uncoated	Fused Silica	#38-641	A\$245.55 Volume Pricing	20+ In Stock
12.70	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-667	A\$309.82 Volume Pricing	3 In Stock
12.70	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-690	A\$309.82 Volume Pricing	5 In Stock

12.70	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-717	A\$309.82 Volume Pricing	4 In Stock
12.70	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-740	A\$309.82 Volume Pricing	6 In Stock
12.70	300.00	297.38	Uncoated	Fused Silica	#38-643	A\$245.55 Volume Pricing	20+ In Stock
12.70	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-668	A\$309.82 Volume Pricing	3 In Stock
12.70	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-691	A\$309.82 Volume Pricing	7 In Stock
12.70	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-718	A\$309.82 Volume Pricing	4 In Stock
12.70	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-741	A\$309.82 Volume Pricing	1 In Stock
12.70	500.00	497.44	Uncoated	Fused Silica	#38-644	A\$245.55 Volume Pricing	20+ In Stock
12.70	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-669	A\$309.82 Volume Pricing	3 In Stock
12.70	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-692	A\$309.82 Volume Pricing	9 In Stock
12.70	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-719	A\$309.82 Volume Pricing	14 In Stock
12.70	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-742	A\$309.82 Volume Pricing	3 In Stock
12.70	1,000.00	997.59	Uncoated	Fused Silica	#38-645	A\$245.55 Volume Pricing	20+ In Stock
12.70	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-670	A\$309.82 Volume Pricing	1 In Stock
12.70	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-693	A\$309.82 Volume Pricing	3 In Stock

12.70	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-720	A\$309.82 Volume Pricing	8 In Stock
12.70	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-743	A\$309.82 Volume Pricing	5 In Stock
25.00	38.00	33.03	Uncoated	Fused Silica	#67-094	A\$306.53 Volume Pricing	20+ In Stock
25.00	38.00	33.03	Laser V-Coat (266nm)	Fused Silica	#67-943	A\$344.43 Volume Pricing	17 In Stock
25.00	38.00	33.03	Laser V-Coat (355nm)	Fused Silica	#67-953	A\$344.43 Volume Pricing	8 In Stock
25.00	38.00	33.03	Laser V-Coat (532nm)	Fused Silica	#67-963	A\$344.43 Volume Pricing	5 In Stock
25.00	38.00	33.03	Laser V-Coat (1064nm)	Fused Silica	#67-973	A\$344.43 Volume Pricing	2 In Stock
25.00	50.00	46.00	Uncoated	Fused Silica	#67-095	A\$306.53 Volume Pricing	7 In Stock
25.00	50.00	46.00	Laser V-Coat (266nm)	Fused Silica	#67-944	A\$344.43 Volume Pricing	7 In Stock
25.00	50.00	46.00	Laser V-Coat (355nm)	Fused Silica	#67-954	A\$344.43 Volume Pricing	5 In Stock
25.00	50.00	46.00	Laser V-Coat (532nm)	Fused Silica	#67-964	A\$344.43 Volume Pricing	9 In Stock
25.00	50.00	46.00	Laser V-Coat (1064nm)	Fused Silica	#67-974	A\$344.43 Volume Pricing	6 In Stock
25.00	75.00	71.96	Uncoated	Fused Silica	#67-096	A\$306.53 Volume Pricing	13 In Stock
25.00	75.00	71.96	Laser V-Coat (266nm)	Fused Silica	#67-945	A\$344.43 Volume Pricing	Contact Us
25.00	75.00	71.96	Laser V-Coat (355nm)	Fused Silica	#67-955	A\$344.43 Volume Pricing	5 In Stock

25.00	75.00	71.96	Laser V-Coat (532nm)	Fused Silica	#67-965	A\$344.43 Volume Pricing	20+ In Stock
25.00	75.00	71.96	Laser V-Coat (1064nm)	Fused Silica	#67-975	A\$344.43 Volume Pricing	7 In Stock
25.00	100.00	97.40	Uncoated	Fused Silica	#67-097	A\$306.53 Volume Pricing	2 In Stock
25.00	100.00	97.4	Laser V-Coat (266nm)	Fused Silica	#67-946	A\$344.43 Volume Pricing	17 In Stock
25.00	100.00	97.40	Laser V-Coat (355nm)	Fused Silica	#67-956	A\$344.43 Volume Pricing	5 In Stock
25.00	100.00	97.40	Laser V-Coat (532nm)	Fused Silica	#67-966	A\$344.43 Volume Pricing	10 In Stock
25.00	100.00	97.40	Laser V-Coat (1064nm)	Fused Silica	#67-976	A\$344.43 Volume Pricing	9 In Stock
25.00	150.00	147.82	Uncoated	Fused Silica	#67-098	A\$306.53 Volume Pricing	20+ In Stock
25.00	150.00	147.86	Laser V-Coat (266nm)	Fused Silica	#67-947	A\$344.43 Volume Pricing	3 In Stock
25.00	150.00	147.82	Laser V-Coat (355nm)	Fused Silica	#67-957	A\$344.43 Volume Pricing	20+ In Stock
25.00	150.00	147.82	Laser V-Coat (532nm)	Fused Silica	#67-967	A\$344.43 Volume Pricing	Contact Us
25.00	150.00	147.82	Laser V-Coat (1064nm)	Fused Silica	#67-977	A\$344.43 Volume Pricing	Contact Us
25.00	250.00	248.14	Uncoated	Fused Silica	#67-099	A\$306.53 Volume Pricing	1 In Stock
25.00	250.00	248.14	Laser V-Coat (266nm)	Fused Silica	#67-948	A\$344.43 Volume Pricing	15 In Stock
25.00	250.00	248.14	Laser V-Coat (355nm)	Fused Silica	#67-958	A\$344.43 Volume Pricing	6 In Stock

25.00	250.00	248.14	Laser V-Coat (532nm)	Fused Silica	#67-968	A\$344.43 Volume Pricing	5 In Stock
25.00	250.00	248.14	Laser V-Coat (1064nm)	Fused Silica	#67-978	A\$344.43 Volume Pricing	6 In Stock
25.40	35.00	28.55	Uncoated	Fused Silica	#38-624	A\$306.53 Volume Pricing	9 In Stock
25.40	35.00	28.55	Laser V-Coat (266nm)	Fused Silica	#38-646	A\$344.43 Volume Pricing	7 In Stock
25.40	35.00	28.55	Laser V-Coat (355nm)	Fused Silica	#38-671	A\$344.43 Volume Pricing	16 In Stock
25.40	35.00	28.55	Laser V-Coat (532nm)	Fused Silica	#38-694	A\$344.43 Volume Pricing	1 In Stock
25.40	35.00	28.55	Laser V-Coat (1064nm)	Fused Silica	#38-721	A\$344.43 Volume Pricing	2 In Stock
25.40	50.00	45.71	Uncoated	Fused Silica	#38-625	A\$306.53 Volume Pricing	12 In Stock
25.40	50.00	45.71	Laser V-Coat (266nm)	Fused Silica	#38-647	A\$344.43 Volume Pricing	3 In Stock
25.40	50.00	45.71	Laser V-Coat (355nm)	Fused Silica	#38-672	A\$344.43 Volume Pricing	5 In Stock
25.40	50.00	45.71	Laser V-Coat (532nm)	Fused Silica	#38-695	A\$344.43 Volume Pricing	7 In Stock
25.40	50.00	45.71	Laser V-Coat (1064nm)	Fused Silica	#38-722	A\$344.43 Volume Pricing	3 In Stock
25.40	75.00	71.63	Uncoated	Fused Silica	#38-626	A\$306.53 Volume Pricing	6 In Stock
25.40	75.00	71.63	Laser V-Coat (266nm)	Fused Silica	#38-648	A\$344.43 Volume Pricing	5 In Stock
25.40	75.00	71.63	Laser V-Coat (355nm)	Fused Silica	#38-673	A\$344.43 Volume Pricing	4 In Stock

25.40	75.00	71.63	Laser V-Coat (532nm)	Fused Silica	#38-699	A\$344.43 Volume Pricing	4 In Stock
25.40	75.00	71.63	Laser V-Coat (1064nm)	Fused Silica	#38-723	A\$344.43 Volume Pricing	2 In Stock
25.40	100.00	97.32	Uncoated	Fused Silica	#38-627	A\$306.53 Volume Pricing	Contact Us
25.40	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-649	A\$344.43 Volume Pricing	Contact Us
25.40	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-674	A\$344.43 Volume Pricing	10 In Stock
25.40	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-700	A\$344.43 Volume Pricing	3 In Stock
25.40	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-724	A\$344.43 Volume Pricing	14 In Stock
25.40	150.00	147.33	Uncoated	Fused Silica	#38-628	A\$306.53 Volume Pricing	16 In Stock
25.40	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-650	A\$344.43 Volume Pricing	3 In Stock
25.40	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-675	A\$344.43 Volume Pricing	12 In Stock
25.40	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-701	A\$344.43 Volume Pricing	3 In Stock
25.40	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-725	A\$344.43 Volume Pricing	7 In Stock
25.40	200.00	197.35	Uncoated	Fused Silica	#38-629	A\$306.53 Volume Pricing	20+ In Stock
25.40	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-651	A\$344.43 Volume Pricing	4 In Stock
25.40	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-676	A\$344.43 Volume Pricing	9 In Stock

25.40	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-702	A\$344.43 Volume Pricing	10 In Stock
25.40	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-726	A\$344.43 Volume Pricing	Contact Us
25.40	250.00	247.36	Uncoated	Fused Silica	#38-630	A\$306.53 Volume Pricing	20+ In Stock
25.40	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-652	A\$344.43 Volume Pricing	4 In Stock
25.40	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-677	A\$344.43 Volume Pricing	7 In Stock
25.40	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-703	A\$344.43 Volume Pricing	7 In Stock
25.40	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-727	A\$344.43 Volume Pricing	2 In Stock
25.40	300.00	297.38	Uncoated	Fused Silica	#38-631	A\$306.53 Volume Pricing	20+ In Stock
25.40	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-653	A\$344.43 Volume Pricing	5 In Stock
25.40	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-678	A\$344.43 Volume Pricing	4 In Stock
25.40	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-704	A\$344.43 Volume Pricing	5 In Stock
25.40	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-729	A\$344.43 Volume Pricing	5 In Stock
25.40	500.00	497.44	Uncoated	Fused Silica	#38-632	A\$306.53 Volume Pricing	9 In Stock
25.40	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-654	A\$344.43 Volume Pricing	6 In Stock
25.40	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-679	A\$344.43 Volume Pricing	Contact Us

25.40	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-705	A\$344.43 Volume Pricing	3 In Stock
25.40	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-731	A\$344.43 Volume Pricing	6 In Stock
25.40	1,000.00	997.59	Uncoated	Fused Silica	#38-633	A\$306.53 Volume Pricing	20+ In Stock
25.40	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-655	A\$344.43 Volume Pricing	4 In Stock
25.40	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-680	A\$344.43 Volume Pricing	3 In Stock
25.40	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-706	A\$344.43 Volume Pricing	13 In Stock
25.40	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-732	A\$344.43 Volume Pricing	7 In Stock

[#70-003 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80	100.00	91.773	Uncoated	Fused Silica		A\$618.00 Volume Pricing	20+ In Stock
-------	--------	--------	----------	------------------------------	--	---	--------------

[#70-004 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144 Uncoated

[Fused Silica](#)

A\$618.00
[Volume Pricing](#)

20+ In Stock

[#70-005 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515 Uncoated

[Fused Silica](#)

A\$618.00
[Volume Pricing](#)

6 In Stock

[#70-006 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514 Uncoated

[Fused Silica](#)

A\$618.00
[Volume Pricing](#)

20+ In Stock

[#70-007 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516 Uncoated

[Fused Silica](#)

A\$618.00
[Volume Pricing](#)

15 In Stock

[#70-013 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

4 In Stock

50.80 100.00 91.773 Laser V-Coat (266nm) [Fused Silica](#)

[#70-014 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

4 In Stock

50.80 150.00 143.144 Laser V-Coat (266nm) [Fused Silica](#)

[#70-016 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

5 In Stock

50.80 250.00 244.514 Laser V-Coat (266nm)

[Fused Silica](#)

[#70-017 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

9 In Stock

50.80 300.00 294.516 Laser V-Coat (266nm)

[Fused Silica](#)

[#70-023 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

5 In Stock

50.80 100.00 91.773 Laser V-Coat (355nm) [Fused Silica](#)

[#70-024 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

5 In Stock

50.80 150.00 143.144 Laser V-Coat (355nm) [Fused Silica](#)

[#70-025 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

5 In Stock

50.80 200.00 194.515 Laser V-Coat (355nm) [Fused Silica](#)

[#70-026 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

5 In Stock

50.80 250.00 244.514 Laser V-Coat (355nm) [Fused Silica](#)

[#70-027 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

5 In Stock

50.80 300.00 294.516 Laser V-Coat (355nm)

[Fused Silica](#)

[#70-033 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

2 In Stock

50.80 100.00 91.773 Laser V-Coat (532nm)

[Fused Silica](#)

[#70-034 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144

Laser V-Coat (532nm)

[Fused Silica](#)

A\$652.61
[Volume Pricing](#)

1 In Stock

[#70-035 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515

Laser V-Coat (532nm)

[Fused Silica](#)

A\$652.61
[Volume Pricing](#)

13 In Stock

[#70-036 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514

Laser V-Coat (532nm)

[Fused Silica](#)

A\$652.61
[Volume Pricing](#)

1 In Stock

[#70-037 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516

Laser V-Coat (532nm)

[Fused Silica](#)

A\$652.61
[Volume Pricing](#)

7 In Stock

[#70-043 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 100.00 91.773

Laser V-Coat
(1064nm)

[Fused Silica](#)

A\$652.61
[Volume Pricing](#)

2 In Stock

[#70-044 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144

Laser V-Coat
(1064nm)

[Fused Silica](#)

A\$652.61
[Volume Pricing](#)

7 In Stock

#70-045 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

4 In Stock

50.80 200.00 194.515 Laser V-Coat (1064nm) [Fused Silica](#)

#70-046 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

A\$652.61
[Volume Pricing](#)

5 In Stock

50.80 200.00 194.515 Laser V-Coat (1064nm) [Fused Silica](#)



Edmund
optics | worldwide

Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com