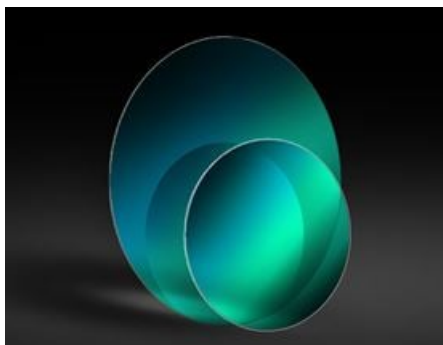


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)
TECHSPEC® Ultra-Thin N-BK7 Windows See More by [SCHOTT Optical Components](#)


- Ultra-Thin 0.20mm Thickness
- Precision N-BK7 Substrate
- Extremely Lightweight

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm²):	610.00	Parallelism (arcsec):	<30
Poisson's Ratio:	0.21	Young's Modulus (GPa):	82

Optical Properties

Abbe Number (v_d):	64.17	Index of Refraction (n_d):	1.516
Substrate:	N-BK7	Transmitted Wavefront, P-V:	$\lambda/2$

Material Properties

Density (g/cm³):	2.51
------------------------------------	------

Technical Information

Products

Dia. (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	0.20	Uncoated	#66-184	A\$171.20 Volume Pricing	20+ In Stock
10.00	0.20	Uncoated	#66-185	A\$171.20 Volume Pricing	20+ In Stock
12.50	0.20	Uncoated	#66-186	A\$171.20 Volume Pricing	20+ In Stock
20.00	0.20	Uncoated	#66-187	A\$171.20 Volume Pricing	20+ In Stock
25.00	0.20	Uncoated	#66-188	A\$204.80 Volume Pricing	20+ In Stock
30.00	0.20	Uncoated	#66-189	A\$246.40 Volume Pricing	20+ In Stock
40.00	0.20	Uncoated	#66-190	A\$260.80 Volume Pricing	20+ In Stock
50.00	0.20	Uncoated	#66-191	A\$328.00 Volume Pricing	20+ In Stock
5.00	0.20	MgF ₂ (400-700nm)	#66-192	A\$190.40 Volume Pricing	20+ In Stock
10.00	0.20	MgF ₂ (400-700nm)	#66-193	A\$190.40 Volume Pricing	20+ In Stock
12.50	0.20	MgF ₂ (400-700nm)	#66-194	A\$190.40 Volume Pricing	20+ In Stock
20.00	0.20	MgF ₂ (400-700nm)	#66-195	A\$190.40 Volume Pricing	15 In Stock
25.00	0.20	MgF ₂ (400-700nm)	#66-196	A\$222.40 Volume Pricing	20+ In Stock
30.00	0.20	MgF ₂ (400-700nm)	#66-197	A\$276.80 Volume Pricing	20+ In Stock
40.00	0.20	MgF ₂ (400-700nm)	#66-198	A\$291.20 Volume Pricing	20+ In Stock
50.00	0.20	MgF ₂ (400-700nm)	#66-199	A\$356.80 Volume Pricing	7 In Stock
5.00	0.20	VIS 0° (425-675nm)	#83-099	A\$208.00 Volume Pricing	20+ In Stock

10.00	0.20	VIS 0° (425-675nm)	#83-100	A\$208.00 Volume Pricing	7 In Stock
12.50	0.20	VIS 0° (425-675nm)	#83-101	A\$208.00 Volume Pricing	20+ In Stock
20.00	0.20	VIS 0° (425-675nm)	#83-102	A\$208.00 Volume Pricing	20+ In Stock
25.00	0.20	VIS 0° (425-675nm)	#83-103	A\$243.20 Volume Pricing	20+ In Stock
30.00	0.20	VIS 0° (425-675nm)	#83-104	A\$294.40 Volume Pricing	20+ In Stock
40.00	0.20	VIS 0° (425-675nm)	#83-105	A\$308.80 Volume Pricing	20+ In Stock
50.00	0.20	VIS 0° (425-675nm)	#83-106	A\$374.40 Volume Pricing	20+ In Stock
5.00	0.20	VIS-NIR (400-1000nm)	#22-036	A\$208.00 Volume Pricing	15 In Stock
10.00	0.20	VIS-NIR (400-1000nm)	#22-037	A\$208.00 Volume Pricing	9 In Stock
12.50	0.20	VIS-NIR (400-1000nm)	#22-038	A\$208.00 Volume Pricing	12 In Stock
20.00	0.20	VIS-NIR (400-1000nm)	#22-039	A\$208.00 Volume Pricing	4 In Stock
25.00	0.20	VIS-NIR (400-1000nm)	#22-040	A\$243.20 Volume Pricing	10 In Stock
30.00	0.20	VIS-NIR (400-1000nm)	#22-041	A\$294.40 Volume Pricing	3 In Stock
40.00	0.20	VIS-NIR (400-1000nm)	#22-042	A\$308.80 Volume Pricing	4 In Stock
50.00	0.20	VIS-NIR (400-1000nm)	#22-043	A\$374.40 Volume Pricing	Contact Us
5.00	0.20	NIR I (600-1050nm)	#22-044	A\$208.00 Volume Pricing	12 In Stock
10.00	0.20	NIR I (600-1050nm)	#22-045	A\$208.00 Volume Pricing	2 In Stock
12.50	0.20	NIR I (600-1050nm)	#22-046	A\$208.00 Volume Pricing	9 In Stock
20.00	0.20	NIR I (600-1050nm)	#22-047	A\$208.00 Volume Pricing	5 In Stock

25.00	0.20	NIR I (600-1050nm)	#22-048	A\$243.20 Volume Pricing	8 In Stock
30.00	0.20	NIR I (600-1050nm)	#22-049	A\$294.40 Volume Pricing	5 In Stock
40.00	0.20	NIR I (600-1050nm)	#22-050	A\$308.80 Volume Pricing	4 In Stock
50.00	0.20	NIR I (600-1050nm)	#22-051	A\$374.40 Volume Pricing	10 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com