


[All Products](#) / [Optics](#) / [Polarization Optics](#) / [Linear Polarizers](#) / [Crystalline Polarizers](#)

Rochon Polarizers

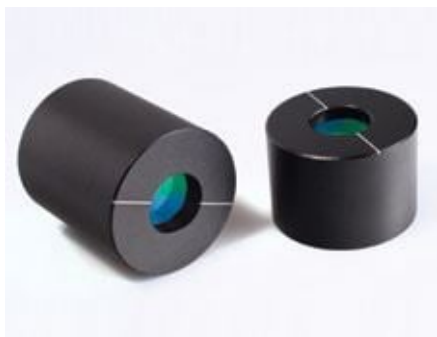

- Multiple Polarization Materials Available
- Ordinary Rays Pass Through Undeviated
- Extraordinary Rays Deviate
- [Wollaston Polarizers](#) Also Available

Common Specifications


Physical & Mechanical Properties

Clear Aperture CA (mm):	10.0	Diameter (mm):	25.40
Dimensional Tolerance (mm):	+0.0/-0.2	Construction:	Crystalline Rochon Polarizer
Length Tolerance (mm):	±0.1	Housing:	Black Anodized Aluminum

Optical Properties

Surface Quality:	20-10	Transmitted Wavefront, P-V:	$\lambda/4$ @ 632.8nm
Beam Deviation (arcmin):	<3	Damage Threshold, By Design:	10 J/cm ² @ 1064nm, 20ns

Technical Information

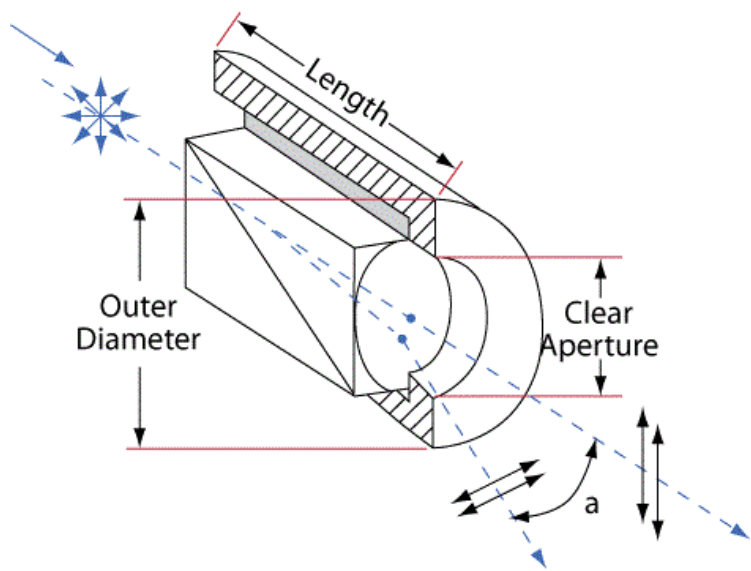

Products

Wavelength Range (nm)	Extinction Ratio	Substrate	CA (mm)	Length (mm)	Stock Number	Price	Buy
200 - 2300	20,000:1	Crystal Quartz	10.0	28.00	#68-824	A\$1,310.16	10 In Stock
130 - 7000	10,000:1	MgF ₂	10.0	28.00	#68-825	A\$1,606.80	5 In Stock
200 - 3500	200,000:1	α-BBO	10.0	18.00	#68-827	A\$1,921.57	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com