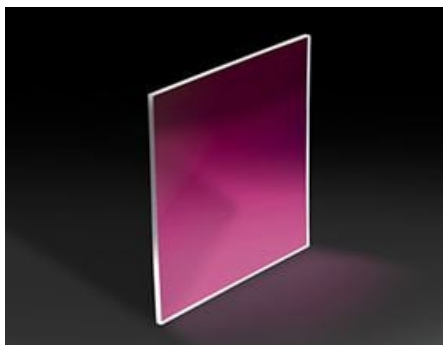


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)
TECHSPEC® Gorilla® Glass Windows


- Chemically Strengthened Drawn Glass
- Highly Resistance to Surface Scratches
- Ideal for Electronic Displays

Common Specifications

General

Chemical Strengthening Cycle (hours):	8
---------------------------------------	---

Physical & Mechanical Properties

Bevel:	Protective as needed
--------	----------------------

Clear Aperture (%):	90.00
---------------------	-------

Poisson's Ratio:	0.22
------------------	------

Young's Modulus (GPa):	70
------------------------	----

Optical Properties

Index of Refraction (n_d):	1.5
--------------------------------	-----

Substrate:	Gorilla® Glass
------------	----------------


Surface Quality:	80-50
------------------	-------

Material Properties

Coefficient of Thermal Expansion CTE ($10^{-6}/^{\circ}\text{C}$):	7.58 (0 to +300°C)
--	--------------------

Density (g/cm^3):	2.39
-------------------------------------	------

Technical Information

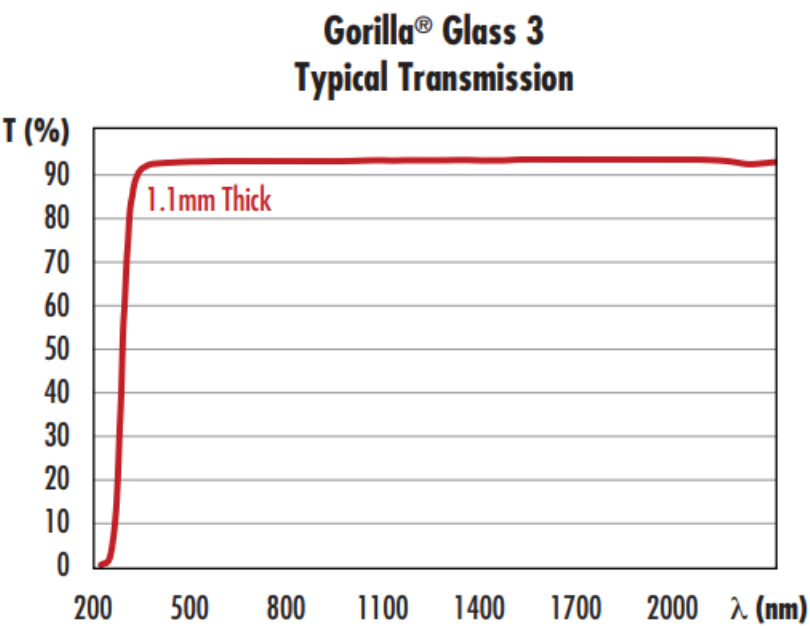

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	-	1.10	Uncoated	#83-359	A\$49.85 Volume Pricing	20+ In Stock
5.00	-	1.10	MgF ₂ (400-700nm)	#22-848	A\$84.05 Volume Pricing	9 In Stock
10.00	-	1.10	Uncoated	#83-360	A\$49.85 Volume Pricing	Contact Us
10.00	-	1.10	MgF ₂ (400-700nm)	#22-849	A\$84.05 Volume Pricing	8 In Stock
12.50	-	1.10	Uncoated	#83-361	A\$49.85 Volume Pricing	20+ In Stock
12.50	-	1.10	MgF ₂ (400-700nm)	#22-850	A\$84.05 Volume Pricing	8 In Stock
20.00	-	1.10	Uncoated	#83-362	A\$51.50 Volume Pricing	12 In Stock
20.00	-	0.40	Uncoated	#29-719	A\$51.50 Volume Pricing	9 In Stock
20.00	-	0.55	Uncoated	#29-720	A\$51.50 Volume Pricing	9 In Stock
20.00	-	1.50	Uncoated	#29-721	A\$51.50 Volume Pricing	10 In Stock
20.00	-	2.00	Uncoated	#29-722	A\$51.50 Volume Pricing	5 In Stock
20.00	-	1.10	MgF ₂ (400-700nm)	#22-851	A\$85.70 Volume Pricing	Contact Us
25.00	-	1.10	Uncoated	#83-363	A\$51.50 Volume Pricing	20+ In Stock
25.00	-	0.40	Uncoated	#21-232	A\$51.50 Volume Pricing	20+ In Stock
25.00	-	0.55	Uncoated	#21-233	A\$51.50 Volume Pricing	3 In Stock
25.00	-	0.80	Uncoated	#21-234	A\$51.50 Volume Pricing	20+ In Stock
25.00	-	1.50	Uncoated	#21-235	A\$51.50 Volume Pricing	15 In Stock

25.00	-	2.00	Uncoated	#21-236	A\$51.50 Volume Pricing	20+ In Stock
25.00	-	1.10	MgF ₂ (400-700nm)	#22-852	A\$85.70 Volume Pricing	Contact Us
30.00	-	1.10	Uncoated	#83-364	A\$64.27 Volume Pricing	20+ In Stock
30.00	-	0.40	Uncoated	#29-723	A\$64.27 Volume Pricing	20+ In Stock
30.00	-	0.55	Uncoated	#29-724	A\$64.27 Volume Pricing	9 In Stock
30.00	-	1.50	Uncoated	#29-725	A\$64.27 Volume Pricing	2 In Stock
30.00	-	2.00	Uncoated	#29-726	A\$64.27 Volume Pricing	6 In Stock
30.00	-	1.10	MgF ₂ (400-700nm)	#22-853	A\$107.12 Volume Pricing	11 In Stock
40.00	-	1.10	Uncoated	#83-365	A\$71.28 Volume Pricing	Contact Us
40.00	-	1.10	MgF ₂ (400-700nm)	#22-854	A\$113.71 Volume Pricing	20+ In Stock
50.00	-	1.10	Uncoated	#83-366	A\$75.40 Volume Pricing	Contact Us
50.00	-	0.40	Uncoated	#29-727	A\$75.40 Volume Pricing	20+ In Stock
50.00	-	0.55	Uncoated	#29-728	A\$75.40 Volume Pricing	9 In Stock
50.00	-	1.50	Uncoated	#29-729	A\$75.40 Volume Pricing	1 In Stock
50.00	-	2.00	Uncoated	#29-730	A\$75.40 Volume Pricing	20+ In Stock
50.00	-	1.10	MgF ₂ (400-700nm)	#22-855	A\$118.66 Volume Pricing	20+ In Stock
75.00	-	1.10	Uncoated	#11-854	A\$79.52 Volume Pricing	20+ In Stock
75.00	-	1.10	MgF ₂ (400-700nm)	#22-856	A\$158.21 Volume Pricing	Contact Us
100.00	-	1.10	Uncoated	#21-239	A\$98.88 Volume Pricing	11 In Stock

100.00	-	0.40	Uncoated	#29-731	A\$98.88 Volume Pricing	Contact Us
100.00	-	0.55	Uncoated	#29-732	A\$98.88 Volume Pricing	3 In Stock
100.00	-	1.50	Uncoated	#29-733	A\$98.88 Volume Pricing	5 In Stock
100.00	-	2.00	Uncoated	#29-734	A\$98.88 Volume Pricing	5 In Stock
200.00	-	1.10	Uncoated	#21-240	A\$163.15 Volume Pricing	2 In Stock
-	203.2 x 254	1.10	Uncoated	#21-237	A\$163.15 Volume Pricing	5 In Stock
-	254 x 304.8	1.10	Uncoated	#21-238	A\$184.58 Volume Pricing	7 In Stock
-	25.00 x 25.00	1.10	Uncoated	#12-228	A\$49.85 Volume Pricing	20+ In Stock
-	50.00 x 50.00	1.10	Uncoated	#11-853	A\$76.22 Volume Pricing	20+ In Stock
-	75.00 x 75.00	1.10	Uncoated	#11-855	A\$79.52 Volume Pricing	10 In Stock
-	100.00 x 100.00	1.10	Uncoated	#83-367	A\$89.82 Volume Pricing	20+ In Stock
-	100.00 x 100.00	0.40	Uncoated	#29-970	A\$89.82 Volume Pricing	9 In Stock
-	100.00 x 100.00	0.55	Uncoated	#29-971	A\$89.82 Volume Pricing	3 In Stock
-	100.00 x 100.00	1.50	Uncoated	#29-972	A\$89.82 Volume Pricing	3 In Stock
-	100.00 x 100.00	2.00	Uncoated	#29-973	A\$89.82 Volume Pricing	5 In Stock
150.00	-	1.10	Uncoated	#29-736	A\$124.42 Volume Pricing	9 In Stock
-	150.00 x 150.00	1.10	Uncoated	#29-735	A\$124.42 Volume Pricing	9 In Stock
-	200.00 x 200.00	1.10	Uncoated	#83-368	A\$163.15 Volume Pricing	12 In Stock
-	250.00 x 250.00	1.10	Uncoated	#17-161	A\$184.58 Volume Pricing	5 In Stock

-	500.00 x 500.00	1.10	Uncoated	#17-162	A\$500.99 Volume Pricing	1 In Stock
---	--------------------	------	----------	-------------------------	---	------------



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com