


[All Products](#) / [Optics](#) / [Optical Filters](#) / [Longpass Filters](#)

TECHSPEC® Dichroic Longpass Filters

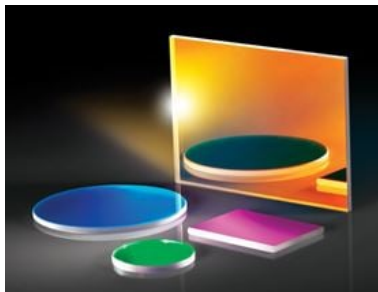

- Ideal for Fluorescence or Multispectral Imaging
- Sharp Cut-On Wavelength
- Broad Transmission and Reflection Ranges

Common Specifications

Physical & Mechanical Properties

Thickness (mm):	1.05 ±0.1	Dimensional Tolerance (mm):	+0.0/-0.2
Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2		


Optical Properties

Angle of Incidence (°):	45		
Substrate:	Fused Silica (Corning 7980)	Coating:	Hard Coated
Reflection (%):	>97, Average Polarization >95, Absolute Polarization	Surface Quality:	60-40
Transmission (%):	>85, Average Polarization >80, Absolute Polarization	Transmitted Wavefront Tolerance:	λ/4
Cut-On Tolerance (%):	±2	Slope Factor (%):	3.00

Environmental & Durability Factors

Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7		
----------------------------------	---	--	--

Technical Information

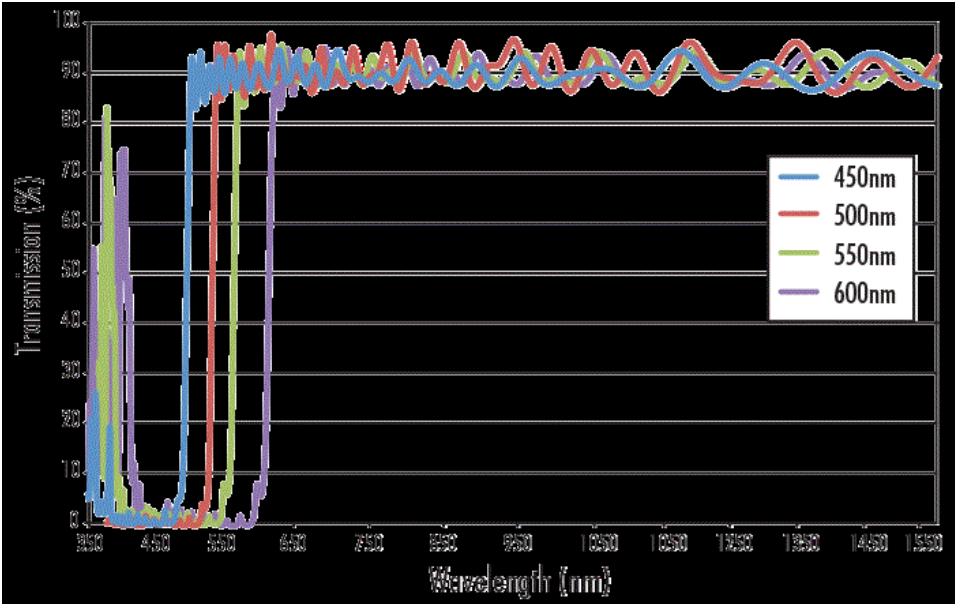

Products

Dimensions (mm)	Dia. (mm)	Cut-On Wavelength (nm)	Thickness (mm)	Reflection Wavelength (nm)	Transmission Wavelength (nm)	Stock Number	Price	Buy
-	12.50	400.00	1.05	350 - 375	420 - 1600	#69-864	A\$214.24 Volume Pricing	1 In Stock
12.5 x 17.6	-	400.00	1.05	350 - 375	420 - 1600	#69-875	A\$214.24 Volume Pricing	20+ In Stock
-	25.00	400.00	1.05	350 - 375	420 - 1600	#69-886	A\$286.75 Volume Pricing	Contact Us
25.2 x 35.6	-	400.00	1.05	350 - 375	420 - 1600	#69-897	A\$286.75 Volume Pricing	16 In Stock
-	12.50	450.00	1.05	350 - 430	470 - 1600	#69-865	A\$214.24 Volume Pricing	4 In Stock
12.5 x 17.6	-	450.00	1.05	350 - 430	470 - 1600	#69-876	A\$214.24 Volume Pricing	20+ In Stock
-	25.00	450.00	1.05	350 - 430	470 - 1600	#69-887	A\$286.75 Volume Pricing	Contact Us
25.2 x 35.6	-	450.00	1.05	350 - 430	470 - 1600	#69-898	A\$286.75 Volume Pricing	14 In Stock
-	12.50	500.00	1.05	350 - 480	520 - 1600	#69-866	A\$214.24 Volume Pricing	5 In Stock
12.5 x 17.6	-	500.00	1.05	350 - 480	520 - 1600	#69-877	A\$214.24 Volume Pricing	20+ In Stock
-	25.00	500.00	1.05	350 - 480	520 - 1600	#69-888	A\$286.75 Volume Pricing	2 In Stock
25.2 x 35.6	-	500.00	1.05	350 - 480	520 - 1600	#69-899	A\$286.75 Volume Pricing	5 In Stock
-	12.50	550.00	1.05	415 - 515	575 - 1600	#69-867	A\$214.24 Volume Pricing	20+ In Stock
12.5 x 17.6	-	550.00	1.05	415 - 515	575 - 1600	#69-878	A\$214.24 Volume Pricing	20+ In Stock
-	25.00	550.00	1.05	415 - 515	575 - 1600	#69-889	A\$286.75 Volume Pricing	2 In Stock
25.2 x 35.6	-	550.00	1.05	415 - 515	575 - 1600	#69-900	A\$286.75 Volume Pricing	20+ In Stock
-	12.50	600.00	1.05	460 - 570	625 - 1600	#69-868	A\$214.24 Volume Pricing	20+ In Stock
12.5 x 17.6	-	600.00	1.05	460 - 570	625 - 1600	#69-879	A\$214.24 Volume Pricing	5 In Stock
-	25.00	600.00	1.05	460 - 570	625 - 1600	#69-890	A\$286.75 Volume Pricing	20+ In Stock
25.2 x 35.6	-	600.00	1.05	460 - 570	625 - 1600	#69-901	A\$286.75 Volume Pricing	8 In Stock

-	12.50	650.00	1.05	495 - 610	675 - 1600	#69-869	A\$214.24 Volume Pricing	17 In Stock
12.5 x 17.6	-	650.00	1.05	495 - 610	675 - 1600	#69-880	A\$214.24 Volume Pricing	3 In Stock
-	25.00	650.00	1.05	495 - 610	675 - 1600	#69-891	A\$286.75 Volume Pricing	20+ In Stock
25.2 x 35.6	-	650.00	1.05	495 - 610	675 - 1600	#69-902	A\$286.75 Volume Pricing	Contact Us
-	12.50	700.00	1.05	535 - 660	725 - 1600	#69-870	A\$214.24 Volume Pricing	4 In Stock
12.5 x 17.6	-	700.00	1.05	535 - 660	725 - 1600	#69-881	A\$214.24 Volume Pricing	2 In Stock
-	25.00	700.00	1.05	535 - 660	725 - 1600	#69-892	A\$286.75 Volume Pricing	5 In Stock
25.2 x 35.6	-	700.00	1.05	535 - 660	725 - 1600	#69-903	A\$286.75 Volume Pricing	2 In Stock
-	12.50	750.00	1.05	565 - 715	780 - 1600	#69-871	A\$217.54 Volume Pricing	13 In Stock
12.5 x 17.6	-	750.00	1.05	565 - 715	780 - 1600	#69-882	A\$217.54 Volume Pricing	2 In Stock
-	25.00	750.00	1.05	565 - 715	780 - 1600	#69-893	A\$296.64 Volume Pricing	20+ In Stock
25.2 x 35.6	-	750.00	1.05	565 - 715	780 - 1600	#69-904	A\$296.64 Volume Pricing	20+ In Stock
-	12.50	800.00	1.05	600 - 760	830 - 1600	#69-872	A\$217.54 Volume Pricing	5 In Stock
12.5 x 17.6	-	800.00	1.05	600 - 760	830 - 1600	#69-883	A\$217.54 Volume Pricing	20+ In Stock
-	25.00	800.00	1.05	600 - 760	830 - 1600	#69-894	A\$296.64 Volume Pricing	2 In Stock
25.2 x 35.6	-	800.00	1.05	600 - 760	830 - 1600	#69-905	A\$296.64 Volume Pricing	7 In Stock
-	12.50	850.00	1.05	635 - 805	880 - 1600	#69-873	A\$217.54 Volume Pricing	Contact Us
12.5 x 17.6	-	850.00	1.05	635 - 805	880 - 1600	#69-884	A\$217.54 Volume Pricing	5 In Stock
-	25.00	850.00	1.05	635 - 805	880 - 1600	#69-895	A\$296.64 Volume Pricing	3 In Stock
25.2 x 35.6	-	850.00	1.05	635 - 805	880 - 1600	#69-906	A\$296.64 Volume Pricing	3 In Stock
-	12.50	900.00	1.05	675 - 855	935 - 1600	#69-874	A\$217.54 Volume Pricing	1 In Stock
12.5 x 17.6	-	900.00	1.05	675 - 855	935 - 1600	#69-885	A\$217.54 Volume Pricing	2 In Stock
-	25.00	900.00	1.05	675 - 855	935 - 1600	#69-896	A\$296.64 Volume Pricing	5 In Stock

25.2 x 35.6	-	900.00	1.05	675 - 855	935 - 1600	#69-907	A\$296.64 Volume Pricing	16 In Stock
-	12.50	950.00	1.05	715 - 900	985 - 1600	#87-027	A\$217.54 Volume Pricing	5 In Stock
12.5 x 17.6	-	950.00	1.05	715 - 900	985 - 1600	#87-033	A\$217.54 Volume Pricing	3 In Stock
-	25.00	950.00	1.05	715 - 900	985 - 1600	#87-039	A\$296.64 Volume Pricing	5 In Stock
25.2 x 35.6	-	950.00	1.05	715 - 900	985 - 1600	#87-045	A\$296.64 Volume Pricing	6 In Stock
-	12.50	1,000.00	1.05	750 - 950	1035 - 1600	#87-028	A\$224.13 Volume Pricing	16 In Stock
12.5 x 17.6	-	1,000.00	1.05	750 - 950	1035 - 1600	#87-034	A\$224.13 Volume Pricing	9 In Stock
-	25.00	1,000.00	1.05	750 - 950	1035 - 1600	#87-040	A\$304.88 Volume Pricing	2 In Stock
25.2 x 35.6	-	1,000.00	1.05	750 - 950	1035 - 1600	#87-046	A\$304.88 Volume Pricing	2 In Stock
-	12.50	1,050.00	1.05	790 - 1000	1085 - 1600	#87-029	A\$224.13 Volume Pricing	3 In Stock
12.5 x 17.6	-	1,050.00	1.05	790 - 1000	1085 - 1600	#87-035	A\$217.54 Volume Pricing	20+ In Stock
-	25.00	1,050.00	1.05	790 - 1000	1085 - 1600	#87-041	A\$304.88 Volume Pricing	2 In Stock
25.2 x 35.6	-	1,050.00	1.05	790 - 1000	1085 - 1600	#87-047	A\$304.88 Volume Pricing	20+ In Stock
-	12.50	1,100.00	1.05	825 - 1045	1135 - 1600	#87-030	A\$224.13 Volume Pricing	3 In Stock
12.5 x 17.6	-	1,100.00	1.05	825 - 1045	1135 - 1600	#87-036	A\$224.13 Volume Pricing	20+ In Stock
-	25.00	1,100.00	1.05	825 - 1045	1135 - 1600	#87-042	A\$304.88 Volume Pricing	20+ In Stock
25.2 x 35.6	-	1,100.00	1.05	825 - 1045	1135 - 1600	#87-048	A\$304.88 Volume Pricing	4 In Stock
-	12.50	1,150.00	1.05	875 - 1095	1190 - 1600	#87-031	A\$224.13 Volume Pricing	2 In Stock
12.5 x 17.6	-	1,150.00	1.05	875-1095	1190 - 1600	#87-037	A\$224.13 Volume Pricing	20+ In Stock
-	25.00	1,150.00	1.05	875 - 1095	1190 - 1600	#87-043	A\$304.88 Volume Pricing	7 In Stock
25.2 x 35.6	-	1,150.00	1.05	875 - 1095	1190 - 1600	#87-049	A\$304.88 Volume Pricing	3 In Stock
-	12.50	1,200.00	1.05	920 - 1160	1240 - 1600	#87-032	A\$224.13 Volume Pricing	Contact Us
12.5 x 17.6	-	1,200.00	1.05	920 - 1160	1240 - 1600	#87-038	A\$224.13 Volume Pricing	4 In Stock

-	25.00	1,200.00	1.05	920 - 1160	1240 - 1600	#87-044	A\$304.88 Volume Pricing	6 In Stock
	Edmund	05	920 - 1160	1240 - 1600	#87-050	A\$304.88 Volume Pricing	1 In Stock	

Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com