

[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Pattern Projectors](#)

Advanced Illumination LED Pattern Projectors See More by [Advanced Illumination](#)



- Multiple Wavelength Options Available
- Equip C-Mount [Imaging Lenses](#) to Control Illumination Geometry
- Ideal for 3D Reconstruction and Mapping

Common Specifications

General

LED Lifetime (hours):	50,000	Type of Illumination:	LED Illuminator
Note:	Optional Manual Intensity Adjustment #86-887 and #89-555 are Available	Manufacturer:	Advanced Illumination
Geometry:	Spot Light	Illumination Mode:	Constant


Physical & Mechanical Properties

Diameter of Compatible Reticle (mm):	20.8
---	------

Hardware & Interface Connectivity

Connector:	Flying Leads
Power Supply:	Power Supply Required and Sold Separately: USA: #66-855 Europe: #66-855 Japan: #89-513 Korea: #33-773 China: #66-855

Technical Information

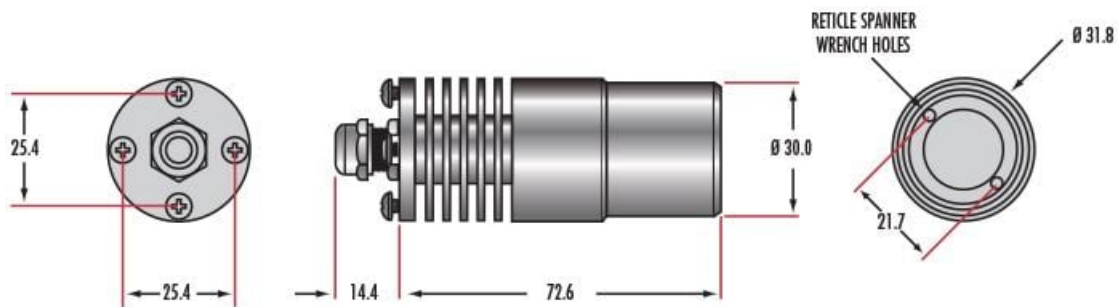

Single Line Reticle (#88-518)




Crosshair Reticle (#88-519)



8 Line Reticle (#88-520)




7 x 7 Grid Reticle (#88-521)

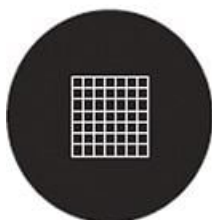


Edge Reticle (#88-522)



Pattern Projector Mounting Configuration

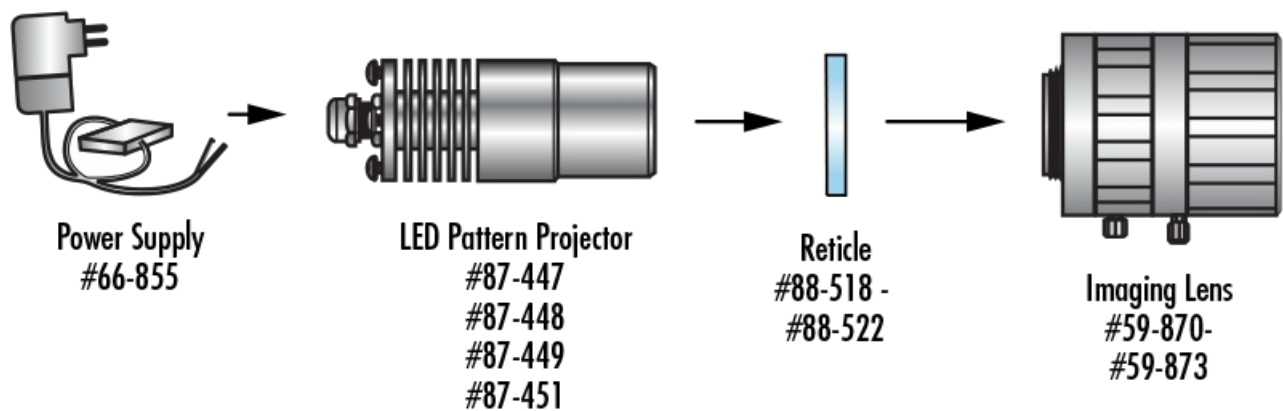

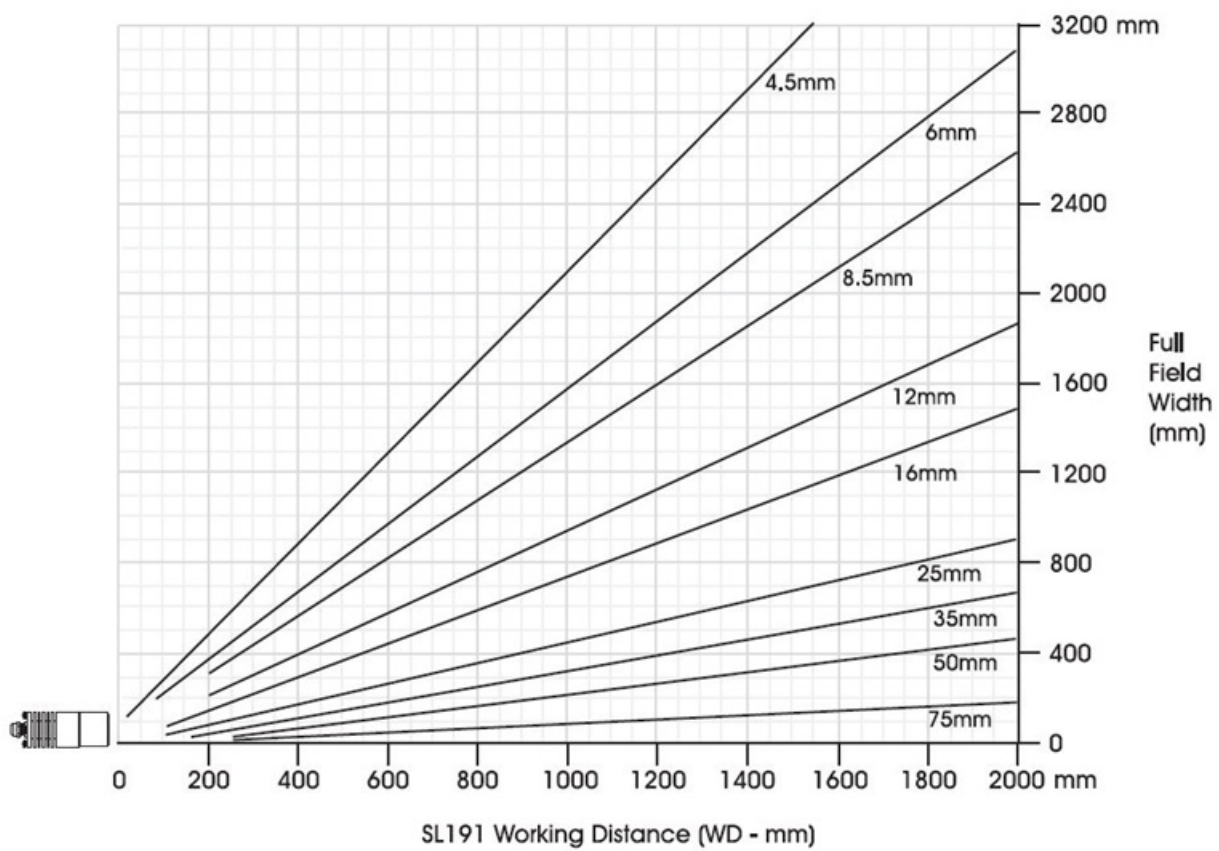

Products

Color	Wavelength (nm)	Stock Number	Price	Buy
Blue	455.00	#87-447	A\$1,240.00	1 In Stock
Green	530.00	#87-448	A\$1,240.00	1 In Stock
Red	625.00	#87-449	A\$1,240.00	3 In Stock
White	-	#87-451	A\$1,240.00	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com