

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® VIS-EXT Coated Plano-Convex (PCX) Lenses



- Visible Broadband Anti-Reflection Coating with Extended UV Performance
- AR Coated to Provide <0.5% Reflectance per Surface for 350 - 700nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties

Bevel: Protective as needed


Optical Properties

Coating: VIS-EXT (350-700nm)

Focal Length Tolerance (%): ± 1

Wavelength Range (nm): 350 - 700

Technical Information

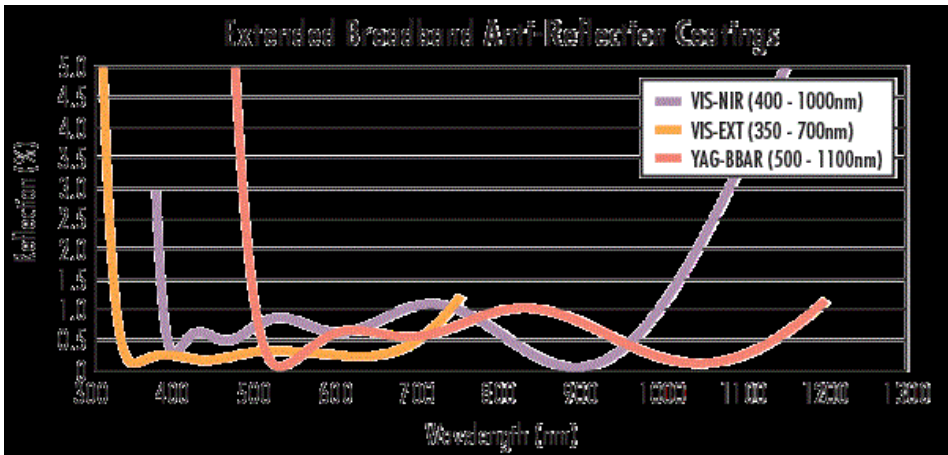

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	VIS-EXT (350-700nm)	N-LASF9	#35-694	A\$134.31 Volume Pricing	5 In Stock
1.00	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-695	A\$134.31 Volume Pricing	14 In Stock
1.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-696	A\$134.31 Volume Pricing	7 In Stock
1.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-697	A\$134.31 Volume Pricing	11 In Stock
1.50	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-698	A\$134.31 Volume Pricing	Contact Us
1.50	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-699	A\$134.31 Volume Pricing	Contact Us
1.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-700	A\$134.31 Volume Pricing	10 In Stock
2.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-701	A\$132.66 Volume Pricing	20+ In Stock
2.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-702	A\$132.66 Volume Pricing	20+ In Stock
2.00	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-703	A\$132.66 Volume Pricing	20+ In Stock
2.00	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-704	A\$132.66 Volume Pricing	10 In Stock
2.00	4.00	3.46	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-257	A\$179.63 Volume Pricing	5 In Stock

2.00	6.00	5.45	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-265	A\$171.39 Volume Pricing	5 In Stock
2.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-705	A\$132.66 Volume Pricing	4 In Stock
2.50	2.50	2.07	VIS-EXT (350-700nm)	N-LASF9	#35-706	A\$132.66 Volume Pricing	Contact Us
2.50	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-707	A\$132.66 Volume Pricing	13 In Stock
2.50	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-708	A\$132.66 Volume Pricing	14 In Stock
2.50	5.00	4.57	VIS-EXT (350-700nm)	N-LASF9	#35-709	A\$132.66 Volume Pricing	3 In Stock
3.00	3.00	1.88	VIS-EXT (350-700nm)	N-SF11	#88-615	A\$113.71 Volume Pricing	Contact Us
3.00	4.50	3.50	VIS-EXT (350-700nm)	N-LASF44	#88-616	A\$113.71 Volume Pricing	20+ In Stock
3.00	6.00	4.81	VIS-EXT (350-700nm)	N-BK7	#88-617	A\$105.47 Volume Pricing	10 In Stock
3.00	6.00	5.01	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-274	A\$179.63 Volume Pricing	9 In Stock
3.00	7.50	6.51	VIS-EXT (350-700nm)	N-BK7	#88-618	A\$105.47 Volume Pricing	Contact Us
3.00	9.00	8.01	VIS-EXT (350-700nm)	N-BK7	#88-619	A\$105.47 Volume Pricing	2 In Stock
3.00	9.00	8.11	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-282	A\$171.39 Volume Pricing	9 In Stock
3.00	12.00	11.29	VIS-EXT (350-700nm)	N-BK7	#88-620	A\$105.47 Volume Pricing	12 In Stock

3.00	15.00	14.22	VIS-EXT (350-700nm)	N-BK7	#88-621	A\$105.47 Volume Pricing	Contact Us
4.00	4.00	3.06	VIS-EXT (350-700nm)	N-LASF44	#88-622	A\$113.71 Volume Pricing	20+ In Stock
4.00	6.00	4.51	VIS-EXT (350-700nm)	N-BK7	#88-623	A\$113.71 Volume Pricing	14 In Stock
4.00	8.00	6.91	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-290	A\$212.59 Volume Pricing	16 In Stock
4.00	10.00	8.92	VIS-EXT (350-700nm)	N-BK7	#88-625	A\$107.12 Volume Pricing	17 In Stock
4.00	12.00	11.00	VIS-EXT (350-700nm)	N-BK7	#88-626	A\$107.12 Volume Pricing	3 In Stock
4.00	12.00	11.04	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-298	A\$204.35 Volume Pricing	8 In Stock
4.50	4.50	3.05	VIS-EXT (350-700nm)	N-LASF44	#88-627	A\$113.71 Volume Pricing	17 In Stock
4.50	9.00	7.41	VIS-EXT (350-700nm)	N-BK7	#88-628	A\$107.12 Volume Pricing	3 In Stock
5.00	5.00	3.96	VIS-EXT (350-700nm)	N-LASF44	#88-629	A\$83.64 Volume Pricing	20+ In Stock
5.00	7.50	6.43	VIS-EXT (350-700nm)	N-SF11	#88-630	A\$82.81 Volume Pricing	20+ In Stock
5.00	10.00	8.91	VIS-EXT (350-700nm)	N-BK7	#88-631	A\$82.81 Volume Pricing	3 In Stock
5.00	12.00	10.83	VIS-EXT (350-700nm)	N-BK7	#88-632	A\$82.81 Volume Pricing	10 In Stock
5.00	15.00	13.94	VIS-EXT (350-700nm)	N-BK7	#88-633	A\$82.81 Volume Pricing	Contact Us

5.00	20.00	19.02	VIS-EXT (350-700nm)	N-BK7	#88-634	A\$82.81 Volume Pricing	7 In Stock
5.00	25.00	23.95	VIS-EXT (350-700nm)	N-BK7	#88-635	A\$82.81 Volume Pricing	9 In Stock
5.00	30.00	28.95	VIS-EXT (350-700nm)	N-BK7	#88-636	A\$82.81 Volume Pricing	6 In Stock
6.00	6.00	4.60	VIS-EXT (350-700nm)	N-SF11	#88-637	A\$70.04 Volume Pricing	17 In Stock
6.00	7.50	6.10	VIS-EXT (350-700nm)	N-SF11	#88-638	A\$69.22 Volume Pricing	1 In Stock
6.00	9.00	7.95	VIS-EXT (350-700nm)	N-SF5	#88-639	A\$69.22 Volume Pricing	20+ In Stock
6.00	10.00	8.82	VIS-EXT (350-700nm)	N-BK7	#38-437	A\$69.22 Volume Pricing	16 In Stock
6.00	12.00	10.94	VIS-EXT (350-700nm)	N-BK7	#88-640	A\$67.57 Volume Pricing	5 In Stock
6.00	15.00	13.68	VIS-EXT (350-700nm)	N-BK7	#88-641	A\$67.57 Volume Pricing	20+ In Stock
6.00	18.00	17.07	VIS-EXT (350-700nm)	N-BK7	#88-642	A\$67.57 Volume Pricing	12 In Stock
6.00	20.00	19.04	VIS-EXT (350-700nm)	N-BK7	#38-438	A\$67.57 Volume Pricing	3 In Stock
6.00	21.00	20.06	VIS-EXT (350-700nm)	N-BK7	#88-643	A\$67.57 Volume Pricing	9 In Stock
6.00	24.00	23.01	VIS-EXT (350-700nm)	N-BK7	#88-644	A\$67.57 Volume Pricing	20+ In Stock
6.00	25.00	24.04	VIS-EXT (350-700nm)	N-BK7	#38-439	A\$67.57 Volume Pricing	2 In Stock

6.00	30.00	29.14	VIS-EXT (350-700nm)	N-BK7	#88-645	A\$67.57 Volume Pricing	20+ In Stock
6.00	36.00	34.95	VIS-EXT (350-700nm)	N-BK7	#88-646	A\$67.57 Volume Pricing	1 In Stock
6.00	48.00	46.95	VIS-EXT (350-700nm)	N-BK7	#88-647	A\$67.57 Volume Pricing	10 In Stock
6.00	60.00	58.95	VIS-EXT (350-700nm)	N-BK7	#88-648	A\$67.57 Volume Pricing	6 In Stock
6.00	72.00	70.97	VIS-EXT (350-700nm)	N-BK7	#88-649	A\$67.57 Volume Pricing	20+ In Stock
7.00	7.00	5.50	VIS-EXT (350-700nm)	N-SF11	#71-297	A\$69.22 Volume Pricing	5 In Stock
7.00	10.00	8.10	VIS-EXT (350-700nm)	N-BK7	#71-304	A\$68.39 Volume Pricing	8 In Stock
7.00	12.00	10.30	VIS-EXT (350-700nm)	N-BK7	#71-311	A\$68.39 Volume Pricing	4 In Stock
8.00	8.00	6.40	VIS-EXT (350-700nm)	N-SF11	#71-318	A\$69.22 Volume Pricing	5 In Stock
8.00	10.00	7.60	VIS-EXT (350-700nm)	N-BK7	#71-325	A\$68.39 Volume Pricing	Contact Us
8.00	12.00	10.00	VIS-EXT (350-700nm)	N-BK7	#71-332	A\$68.39 Volume Pricing	2 In Stock
9.00	9.00	7.32	VIS-EXT (350-700nm)	N-SF11	#88-650	A\$70.86 Volume Pricing	20+ In Stock
9.00	10.00	8.49	VIS-EXT (350-700nm)	N-SF11	#38-440	A\$70.86 Volume Pricing	5 In Stock
9.00	12.00	10.60	VIS-EXT (350-700nm)	N-SF11	#88-651	A\$70.86 Volume Pricing	5 In Stock

9.00	13.50	11.94	VIS-EXT (350-700nm)	N-SF5	#88-652	A\$70.86 Volume Pricing	1 In Stock
9.00	15.00	13.02	VIS-EXT (350-700nm)	N-BK7	#88-653	A\$70.86 Volume Pricing	20+ In Stock
9.00	18.00	16.41	VIS-EXT (350-700nm)	N-BK7	#88-654	A\$69.22 Volume Pricing	11 In Stock
9.00	20.00	18.55	VIS-EXT (350-700nm)	N-BK7	#38-441	A\$69.22 Volume Pricing	9 In Stock
9.00	22.00	20.73	VIS-EXT (350-700nm)	N-BK7	#88-655	A\$69.22 Volume Pricing	8 In Stock
9.00	25.00	23.68	VIS-EXT (350-700nm)	N-BK7	#38-442	A\$69.22 Volume Pricing	5 In Stock
9.00	27.00	25.34	VIS-EXT (350-700nm)	N-BK7	#88-656	A\$69.22 Volume Pricing	10 In Stock
9.00	36.00	34.48	VIS-EXT (350-700nm)	N-BK7	#88-657	A\$69.22 Volume Pricing	20+ In Stock
9.00	45.00	43.98	VIS-EXT (350-700nm)	N-BK7	#88-658	A\$69.22 Volume Pricing	2 In Stock
9.00	54.00	52.69	VIS-EXT (350-700nm)	N-BK7	#88-659	A\$69.22 Volume Pricing	2 In Stock
9.00	72.00	70.68	VIS-EXT (350-700nm)	N-BK7	#88-660	A\$69.22 Volume Pricing	5 In Stock
9.00	90.00	88.68	VIS-EXT (350-700nm)	N-BK7	#88-661	A\$69.22 Volume Pricing	10 In Stock
10.00	10.00	8.18	VIS-EXT (350-700nm)	N-SF11	#88-662	A\$70.86 Volume Pricing	1 In Stock
10.00	12.50	10.99	VIS-EXT (350-700nm)	N-SF11	#38-443	A\$70.86 Volume Pricing	17 In Stock

10.00	15.00	13.32	VIS-EXT (350-700nm)	N-SF11	#88-663	A\$70.86 Volume Pricing	3 In Stock
10.00	17.50	15.66	VIS-EXT (350-700nm)	N-BK7	#38-444	A\$69.22 Volume Pricing	3 In Stock
10.00	20.00	18.03	VIS-EXT (350-700nm)	N-BK7	#88-664	A\$69.22 Volume Pricing	8 In Stock
10.00	25.00	23.02	VIS-EXT (350-700nm)	N-BK7	#88-665	A\$69.22 Volume Pricing	15 In Stock
10.00	30.00	28.01	VIS-EXT (350-700nm)	N-BK7	#88-666	A\$69.22 Volume Pricing	2 In Stock
10.00	40.00	38.02	VIS-EXT (350-700nm)	N-BK7	#88-667	A\$69.22 Volume Pricing	1 In Stock
10.00	50.00	48.02	VIS-EXT (350-700nm)	N-BK7	#88-668	A\$69.22 Volume Pricing	10 In Stock
10.00	75.00	73.02	VIS-EXT (350-700nm)	N-BK7	#88-669	A\$69.22 Volume Pricing	7 In Stock
10.00	100.00	98.02	VIS-EXT (350-700nm)	N-BK7	#88-670	A\$69.22 Volume Pricing	5 In Stock
12.00	12.00	9.76	VIS-EXT (350-700nm)	N-SF11	#88-671	A\$76.63 Volume Pricing	12 In Stock
12.00	15.00	12.03	VIS-EXT (350-700nm)	N-BK7	#88-672	A\$76.63 Volume Pricing	8 In Stock
12.00	18.00	16.22	VIS-EXT (350-700nm)	N-SF5	#88-673	A\$76.63 Volume Pricing	16 In Stock
12.00	20.00	17.69	VIS-EXT (350-700nm)	N-BK7	#88-674	A\$76.63 Volume Pricing	13 In Stock
12.00	24.00	22.15	VIS-EXT (350-700nm)	N-BK7	#88-675	A\$74.98 Volume Pricing	4 In Stock

12.00	25.00	23.22	VIS-EXT (350-700nm)	N-BK7	#38-445	A\$74.98 Volume Pricing	5 In Stock
12.00	30.00	28.02	VIS-EXT (350-700nm)	N-BK7	#88-676	A\$74.98 Volume Pricing	4 In Stock
12.00	36.00	34.02	VIS-EXT (350-700nm)	N-BK7	#34-177	A\$74.98 Volume Pricing	1 In Stock
12.00	42.00	40.22	VIS-EXT (350-700nm)	N-BK7	#88-678	A\$74.98 Volume Pricing	6 In Stock
12.00	48.00	46.36	VIS-EXT (350-700nm)	N-BK7	#88-679	A\$74.98 Volume Pricing	4 In Stock
12.00	50.00	48.75	VIS-EXT (350-700nm)	N-BK7	#38-446	A\$74.98 Volume Pricing	4 In Stock
12.00	54.00	52.02	VIS-EXT (350-700nm)	N-BK7	#88-680	A\$74.98 Volume Pricing	4 In Stock
12.00	60.00	58.37	VIS-EXT (350-700nm)	N-BK7	#88-681	A\$74.98 Volume Pricing	7 In Stock
12.00	72.00	70.42	VIS-EXT (350-700nm)	N-BK7	#88-682	A\$74.98 Volume Pricing	6 In Stock
12.00	84.00	82.39	VIS-EXT (350-700nm)	N-BK7	#88-683	A\$74.98 Volume Pricing	6 In Stock
12.00	100.00	98.35	VIS-EXT (350-700nm)	N-BK7	#88-684	A\$74.98 Volume Pricing	5 In Stock
12.50	12.50	10.40	VIS-EXT (350-700nm)	N-SF11	#38-448	A\$74.98 Volume Pricing	16 In Stock
12.50	15.00	13.26	VIS-EXT (350-700nm)	N-SF11	#38-449	A\$74.98 Volume Pricing	3 In Stock
12.50	17.50	15.00	VIS-EXT (350-700nm)	N-BK7	#38-450	A\$74.98 Volume Pricing	9 In Stock

12.50	20.00	17.69	VIS-EXT (350-700nm)	N-BK7	#38-451	A\$74.98 Volume Pricing	20+ In Stock
12.50	25.00	22.96	VIS-EXT (350-700nm)	N-BK7	#38-453	A\$73.34 Volume Pricing	1 In Stock
12.50	30.00	28.22	VIS-EXT (350-700nm)	N-BK7	#38-454	A\$73.34 Volume Pricing	Contact Us
12.50	35.00	33.42	VIS-EXT (350-700nm)	N-BK7	#38-455	A\$73.34 Volume Pricing	4 In Stock
12.50	40.00	38.55	VIS-EXT (350-700nm)	N-BK7	#38-457	A\$73.34 Volume Pricing	3 In Stock
12.50	45.00	43.68	VIS-EXT (350-700nm)	N-BK7	#38-458	A\$73.34 Volume Pricing	3 In Stock
12.50	50.00	48.68	VIS-EXT (350-700nm)	N-BK7	#38-459	A\$73.34 Volume Pricing	8 In Stock
12.50	75.00	73.88	VIS-EXT (350-700nm)	N-BK7	#38-460	A\$73.34 Volume Pricing	20+ In Stock
12.50	100.00	98.95	VIS-EXT (350-700nm)	N-BK7	#38-461	A\$73.34 Volume Pricing	20+ In Stock
12.70	12.70	10.46	VIS-EXT (350-700nm)	N-SF11	#88-685	A\$74.98 Volume Pricing	20+ In Stock
12.70	15.00	11.53	VIS-EXT (350-700nm)	N-BK7	#88-686	A\$74.98 Volume Pricing	3 In Stock
12.70	19.10	16.46	VIS-EXT (350-700nm)	N-BK7	#88-687	A\$74.98 Volume Pricing	4 In Stock
12.70	20.00	17.49	VIS-EXT (350-700nm)	N-BK7	#38-462	A\$74.98 Volume Pricing	1 In Stock
12.70	25.40	23.43	VIS-EXT (350-700nm)	N-BK7	#88-688	A\$73.34 Volume Pricing	6 In Stock

12.70	30.00	28.22	VIS-EXT (350-700nm)	N-BK7	#38-463	A\$73.34 Volume Pricing	2 In Stock
12.70	31.80	29.81	VIS-EXT (350-700nm)	N-BK7	#88-689	A\$73.34 Volume Pricing	9 In Stock
12.70	38.10	36.12	VIS-EXT (350-700nm)	N-BK7	#88-690	A\$73.34 Volume Pricing	3 In Stock
12.70	40.00	38.48	VIS-EXT (350-700nm)	N-BK7	#38-464	A\$73.34 Volume Pricing	10 In Stock
12.70	44.50	42.69	VIS-EXT (350-700nm)	N-BK7	#88-691	A\$73.34 Volume Pricing	4 In Stock
12.70	50.80	49.15	VIS-EXT (350-700nm)	N-BK7	#88-692	A\$73.34 Volume Pricing	11 In Stock
12.70	100.00	98.88	VIS-EXT (350-700nm)	N-BK7	#38-465	A\$73.34 Volume Pricing	1 In Stock
15.00	15.00	11.71	VIS-EXT (350-700nm)	N-SF5	#88-693	A\$76.63 Volume Pricing	6 In Stock
15.00	18.00	15.61	VIS-EXT (350-700nm)	N-SF5	#88-694	A\$76.63 Volume Pricing	6 In Stock
15.00	20.00	17.74	VIS-EXT (350-700nm)	N-SF5	#88-695	A\$76.63 Volume Pricing	Contact Us
15.00	22.50	20.50	VIS-EXT (350-700nm)	N-SF5	#88-696	A\$76.63 Volume Pricing	4 In Stock
15.00	25.00	22.50	VIS-EXT (350-700nm)	N-BK7	#38-466	A\$74.98 Volume Pricing	4 In Stock
15.00	30.00	27.90	VIS-EXT (350-700nm)	N-BK7	#88-697	A\$74.98 Volume Pricing	9 In Stock
15.00	40.00	38.02	VIS-EXT (350-700nm)	N-BK7	#88-698	A\$74.98 Volume Pricing	20+ In Stock

15.00	45.00	43.35	VIS-EXT (350-700nm)	N-BK7	#88-699	A\$74.98 Volume Pricing	8 In Stock
15.00	50.00	48.35	VIS-EXT (350-700nm)	N-BK7	#38-467	A\$74.98 Volume Pricing	4 In Stock
15.00	60.00	58.65	VIS-EXT (350-700nm)	N-BK7	#88-700	A\$74.98 Volume Pricing	14 In Stock
15.00	75.00	73.79	VIS-EXT (350-700nm)	N-BK7	#88-701	A\$74.98 Volume Pricing	6 In Stock
15.00	100.00	98.02	VIS-EXT (350-700nm)	N-BK7	#88-702	A\$74.98 Volume Pricing	Contact Us
15.00	200.00	197.89	VIS-EXT (350-700nm)	N-BK7	#14-379	A\$74.98 Volume Pricing	4 In Stock
15.00	250.00	248.02	VIS-EXT (350-700nm)	N-BK7	#14-387	A\$74.98 Volume Pricing	2 In Stock
18.00	18.00	15.20	VIS-EXT (350-700nm)	N-SF11	#88-703	A\$79.10 Volume Pricing	3 In Stock
18.00	20.00	17.59	VIS-EXT (350-700nm)	N-SF11	#38-468	A\$78.28 Volume Pricing	8 In Stock
18.00	22.50	20.26	VIS-EXT (350-700nm)	N-SF11	#88-704	A\$78.28 Volume Pricing	8 In Stock
18.00	25.00	21.51	VIS-EXT (350-700nm)	N-BK7	#38-469	A\$78.28 Volume Pricing	5 In Stock
18.00	27.00	24.73	VIS-EXT (350-700nm)	N-SF5	#88-705	A\$78.28 Volume Pricing	8 In Stock
18.00	30.00	27.10	VIS-EXT (350-700nm)	N-BK7	#38-470	A\$75.81 Volume Pricing	Contact Us
18.00	36.00	33.65	VIS-EXT (350-700nm)	N-BK7	#88-706	A\$75.81 Volume Pricing	17 In Stock

18.00	50.00	48.09	VIS-EXT (350-700nm)	N-BK7	#38-471	A\$75.81 Volume Pricing	7 In Stock
18.00	54.00	52.02	VIS-EXT (350-700nm)	N-BK7	#88-707	A\$75.81 Volume Pricing	4 In Stock
18.00	72.00	70.05	VIS-EXT (350-700nm)	N-BK7	#88-708	A\$75.81 Volume Pricing	5 In Stock
20.00	20.00	17.42	VIS-EXT (350-700nm)	N-SF11	#88-709	A\$79.93 Volume Pricing	20+ In Stock
20.00	25.00	22.76	VIS-EXT (350-700nm)	N-SF11	#88-710	A\$79.10 Volume Pricing	8 In Stock
20.00	35.00	32.04	VIS-EXT (350-700nm)	N-BK7	#88-712	A\$79.10 Volume Pricing	12 In Stock
20.00	40.00	36.77	VIS-EXT (350-700nm)	N-BK7	#88-713	A\$76.63 Volume Pricing	2 In Stock
20.00	50.00	47.87	VIS-EXT (350-700nm)	N-BK7	#88-714	A\$76.63 Volume Pricing	20+ In Stock
20.00	60.00	57.03	VIS-EXT (350-700nm)	N-BK7	#88-715	A\$76.63 Volume Pricing	4 In Stock
20.00	70.00	68.03	VIS-EXT (350-700nm)	N-BK7	#88-716	A\$76.63 Volume Pricing	3 In Stock
20.00	80.00	78.45	VIS-EXT (350-700nm)	N-BK7	#88-717	A\$76.63 Volume Pricing	3 In Stock
20.00	100.00	97.13	VIS-EXT (350-700nm)	N-BK7	#88-718	A\$76.63 Volume Pricing	20+ In Stock
20.00	150.00	148.02	VIS-EXT (350-700nm)	N-BK7	#88-719	A\$76.63 Volume Pricing	9 In Stock
25.00	25.00	20.22	VIS-EXT (350-700nm)	N-SF5	#88-720	A\$84.05 Volume Pricing	7 In Stock

25.00	30.00	24.69	VIS-EXT (350-700nm)	N-BK7	#88-721	A\$84.05 Volume Pricing	5 In Stock
25.00	35.00	30.42	VIS-EXT (350-700nm)	N-BK7	#88-722	A\$84.05 Volume Pricing	20+ In Stock
25.00	40.00	36.31	VIS-EXT (350-700nm)	N-BK7	#88-723	A\$84.05 Volume Pricing	5 In Stock
25.00	50.00	46.75	VIS-EXT (350-700nm)	N-BK7	#88-724	A\$80.75 Volume Pricing	14 In Stock
25.00	60.00	56.90	VIS-EXT (350-700nm)	N-BK7	#88-725	A\$80.75 Volume Pricing	20+ In Stock
25.00	75.00	72.00	VIS-EXT (350-700nm)	N-BK7	#88-726	A\$80.75 Volume Pricing	4 In Stock
25.00	85.00	82.17	VIS-EXT (350-700nm)	N-BK7	#88-727	A\$80.75 Volume Pricing	12 In Stock
25.00	100.00	97.17	VIS-EXT (350-700nm)	N-BK7	#88-728	A\$80.75 Volume Pricing	20+ In Stock
25.00	125.00	122.70	VIS-EXT (350-700nm)	N-BK7	#88-729	A\$80.75 Volume Pricing	5 In Stock
25.00	150.00	147.81	VIS-EXT (350-700nm)	N-BK7	#88-730	A\$80.75 Volume Pricing	13 In Stock
25.00	175.00	172.85	VIS-EXT (350-700nm)	N-BK7	#88-731	A\$80.75 Volume Pricing	6 In Stock
25.00	200.00	197.89	VIS-EXT (350-700nm)	N-BK7	#34-178	A\$80.75 Volume Pricing	7 In Stock
25.00	250.00	248.02	VIS-EXT (350-700nm)	N-BK7	#88-733	A\$80.75 Volume Pricing	8 In Stock
25.00	300.00	298.02	VIS-EXT (350-700nm)	N-BK7	#88-734	A\$80.75 Volume Pricing	5 In Stock

25.00	400.00	397.89	VIS-EXT (350-700nm)	N-BK7	#34-179	A\$80.75 Volume Pricing	13 In Stock
25.00	500.00	497.89	VIS-EXT (350-700nm)	N-BK7	#88-736	A\$80.75 Volume Pricing	Contact Us
25.00	750.00	747.89	VIS-EXT (350-700nm)	N-BK7	#88-737	A\$80.75 Volume Pricing	Contact Us
25.40	25.40	21.48	VIS-EXT (350-700nm)	N-SF11	#88-738	A\$84.05 Volume Pricing	Contact Us
25.40	35.00	30.46	VIS-EXT (350-700nm)	N-BK7	#38-472	A\$84.05 Volume Pricing	1 In Stock
25.40	38.10	33.48	VIS-EXT (350-700nm)	N-BK7	#88-739	A\$84.05 Volume Pricing	11 In Stock
25.40	40.00	36.11	VIS-EXT (350-700nm)	N-BK7	#38-473	A\$84.05 Volume Pricing	1 In Stock
25.40	50.80	47.50	VIS-EXT (350-700nm)	N-BK7	#88-740	A\$80.75 Volume Pricing	Contact Us
25.40	63.50	60.37	VIS-EXT (350-700nm)	N-BK7	#88-741	A\$80.75 Volume Pricing	20+ In Stock
25.40	75.00	72.69	VIS-EXT (350-700nm)	N-BK7	#38-474	A\$80.75 Volume Pricing	5 In Stock
25.40	76.20	73.56	VIS-EXT (350-700nm)	N-BK7	#88-742	A\$80.75 Volume Pricing	Contact Us
25.40	88.90	86.26	VIS-EXT (350-700nm)	N-BK7	#88-743	A\$80.75 Volume Pricing	5 In Stock
25.40	100.00	98.02	VIS-EXT (350-700nm)	N-BK7	#38-475	A\$80.75 Volume Pricing	5 In Stock
25.40	101.60	98.97	VIS-EXT (350-700nm)	N-BK7	#88-744	A\$80.75 Volume Pricing	5 In Stock

25.40	125.00	123.02	VIS-EXT (350-700nm)	N-BK7	#38-476	A\$80.75 Volume Pricing	5 In Stock
25.40	150.00	148.02	VIS-EXT (350-700nm)	N-BK7	#38-477	A\$80.75 Volume Pricing	1 In Stock
30.00	30.00	26.13	VIS-EXT (350-700nm)	N-SF11	#88-745	A\$97.23 Volume Pricing	16 In Stock
30.00	40.00	37.20	VIS-EXT (350-700nm)	N-SF11	#88-746	A\$93.94 Volume Pricing	20+ In Stock
30.00	50.00	46.17	VIS-EXT (350-700nm)	N-SF5	#88-747	A\$93.94 Volume Pricing	9 In Stock
30.00	60.00	56.03	VIS-EXT (350-700nm)	N-BK7	#88-749	A\$91.46 Volume Pricing	5 In Stock
30.00	75.00	70.95	VIS-EXT (350-700nm)	N-BK7	#88-750	A\$91.46 Volume Pricing	7 In Stock
30.00	100.00	96.01	VIS-EXT (350-700nm)	N-BK7	#88-751	A\$91.46 Volume Pricing	20+ In Stock
30.00	120.00	116.04	VIS-EXT (350-700nm)	N-BK7	#88-752	A\$91.46 Volume Pricing	5 In Stock
35.00	35.00	30.52	VIS-EXT (350-700nm)	N-SF11	#38-478	A\$99.70 Volume Pricing	14 In Stock
35.00	50.00	44.40	VIS-EXT (350-700nm)	N-BK7	#38-479	A\$97.23 Volume Pricing	Contact Us
35.00	70.00	66.04	VIS-EXT (350-700nm)	N-BK7	#38-480	A\$97.23 Volume Pricing	6 In Stock
35.00	100.00	97.03	VIS-EXT (350-700nm)	N-BK7	#38-482	A\$97.23 Volume Pricing	1 In Stock
40.00	40.00	35.13	VIS-EXT (350-700nm)	N-SF11	#88-753	A\$114.54 Volume Pricing	6 In Stock

40.00	60.00	53.90	VIS-EXT (350-700nm)	N-BK7	#88-754	A\$114.54 Volume Pricing	4 In Stock
40.00	80.00	74.73	VIS-EXT (350-700nm)	N-BK7	#34-180	A\$112.89 Volume Pricing	11 In Stock
40.00	100.00	95.39	VIS-EXT (350-700nm)	N-BK7	#34-181	A\$112.89 Volume Pricing	13 In Stock
40.00	200.00	196.7	VIS-EXT (350-700nm)	N-BK7	#34-182	A\$112.89 Volume Pricing	Contact Us
40.00	300.00	296.70	VIS-EXT (350-700nm)	N-BK7	#88-758	A\$112.89 Volume Pricing	Contact Us
40.00	400.00	396.70	VIS-EXT (350-700nm)	N-BK7	#88-759	A\$112.89 Volume Pricing	4 In Stock
50.00	50.00	43.28	VIS-EXT (350-700nm)	N-SF11	#88-760	A\$122.78 Volume Pricing	7 In Stock
50.00	75.00	67.75	VIS-EXT (350-700nm)	N-BK7	#88-761	A\$119.48 Volume Pricing	13 In Stock
50.00	100.00	93.41	VIS-EXT (350-700nm)	N-BK7	#88-762	A\$115.36 Volume Pricing	5 In Stock
50.00	125.00	118.39	VIS-EXT (350-700nm)	N-BK7	#88-763	A\$115.36 Volume Pricing	2 In Stock
50.00	150.00	144.07	VIS-EXT (350-700nm)	N-BK7	#88-764	A\$115.36 Volume Pricing	12 In Stock
50.00	175.00	169.05	VIS-EXT (350-700nm)	N-BK7	#88-765	A\$115.36 Volume Pricing	5 In Stock
50.00	200.00	196.66	VIS-EXT (350-700nm)	N-BK7	#88-766	A\$115.36 Volume Pricing	3 In Stock
50.00	250.00	246.74	VIS-EXT (350-700nm)	N-BK7	#88-767	A\$115.36 Volume Pricing	4 In Stock

50.00	500.00	496.70	VIS-EXT (350-700nm)	N-BK7	#88-768	A\$115.36 Volume Pricing	11 In Stock
50.80	50.81	44.08	VIS-EXT (350-700nm)	N-SF11	#71-339	A\$122.78 Volume Pricing	3 In Stock
50.80	76.20	68.95	VIS-EXT (350-700nm)	N-BK7	#71-346	A\$119.48 Volume Pricing	4 In Stock
75.00	75.00	53.49	VIS-EXT (350-700nm)	N-BK7	#26-109	A\$238.96 Volume Pricing	Contact Us
75.00	100.00	85.61	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-306	A\$1,095.92 Volume Pricing	2 In Stock
75.00	125.00	112.66	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	#72-314	A\$1,062.96 Volume Pricing	1 In Stock
75.00	150.00	142.45	VIS-EXT (350-700nm)	N-BK7	#26-110	A\$235.66 Volume Pricing	3 In Stock
#72-322 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	150.00	136.31	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)		A\$1,030.00 Volume Pricing	1 In Stock
75.00	200.00	194.24	VIS-EXT (350-700nm)	N-BK7	#26-111	A\$235.66 Volume Pricing	3 In Stock

[#72-330 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	200.00	187.18	VIS-EXT (350-700nm)	Fused Silica (Corning 7980)	A\$997.04 Volume Pricing	1 In Stock
-------	--------	--------	------------------------	--------------------------------	---	------------



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100						
75.00	250.00	244.73	VIS-EXT (350-700nm)	N-BK7	#26-112 A\$235.66 Volume Pricing	6 In Stock

Phone: 1-800-363-1992 :
www.edmundoptics.com

75.00	500.00	494.73	VIS-EXT (350-700nm)	N-BK7	#26-113 A\$235.66 Volume Pricing	1 In Stock
-------	--------	--------	------------------------	-----------------------	--	------------