


[All Products](#) / [Lasers](#) / [Laser Sources](#) / [Industrial and Pointing Lasers](#)

Violet and Blue Alignment Laser Diodes

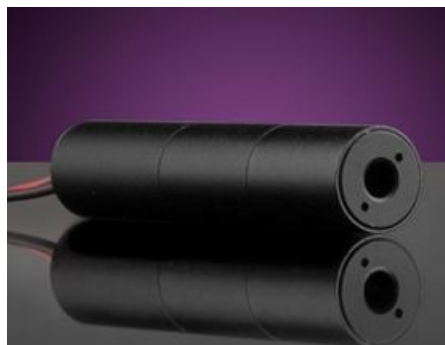

- TTL Modulation up to 10kHz
- Circular and Elliptical Beam Profiles
- Focus Adjustable



Common Specifications

Physical & Mechanical Properties

Length (mm):	36.00
--------------	-------

Optical Properties

Wavelength Tolerance (nm):	±5
----------------------------	----

Electrical

Modulation Frequency (kHz):	0 - 10
-----------------------------	--------

Technical Information

Products

Wavelength (nm)	Output Power (mW)	Beam Diameter (mm)	Beam Divergence (mrad)	Stock Number	Price	Buy
405.00	1	3.5 Typical	<0.5	#37-023	A\$593.60	1 In Stock
405.00	5	3.2 x 1.5	<0.5	#37-024	A\$612.80	4 In Stock
405.00	10	3.5 Typical	<0.5	#37-025	A\$638.40	9 In Stock
405.00	25	3.5 typical	<0.5	#19-461	A\$779.20	3 In Stock
405.00	100	3.5 typical	<1.0	#19-462	A\$1,032.00	5 In Stock
450.00	1	3.5 typical	<1.0	#19-463	A\$568.00	3 In Stock
450.00	5	3.5 typical	<1.0	#19-464	A\$568.00	3 In Stock
450.00	10	3.5 typical	<1.0	#19-465	A\$609.60	2 In Stock
450.00	25	3.5 typical	<1.0	#19-466	A\$779.20	2 In Stock
450.00	100	3.5 typical	<1.0	#19-467	A\$1,032.00	3 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com