


[All Products](#) / [Optics](#) / [SCHOTT Optical Components](#)

SCHOTT NG Gray Glass Neutral Density (ND) Filters See More by [SCHOTT Optical Components](#)

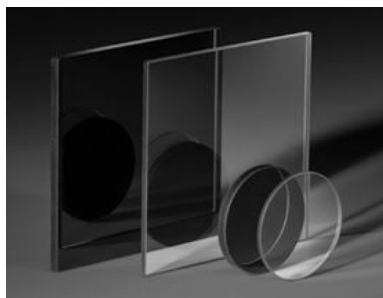

- Tightly Controlled Thickness Specifications
- Standard Thicknesses of 1, 2, and 3mm
- Even Light Attenuation in the Visible Spectrum
- NG1, NG3, NG4, NG5, NG9 and NG11 Glass Types Available
- [Precision SCHOTT NG Glass Filters](#) Also Available


Common Specifications

Physical & Mechanical Properties


Parallelism (arcmin): ≤ 3	Dimensional Tolerance (mm): ± 0.2
Optical Properties	
Coating: Uncoated	Surface Quality: 60-40
Transmission Tolerance (%): (nominal)	Optical Density Tolerance (%): (nominal)

Technical Information

Schott NG Absorptive ND Filters
(1mm Thickness) Visible Spectrum

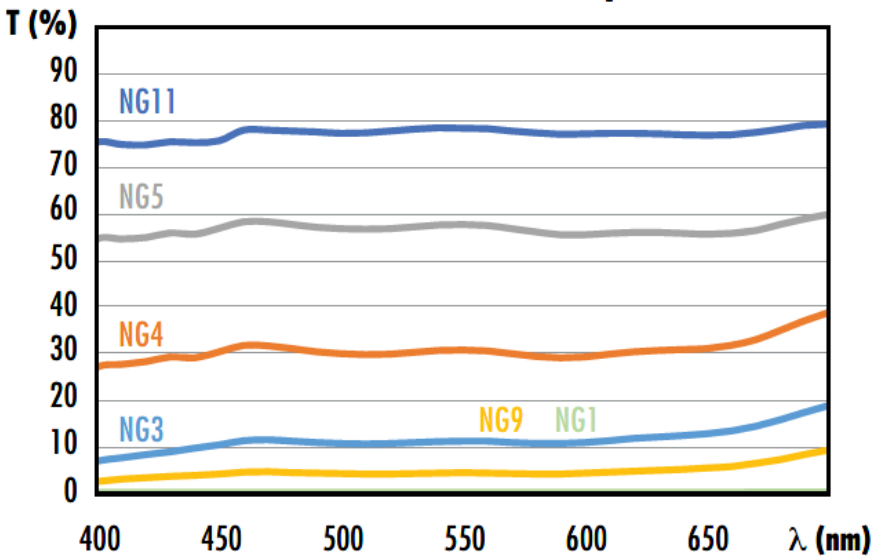

Schott NG Absorptive ND Filters (1mm Thickness) Extended Spectrum

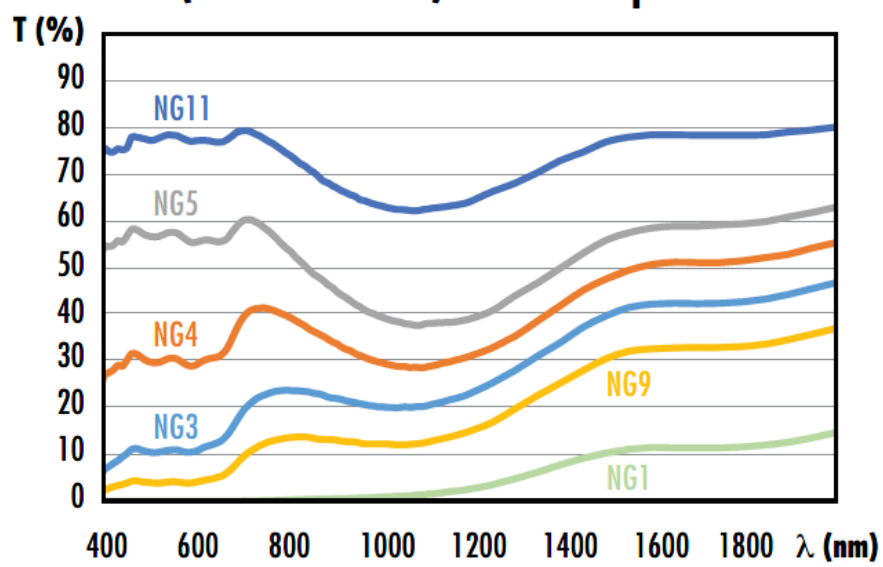

Products

Dia. (mm)	Dimensions (mm)	Optical Density OD (Average)	Glass/Filter Number	Thickness (mm)	Transmission (%)	Stock Number	Price	Buy
25.00	-	4.84	SCHOTT NG1	1.00	0.001	#14-075	A\$71.20 Volume Pricing	5 In Stock
25.00	-	>5	SCHOTT NG1	2.00	<0.001	#14-077	A\$71.20 Volume Pricing	8 In Stock
25.00	-	>5	SCHOTT NG1	3.00	<0.001	#14-079	A\$71.20 Volume Pricing	5 In Stock
-	50.0 x 50.0	4.84	SCHOTT NG1	1.00	0.001	#14-074	A\$157.60 Volume Pricing	8 In Stock
-	50.0 x 50.0	>5	SCHOTT NG1	2.00	<0.001	#14-076	A\$157.60 Volume Pricing	8 In Stock
-	50.0 x 50.0	>5	SCHOTT NG1	3.00	<0.001	#14-078	A\$157.60 Volume Pricing	7 In Stock
25.00	-	0.99	SCHOTT NG3	1.00	10	#14-081	A\$71.20 Volume Pricing	10 In Stock
25.00	-	1.95	SCHOTT NG3	2.00	1.1	#14-083	A\$71.20 Volume Pricing	10 In Stock
25.00	-	2.91	SCHOTT NG3	3.00	0.12	#14-085	A\$71.20 Volume Pricing	5 In Stock
-	50.0 x 50.0	0.99	SCHOTT NG3	1.00	10	#14-080	A\$157.60 Volume Pricing	13 In Stock
-	50.0 x 50.0	1.95	SCHOTT NG3	2.00	1.1	#14-082	A\$157.60 Volume Pricing	9 In Stock
-	50.0 x 50.0	2.91	SCHOTT NG3	3.00	0.12	#14-084	A\$157.60 Volume Pricing	7 In Stock
25.00	-	0.55	SCHOTT NG4	1.00	28	#14-087	A\$71.20 Volume Pricing	6 In Stock
25.00	-	1.06	SCHOTT NG4	2.00	8.6	#14-089	A\$71.20 Volume Pricing	9 In Stock
25.00	-	1.58	SCHOTT NG4	3.00	2.6	#14-091	A\$71.20 Volume Pricing	7 In Stock
-	50.0 x 50.0	0.55	SCHOTT NG4	1.00	28	#14-086	A\$157.60 Volume Pricing	16 In Stock
-	50.0 x 50.0	1.06	SCHOTT NG4	2.00	8.6	#14-088	A\$157.60 Volume Pricing	8 In Stock
-	50.0 x 50.0	1.58	SCHOTT NG4	3.00	2.6	#14-090	A\$157.60 Volume Pricing	7 In Stock
25.00	-	0.28	SCHOTT NG5	1.00	53	#14-093	A\$71.20 Volume Pricing	7 In Stock

25.00	-	0.51	SCHOTT NG5	2.00	31	#14-095	A\$71.20 Volume Pricing	14 In Stock
25.00	-	0.75	SCHOTT NG5	3.00	18	#14-097	A\$71.20 Volume Pricing	7 In Stock
-	50.0 x 50.0	0.28	SCHOTT NG5	1.00	53	#14-092	A\$157.60 Volume Pricing	6 In Stock
-	50.0 x 50.0	0.51	SCHOTT NG5	2.00	31	#14-094	A\$157.60 Volume Pricing	8 In Stock
-	50.0 x 50.0	0.75	SCHOTT NG5	3.00	18	#14-096	A\$157.60 Volume Pricing	7 In Stock
25.00	-	1.42	SCHOTT NG9	1.00	3.8	#14-099	A\$71.20 Volume Pricing	6 In Stock
25.00	-	2.8	SCHOTT NG9	2.00	0.15	#14-101	A\$71.20 Volume Pricing	6 In Stock
25.00	-	4.18	SCHOTT NG9	3.00	0.007	#14-103	A\$71.20 Volume Pricing	5 In Stock
-	50.0 x 50.0	1.42	SCHOTT NG9	1.00	3.8	#14-098	A\$157.60 Volume Pricing	5 In Stock
-	50.0 x 50.0	2.8	SCHOTT NG9	2.00	0.15	#14-100	A\$157.60 Volume Pricing	12 In Stock
-	50.0 x 50.0	4.18	SCHOTT NG9	3.00	0.007	#14-102	A\$157.60 Volume Pricing	5 In Stock
25.00	-	0.14	SCHOTT NG11	1.00	72	#14-105	A\$71.20 Volume Pricing	10 In Stock
25.00	-	0.25	SCHOTT NG11	2.00	56	#14-107	A\$71.20 Volume Pricing	5 In Stock
25.00	-	0.35	SCHOTT NG11	3.00	44	#14-109	A\$71.20 Volume Pricing	7 In Stock
-	50.0 x 50.0	0.14	SCHOTT NG11	1.00	72	#14-104	A\$157.60 Volume Pricing	11 In Stock
-	50.0 x 50.0	0.25	SCHOTT NG11	2.00	56	#14-106	A\$157.60 Volume Pricing	7 In Stock
-	50.0 x 50.0	0.35	SCHOTT NG11	3.00	44	#14-108	A\$157.60 Volume Pricing	7 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com