


[All Products](#) / [Optics](#) / [Optical Filters](#) / [Longpass Filters](#)

Colored Glass Replacement Longpass Filters

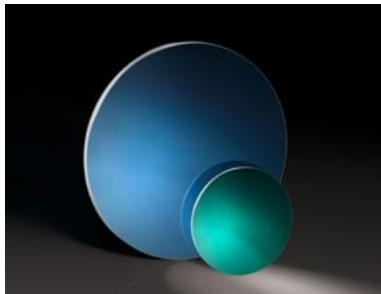


- Dielectric Coated Longpass Filters
- >90% Typical Transmission and >OD5 Blocking
- 100% Environmentally Safe, RoHS Compliant Construction
- Cut-On Wavelengths from 320 to 1000nm

Common Specifications

Physical & Mechanical Properties			
Thickness (mm):	1.10 ±0.10	Clear Aperture (%):	90
Physical Durability:	MIL-C-48497		
Optical Properties			
Optical Density OD (Average):	≥5.0		
Substrate:	BOROFLOAT®	Coating:	Dielectric
Surface Quality:	80-50	Transmission (%):	>90 (typical)
Wavelength Range (nm):	200 - 2500		
Environmental & Durability Factors			
Operating Temperature (°C):	-100 to +400		
Environmental Durability:	MIL-STD-810, Method 507.3, Procedure III, Modified to 40 cycles		

Technical Information

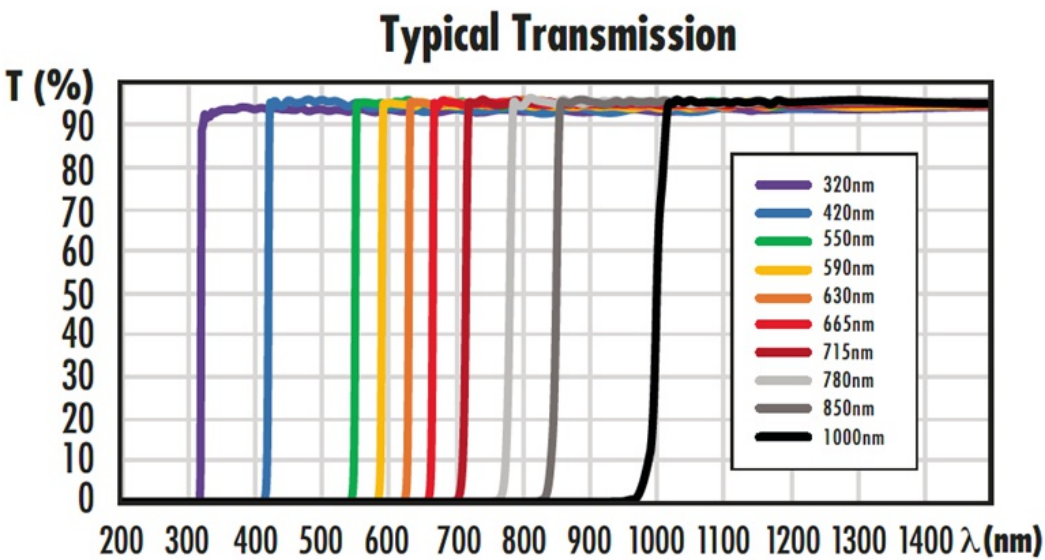

Products

Dia. (mm)	Cut-On Wavelength (nm)	Thickness (mm)	Rejection Wavelength (nm)	Transmission Wavelength (nm)	Wavelength Range (nm)	Stock Number	Price	Buy
12.70	320.00	1.10	200 - 300	335 - 2500	200 - 2500	#15-444	A\$72.51 Volume Pricing	20+ In Stock
12.70	420.00	1.10	200 - 390	440 - 2500	200 - 2500	#15-445	A\$72.51 Volume Pricing	Contact Us
12.70	550.00	1.10	200 - 515	570 - 2500	200 - 2500	#15-446	A\$72.51 Volume Pricing	20+ In Stock
12.70	590.00	1.10	200 - 555	610 - 2500	200 - 2500	#15-447	A\$72.51 Volume Pricing	7 In Stock
12.70	630.00	1.10	200 - 595	650 - 2500	200 - 2500	#15-448	A\$72.51 Volume Pricing	1 In Stock
12.70	665.00	1.10	200 - 630	685 - 2500	200 - 2500	#15-449	A\$72.51 Volume Pricing	2 In Stock
12.70	715.00	1.10	200 - 665	735 - 2500	200 - 2500	#15-450	A\$72.51 Volume Pricing	14 In Stock
12.70	780.00	1.10	200 - 710	800 - 2500	200 - 2500	#15-451	A\$72.51 Volume Pricing	20+ In Stock
12.70	850.00	1.10	200 - 775	870 - 2500	200 - 2500	#15-452	A\$72.51 Volume Pricing	5 In Stock
12.70	1,000.00	1.10	200 - 860	1035 - 2500	200 - 2500	#15-453	A\$72.51 Volume Pricing	20+ In Stock
25.40	320.00	1.10	200 - 300	335 - 2500	200 - 2500	#15-454	A\$91.46 Volume Pricing	5 In Stock
25.40	420.00	1.10	200 - 390	440 - 2500	200 - 2500	#15-455	A\$91.46 Volume Pricing	8 In Stock
25.40	550.00	1.10	200 - 515	570 - 2500	200 - 2500	#15-456	A\$91.46 Volume Pricing	12 In Stock
25.40	590.00	1.10	200 - 555	610 - 2500	200 - 2500	#15-457	A\$91.46 Volume Pricing	14 In Stock
25.40	630.00	1.10	200 - 595	650 - 2500	200 - 2500	#15-458	A\$91.46 Volume Pricing	5 In Stock
25.40	665.00	1.10	200 - 630	685 - 2500	200 - 2500	#15-459	A\$91.46 Volume Pricing	7 In Stock
25.40	715.00	1.10	200 - 665	735 - 2500	200 - 2500	#15-460	A\$91.46 Volume Pricing	12 In Stock
25.40	780.00	1.10	200 - 710	800 - 2500	200 - 2500	#15-461	A\$91.46 Volume Pricing	13 In Stock
25.40	850.00	1.10	200 - 775	870 - 2500	200 - 2500	#15-462	A\$91.46 Volume Pricing	20+ In Stock
25.40	1,000.00	1.10	200 - 860	1035 - 2500	200 - 2500	#15-463	A\$91.46 Volume Pricing	8 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com