


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Precision Polished Metal Coatings](#)

ISP Optics Gold Coated Mirrors See More by [ISP Optics](#)

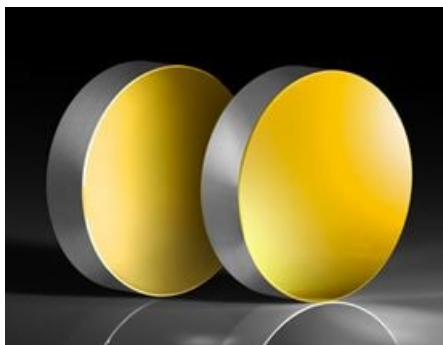

- Pyrex® Mirror Substrates
- Protected Gold Coating
- Ideal for LWIR Applications

Common Specifications

Physical & Mechanical Properties

Back Surface:	Fine Grind	Edges:	Fine Ground
Thickness (mm):	6.35 ±0.20		

Optical Properties

Surface Flatness (P-V):	$\lambda/4$		
Substrate:	Pyrex	Surface Quality:	40-20
Coating Specification:	$R_{avg} \geq 95\% @ 3000 - 5000nm$	Coating:	Protected Gold (3000-5000nm)
Coating Type:	Metal	Wavelength Range (nm):	3000 - 5000

Technical Information

Products

Title	Stock Number	Price	Buy
#25-011 Clearance			
			
12.7mm Dia., Protected Gold Coated, ISP Optics λ/4 Mirror P-MF- AU-12	Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	A\$164.80	8 In Stock

#25-012 Clearance			
			
25.4mm Dia., Protected Gold Coated, ISP Optics λ/4 Mirror P-MF- AU-25	Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	A\$204.72	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com